



- Supplied by the roll

### Characteristics of EPDM

- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

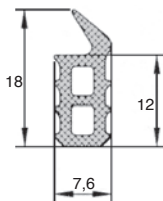

RJA11-27

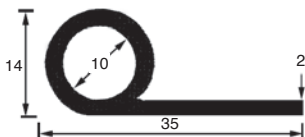

RJA90-38

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA11-27/5	Black EPDM	5 metres	✓	20,81 €
RJA11-27/100	Black EPDM	100 metres	-	333,70 €
RJA90-38/5	Black EPDM	5 metres	✓	38,52 €
RJA90-38/50	Black EPDM	50 metres	-	308,62 €

\*Depending on availability - Dimensions in mm

## Our other products




LVT

Miniature motorised actuator 2A, 2 ampers



PRF\_GAL

Roller for aluminium profile, Flat roller

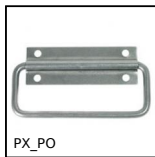

PX\_PO

Carrying handle, standard



PDR-RD

Mounting feet with integrated castors, Offset castor



MDB\_MTB

Moulded plastic bevel gear (nylon), 2:1



HLA24

Right angle spiro bevel gearbox, Up to 78Nm



AF

Shaft clamp with keyway, Set screw



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



BCM\_TP

Modular cylindrical brush, Tampico bristles



PCH

Knob for gripping, Mushroom



MHXred

Reducing sleeve male/female, Hexagonal - steel



GP

Spring loaded toggle latch, With padlock-holder

## Complementary products



RJA00\_02

Sealing strip, Clipping



RJA10\_03

Sealing strip, Clipping