



- Supplied by the roll

### Characteristics of EPDM

- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

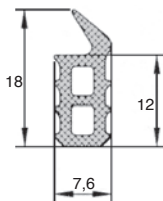

RJA11-27

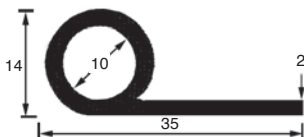

RJA90-38

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA11-27/5	Black EPDM	5 metres	✓	20,81 €
RJA11-27/100	Black EPDM	100 metres	-	333,70 €
RJA90-38/5	Black EPDM	5 metres	✓	38,52 €
RJA90-38/50	Black EPDM	50 metres	-	308,62 €

\*Depending on availability - Dimensions in mm

## Our other products



WSRM

Cylindrical polymer nut, Polymer (Iglidur®) - 1 thread



RBN

Wheel, Rubber tyre - Polypropylene rim



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



BTC20\_10

End cap for rectangular tube, Standard



KITbuh

24V DC motorisation kit, Planetary gears



 
BZY

Cylindrical elasto mount, Steel



PTR

Idle chain sprocket, For standard applications



RIMtce

Locking castor, with central hole



DOMI80

Accessories, Clamping lever



PCH

Knob for gripping, Mushroom



ATZY

Diabolo shaped elasto mount, Steel



CMAss

Eye bolt stainless steel, Stainless steel

## Complementary products



RJA00\_02

Sealing strip, Clipping



RJA10\_03

Sealing strip, Clipping