



- Supplied by the roll

### Characteristics of EPDM

- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

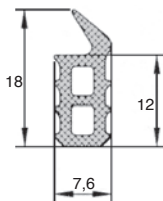

RJA11-27

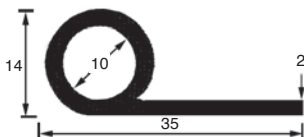

RJA90-38

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA11-27/5	Black EPDM	5 metres	✓	20,81 €
RJA11-27/100	Black EPDM	100 metres	-	333,70 €
RJA90-38/5	Black EPDM	5 metres	✓	38,52 €
RJA90-38/50	Black EPDM	50 metres	-	308,62 €

\*Depending on availability - Dimensions in mm

## Our other products



NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



GGP

Male wing knob, Technopolymer with brass spindle




DOMI80

Accessories, Plate



HBM

 Adjustment bushing for half-rail guide, Adjustment bushing



RPP

Connecting plate for RPP type timing belts, RPP8



BCM\_TP

Modular cylindrical brush, Tampico bristles



MDPOT

Potentiometer,




CLG1

Moulded plastic spur gear, Moulded plastic (nylon)



CHAFR-MINI

 Miniature friction hinge, Friction



JFM

Flanged polymer bush, Universal polymer



BH02

Single housed bearing assembly, Bearing secured with circlips

## Complementary products



RJA00\_02

Sealing strip, Clipping



RJA10\_03

Sealing strip, Clipping