


## RJUM05 RJUM06

Unaffected by dirt


- Housing for closed bearing
- Two versions available: short (RJUM05) or long (RJUM06)
- Interchangeable with standard bearing housings
- Easy to use
- Recommended tolerance: h7
- Material:

Housing: Aluminium  
Liner: iglidur® J




**Fast and silent**

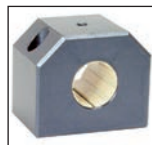

RJUM05

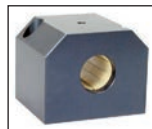

RJUM06

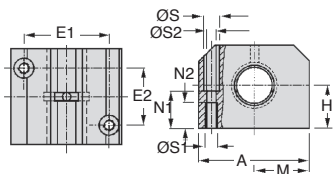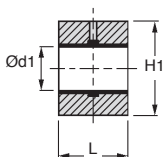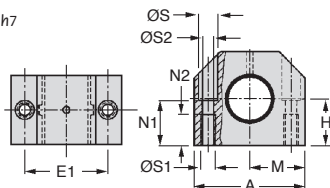

Until  
**-35%\***

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød1	Tolerance	H	H1	A	M	E1	E2	ØS	ØS1	ØS2	N1	N2	L	Price
															each
<b>Short version</b>															1 to 5
RJUM05-12	12	0,02 / 0,05	17	33	40	20,0	29	-	8	M5	4,3	16	11	28	57,00 €
RJUM05-16	16	0,02 / 0,05	19	38	45	22,5	34	-	18	M5	4,3	18	11	30	57,16 €
RJUM05-20	20	0,02 / 0,06	23	45	53	26,5	40	-	19,5	M6	5,3	22	13	30	64,15 €
RJUM05-25	25	0,02 / 0,06	27	54	62	31,0	48	-	11	M8	6,6	26	18	40	66,96 €
RJUM05-30	30	0,03 / 0,07	30	60	67	33,5	53	-	11	M8	6,6	29	18	50	76,48 €
RJUM05-40	40	0,03 / 0,07	39	76	87	43,5	69	-	14	M10	8,4	38	22	60	99,85 €
RJUM05-50	50	0,04 / 0,09	47	92	103	51,5	82	-	19	M12	10,5	46	26	70	135,54 €
<b>Long version</b>															
RJUM06-12	12	0,02 / 0,05	18	35	43	21,5	32	23	8	M5	4,3	16,5	11	39	67,94 €
RJUM06-16	16	0,02 / 0,05	22	42	53	26,5	40	26	10	M6	5,3	21	13	43	75,54 €
RJUM06-20	20	0,02 / 0,06	25	50	60	30,0	45	32	11	M8	6,6	24	18	54	81,36 €
RJUM06-25	25	0,02 / 0,06	30	60	78	39,0	60	40	15	M10	8,4	29	22	67	91,08 €
RJUM06-30	30	0,03 / 0,07	35	70	87	43,5	68	45	15	M10	8,4	34	22	79	99,43 €
RJUM06-40	40	0,03 / 0,07	45	90	108	54,0	86	58	18	M12	10,5	44	26	91	115,81 €
RJUM06-50	50	0,04 / 0,09	50	105	132	66,0	108	50	20	M16	13,5	49	34	113	223,97 €

Dimensions in mm

## Our other products



MC  
Self-compensating shock-absorber, Self-compensating - without adjust...



PRS50  
Stainless steel articulated foot Ø50, Ø 50



BABTV  
Ball lock pins lockable, Stainless steel



MRA\_SS  
Stainless steel Quick link, Stainless steel



BFDdII  
Locking pin for bushes, Nickel-plated steel




PLS  
Cylindrical spacer, Stainless steel 303



CHA60  
Rectangular hinge, drilled or countersunk, Rectangular, drilled or C...



 PMC48\_M8  
Anti-vibration machine mount, Oval base plate



EZYSS  
Stainless steel cylindrical stop, stainless steel



PRF4545r90  
Standard aluminium profile, 45 x 45 mm - R90°



BTESS  
Universal stainless steel arm for tensioner, For use in




J53  
Spur gear coaxial gearbox, from 0.43 to 1.15 - Inline

## Complementary products



 RJUM05  
Drylin R® linear bearing housing, Closed - Long



AWMP  
Aluminium shaft for linear guide, Aluminium