

Steel gravity rollers

For gravity
conveying systems

RLX/AC8

- Mounted on oiled conical steel bearings
- Moving individual loads
- Only for gravity applications
- Axle mounted on left side spring
- Materials:
 - Galvanised steel tube
 - Steel axle
 - Polypropylene roller housing
 - Polypropylene seals




Uses

- Maximum conveyor speed: 0.3 m/s
- Working temp range: -5 to +40 °C

Advantages

- Gentle lateral movement of the product being transported
- Design includes protection of bearing against dust and liquids
- Dirt resistant

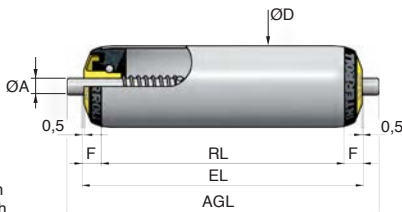

RL = Useful length
EL = Installed length
AGL = Overall length

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD roller	Tube thickness	ØA axle	RL	EL	AGL	F	Load capacity (N)	Stock*	Price each 1 to 5
RLX50-300/AC8	50	1,5	8	300	310	326	11	350	✓	11,38 €
RLX50-350/AC8	50	1,5	8	350	360	376	11	350	-	12,21 €
RLX50-400/AC8	50	1,5	8	400	410	426	11	350	-	13,06 €
RLX50-450/AC8	50	1,5	8	450	460	476	11	350	-	13,88 €
RLX50-500/AC8	50	1,5	8	500	510	526	11	350	-	14,71 €
RLX50-550/AC8	50	1,5	8	550	560	576	11	350	✓	15,55 €
RLX50-600/AC8	50	1,5	8	600	610	626	11	350	✓	16,36 €
RLX50-650/AC8	50	1,5	8	650	660	676	11	350	✓	17,20 €
RLX50-700/AC8	50	1,5	8	700	710	726	11	350	-	18,01 €
RLX50-750/AC8	50	1,5	8	750	760	776	11	350	-	18,85 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

251

 
Our other products



DB_ECO
Eco. range steel bevel gear, 2:1



PPG
Indexing plunger with flange, With horizontal mounting flange



UCF PBT
Stainless steel/Polymer flanged bearing, Polymer and stainless steel



CHM63-MOT
Asynchronous AC motorgearboxes 0.37 to 1.5kW, 0.37 to 1.5kW



BOXKK
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



EBC
Cap nut Hygienic Design®, Compact



PRF4532
Standard aluminium profile, 45 x 32 mm



CHA_GC_9SS
Stainless steel garnet hinge, To be welded



PTA150
Articulated levelling foot, pressed base Ø150, Ø 150



MAX22
Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



PSG25
Spur gear - precision range, Pre-hardened Steel 35NCD6



CFF
Female rod ends DIN ISO12240-4, Steel / bronze

Complementary products



RLX
Free running conveyor roller, PVC



GAL48_OMNI
Omni-directional roller, Omni-directional



PRF_BP
Doorstop for aluminium profile, Swing door stop