

Steel gravity rollers

For gravity
conveying systems

RLX/AC8

- Mounted on oiled conical steel bearings
- Moving individual loads
- Only for gravity applications
- Axle mounted on left side spring
- Materials:
 - Galvanised steel tube
 - Steel axle
 - Polypropylene roller housing
 - Polypropylene seals




Uses

- Maximum conveyor speed: 0.3 m/s
- Working temp range: -5 to +40 °C

Advantages

- Gentle lateral movement of the product being transported
- Design includes protection of bearing against dust and liquids
- Dirt resistant

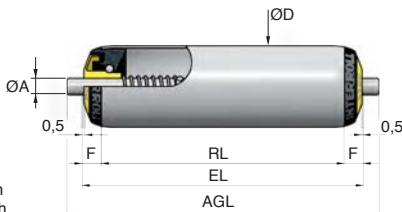

RL = Useful length
EL = Installed length
AGL = Overall length

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD roller	Tube thickness	ØA axle	RL	EL	AGL	F	Load capacity (N)	Stock*	Price each 1 to 5
RLX50-300/AC8	50	1,5	8	300	310	326	11	350	✓	11,38 €
RLX50-350/AC8	50	1,5	8	350	360	376	11	350	-	12,21 €
RLX50-400/AC8	50	1,5	8	400	410	426	11	350	-	13,06 €
RLX50-450/AC8	50	1,5	8	450	460	476	11	350	-	13,88 €
RLX50-500/AC8	50	1,5	8	500	510	526	11	350	-	14,71 €
RLX50-550/AC8	50	1,5	8	550	560	576	11	350	✓	15,55 €
RLX50-600/AC8	50	1,5	8	600	610	626	11	350	✓	16,36 €
RLX50-650/AC8	50	1,5	8	650	660	676	11	350	✓	17,20 €
RLX50-700/AC8	50	1,5	8	700	710	726	11	350	-	18,01 €
RLX50-750/AC8	50	1,5	8	750	760	776	11	350	-	18,85 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

251

Our other products



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



AFM

Flanged polymer bush, Food grade polymer



DB

Steel bevel gear, 2:1



CMM_SS

Male rod ends DIN ISO12240-4, Stainless steel / bronze - Economy range




PRF_SDD_1820

Support for Ø18 or Ø20mm Prox detector, Ø18 and Ø20



ZG0

 Plastic spur gear, Machined plastic (delrin)



M1

Worm and wheel set, Machined plastic (delrin)



BAGtr

Lead screw clamping collar, Aluminium



RJA10_03

Sealing strip, Clipping



VEL

Self-gripping cable strip, electric and pneumatic cables



HRV

V-rail guidance Simple Select® system, Rail with carriage

Complementary products



RLX

Free running conveyor roller, PVC



GAL48_OMNI

Omnidirectional roller, Omnidirectional



PRF_BP

Doorstop for aluminium profile, Swing door stop