



Cam follower without axial guide


Without interior ring

IKO RNAS


- For shaft diameters from 7mm to 60mm
- With external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6
- Shaft hardness: 58-64 HRC, Ra 0.2

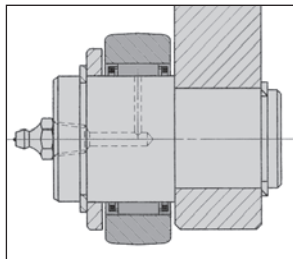

Typical application

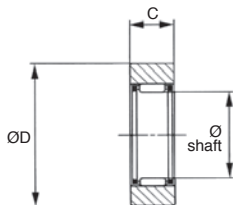

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Shaft Ø	ØD	C	Static load Co (N)	Dynamic load C (N)	Weight (g)	Stock*	Price each 1 to 5
RNAS-5	07	16	07,8	2390	2710	8,9	✓	15,60 €
RNAS-6	10	19	09,8	4550	4160	13,9	✓	16,92 €
RNAS-8	12	24	09,8	5890	5650	23,5	✓	17,63 €
RNAS-10	14	30	11,8	9680	9790	42,5	✓	18,28 €
RNAS-12	16	32	11,8	10900	10500	49,5	✓	19,42 €
RNAS-15	20	35	11,8	14300	12400	50,0	✓	20,29 €
RNAS-17	22	40	15,8	20900	17600	90,0	-	20,19 €
RNAS-20	25	47	15,8	24500	19400	135,0	✓	22,32 €
RNAS-25	30	52	15,8	28400	20800	152,0	-	25,06 €
RNAS-30	38	62	19,8	45400	30500	255,0	-	28,06 €
RNAS-35	42	72	19,8	50600	32400	375,0	-	30,95 €
RNAS-40	50	80	19,8	61100	35900	420,0	-	36,48 €
RNAS-45	55	85	19,8	66400	37400	460,0	-	37,43 €
RNAS-50	60	90	19,8	71700	38900	500,0	-	41,75 €

*Depending on availability - Dimensions in mm


Our other products



SDB
Locking bolt support bracket, Mounting holes at 90° to locating bolt



CHAL3
Piano hinge, Steel

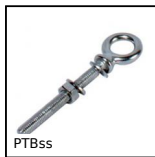

PTBss
Threaded eye hook stainless steel, Stainless steel



FBL6000_K19
Brush strip per meter horsehair fibres Ø0.2, Black horsehair



PRF-GUM
Aluminium profile anodising polisher, Polishing block



 
M0
Worm and wheel set, Machined plastic (delrin)




NSB
Standard linear bearing housing, Closed - Long



VTAP
Magnetic head screw, With rubber coating, With rubber coating



 SLVHlok
Vertical toggle clamp, Vertical toggle clamp / horizontal foot



GLT2-27
Telescopic drawer runners for groove mounting, Partial



FAD
Threaded swivel feet, Swivel feet without anti-slip plate



ADSR
Backlash free coupling Gerwah®, from 12.5 to 525Nm

Complementary products



NAST
Cam follower without axial guide, With interior ring



CF
Cam follower, Standard - steel