


Housing block for ballscrew

BSB
RPB


Possible machining options

The ballscrews will require machining (by the user) before they can be used with the BSB and RPB housings

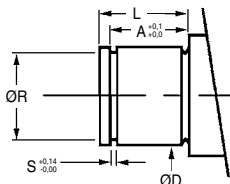

Recommended dimensions for the ends of the ballscrew

For housing block Part number	ØD (g6)	A	ØR	S	L
BSB10	8	7,90	7,6	0,90	11
BSB12	10	9,15	9,6	1,15	12
BSB15	15	10,15	14,3	1,15	12
BSB17	17	13,15	16,2	1,15	16
BSB20	20	13,35	19,0	1,35	16
BSB25	25	16,35	23,9	1,35	20
BSB30	30	17,75	28,6	1,75	20
BSB40	40	19,75	38,0	1,75	25

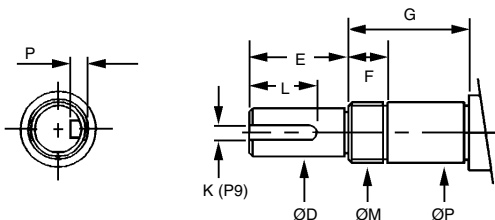

For housing block Part number	ØP (g6)	ØM	ØD (h6)	K	P	E	F	G	L
RPB10	10	M10x1,0	8	2	1,25	15	16	39	11
RPB12	12	M12x1,0	10	3	1,85	15	16	39	30
RPB15	15	M15x1,0	12	4	2,55	20	16	41	21
RPB17	17	M17x1,0	15	5	3,05	27	17	53	21
RPB20	20	M20x1,0	17	5	3,05	27	17	53	30
RPB25	25	M25x1,5	20	6	3,55	36	18	65	34
RPB30	30	M30x1,5	25	8	4,10	42	18	72	40
RPB40	40	M40x1,5	35	10	5,10	70	35	98	49

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


- Free bearing
- Supplied with a radial contact ball bearing
- Material: steel

Assembly

- See end of section for recommended machining options

Accessories

- KGS ballscrews

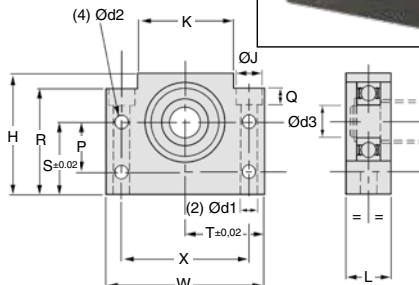

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-15%	On request

Part number	For ballscrew Ø	Shaft Ød3 (h7)	W	H	S±0.02	Bearing	Dynamic load (kN)	
							Axial	Radial
BSB10	16	8	60	39	22	608ZZ	-	3,35
BSB12	16 / 20	10	60	43	25	6000ZZ	-	4,65
BSB15	20	15	70	48	28	6002ZZ	-	5,7
BSB17	20 / 25	17	86	64	39	6203ZZ	-	9,75
BSB20	25	20	88	60	34	6004ZZ	-	9,55
BSB25	32	25	106	80	48	6205ZZ	-	14,3
BSB30	40	30	128	89	51	6206ZZ	-	19,8
BSB40	50	40	160	110	60	6208ZZ	-	29,7

Part number	R	X	K	Ød1	ØJ	Q	Ød2	P	L	Stock*	Price each
											€
BSB10	32,5	46	34	6,6	11,0	5,0	5,5	15	20	-	74,25 €
BSB12	35,0	46	35	6,6	11,0	6,5	5,5	18	20	✓	86,98 €
BSB15	38,0	54	40	6,6	11,0	6,5	5,5	18	20	✓	82,33 €
BSB17	55,0	68	50	9,0	14,0	8,5	6,6	28	23	✓	97,38 €
BSB20	50,0	70	52	9,0	14,0	8,5	6,6	22	26	✓	105,10 €
BSB25	70,0	85	64	11,0	17,5	11,0	9,0	33	30	-	124,80 €
BSB30	78,0	102	76	14,0	20,0	13,0	11,0	33	32	-	140,22 €
BSB40	90,0	130	100	18,0	26,0	17,5	14,0	37	37	-	217,91 €

*Depending on availability - Dimensions in mm

Ballscrew bearing unit



RPB

For rigid assemblies


- Fixed bearing
- Fitted with an angular contact bearing
- Material: steel

Assembly

- See end of section for recommended machining options

Accessories

- KGS ballscrews
- Joint

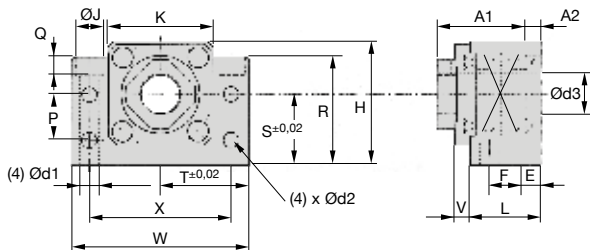

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-15%	On request

Part number	For Shaft ballscrew $\varnothing d_3$								Dynamic load (kN)		
	\varnothing	$(h7)$	W	H	S	R	T	X	Bearing	Axial	Radial
RPB10	16	10	60	39	22	32,5	30	46	7000DFA	6,7	2,78
RPB12	16 / 20	12	60	43	25	32,5	30	46	7001DFA	7,25	3,1
RPB15	20	15	70	48	28	38,0	35	54	7002DFA	7,75	4,07
RPB17	20 / 25	17	86	64	39	55,0	43	68	7203DFA	14	5,95
RPB20	25	20	88	60	34	50,0	44	70	7204DFA	18,3	9,7
RPB25	32	25	106	80	48	70,0	53	85	7205DFA	20,6	11,7
RPB30	40	30	128	89	51	78,0	64	102	7206DFA	28,6	16,6
RPB40	50	40	160	110	60	90,0	80	130	7208DFA	45	27,7

Part number	K	L	E	F	V	A1	A2	$\varnothing d_1$	$\varnothing J$	Q	$\varnothing d_2$	P	Stock*	Price each
RPB10	34	25	6	13	5	29	5	6,6	11,0	5,0	5,5	15	-	159,65 €
RPB12	35	25	6	13	5	29	5	6,6	11,0	6,5	5,5	18	✓	182,94 €
RPB15	40	27	6	15	6	32	6	6,6	11,0	6,5	5,5	18	✓	198,20 €
RPB17	50	35	8	19	9	44	7	9,0	14,0	8,5	6,6	28	-	271,57 €
RPB20	52	35	8	19	8	43	8	9,0	14,0	8,5	6,6	22	✓	243,01 €
RPB25	64	42	10	22	12	54	9	11,0	17,5	11,0	9,0	33	-	291,31 €
RPB30	76	45	11	23	14	61	9	14,0	20,0	13,0	11,0	33	-	386,13 €
RPB40	100	61	14	33	18	76	15	18,0	26,0	17,5	14,0	37	-	484,66 €

*Depending on availability - Dimensions in mm

Our other products



RFK38B
Hypoid gearbox -
Stainless steel, up to
200 Nm




NCT
Square tube
connector, Fixed
angle



AC144
Strike for toggle latch,
22mm



 PRF_PA
Angle plate for
aluminium profile,
Adjustable plate



MR_MMR
Metric section rack,
Steel



RFK48C
Hypoid gearbox -
Stainless steel, up to
350 Nm




R204
Die spring ISO10243,
Average



PSPE20
Conical flexible shaft
handle Ø20, Black
PVC



 PT880
Drive sprocket for slat
top chain, Range 880



LAT4
4A motorised linear
actuator, 4 amperes



SCE
U-shaped cable
clamp, Steel



LVT
Miniature motorised
actuator 4A, 4 amperes

Complementary products



KGS
Ballscrew, supplied by
the metre, Rolled
ballscrew, per metre



BSB
Ballscrew bearing
unit, Support