

Polyamide castor with mounting plate


RPCPL For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
Top plate: pressed steel sheet, protected by bright zinc plating
Polyamide wheel (see RPC)
Working temperature range: - 30°C to + 80°C



Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors

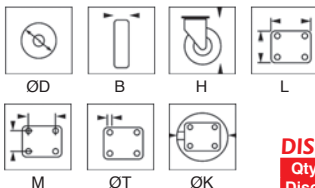


DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max. load (kg)	Stock*	Price each 1 to 9
Fixed										
RPC60/PL/F	60	31	100	110x85	80x60	8	-	200	-	6,80 €
RPC80/PL/F	80	32	109	110x85	80x60	8	-	250	✓	6,36 €
RPC100/PL/F	100	32	126	110x85	80x60	8	-	300	✓	6,89 €
RPC125/PL/F	125	36	154	110x85	80x60	8	-	350	-	10,63 €
RPC150/PL/F	150	37	182	110x85	80x60	8	-	400	-	15,13 €
RPC160/PL/F	160	40	196	135x110	105x80	11	-	500	-	27,70 €
RPC200/PL/F	200	50	241	135x110	105x80	11	-	600	-	32,83 €
Swivel										
RPC60/PL/P	60	31	100	110x85	80x60	8	140	200	-	9,41 €
RPC80/PL/P	80	32	109	110x85	80x60	8	160	250	✓	7,49 €
RPC100/PL/P	100	32	126	110x85	80x60	8	184	300	✓	8,02 €
RPC125/PL/P	125	36	154	110x85	80x60	8	210	350	-	11,93 €
RPC150/PL/P	150	37	182	110x85	80x60	8	246	400	-	18,94 €
RPC160/PL/P	160	40	196	135x110	105x80	11	268	500	-	30,71 €
RPC200/PL/P	200	50	241	135x110	105x80	11	318	600	-	35,11 €
Swivel with double brake										
RPC80/PL/PDB	80	32	109	110x85	80x60	8	290	250	✓	10,80 €
RPC100/PL/PDB	100	32	126	110x85	80x60	8	290	300	✓	11,59 €
RPC125/PL/PDB	125	36	154	110x85	80x60	8	290	350	✓	16,07 €
RPC150/PL/PDB	150	37	182	110x85	80x60	8	290	400	-	23,01 €
RPC160/PL/PDB	160	40	196	135x110	105x80	11	268	500	-	34,36 €
RPC200/PL/PDB	200	50	241	135x110	105x80	11	318	600	-	39,31 €

Dimensions in mm

 Our other products



PF30
Worm and wheel gear reducer, up to 8.80 Nm



SRG
Adjustable latch clamp with strike plate. Stroke from 78mm to 90mm



BEAS
Star shaped anti-static handle, Star, anti-static



BDP2R
Adjustable support arm, Increased grip



GLT3-76
Telescopic drawer,



CHM63
Worm and wheel gear reducer, up to 196 Nm



MSP38
Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...



UFX
Uneflex® elastic coupling, range



VTA
Vari-Tork® slip friction clutch, 0.53 to



PRF_JL6
Lip seal for panel, Door seal - Ø 6mm




AKD
Bellows coupling Gerwah®, from 22 to



HTD8M-BAR
HTD type tooth bar stock, HTD8

 Complementary products



RPC
Wheel, Polyamide



RPCplss
Swivel castor with double brake, Stainless steel - Polyamide



RBGpl
Swivel castor with double brake, Steel - grey rubber



RBNpl
Swivel castor with double brake, Steel - rubber