

Polyamide castor with mounting plate


RPCPL For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
Top plate: pressed steel sheet, protected by bright zinc plating
Polyamide wheel (see RPC)
Working temperature range: - 30°C to + 80°C



Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors

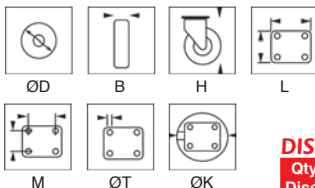

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max. load (kg)	Stock*	Price each 1 to 9
Fixed										
RPC60/PL/F	60	31	100	110x85	80x60	8	-	200	-	6,80 €
RPC80/PL/F	80	32	109	110x85	80x60	8	-	250	✓	6,36 €
RPC100/PL/F	100	32	126	110x85	80x60	8	-	300	✓	6,89 €
RPC125/PL/F	125	36	154	110x85	80x60	8	-	350	-	10,63 €
RPC150/PL/F	150	37	182	110x85	80x60	8	-	400	-	15,13 €
RPC160/PL/F	160	40	196	135x110	105x80	11	-	500	-	27,70 €
RPC200/PL/F	200	50	241	135x110	105x80	11	-	600	-	32,83 €
Swivel										
RPC60/PL/P	60	31	100	110x85	80x60	8	140	200	-	9,41 €
RPC80/PL/P	80	32	109	110x85	80x60	8	160	250	✓	7,49 €
RPC100/PL/P	100	32	126	110x85	80x60	8	184	300	✓	8,02 €
RPC125/PL/P	125	36	154	110x85	80x60	8	210	350	-	11,93 €
RPC150/PL/P	150	37	182	110x85	80x60	8	246	400	-	18,94 €
RPC160/PL/P	160	40	196	135x110	105x80	11	268	500	-	30,71 €
RPC200/PL/P	200	50	241	135x110	105x80	11	318	600	-	35,11 €
Swivel with double brake										
RPC80/PL/PDB	80	32	109	110x85	80x60	8	290	250	✓	10,80 €
RPC100/PL/PDB	100	32	126	110x85	80x60	8	290	300	✓	11,59 €
RPC125/PL/PDB	125	36	154	110x85	80x60	8	290	350	✓	16,07 €
RPC150/PL/PDB	150	37	182	110x85	80x60	8	290	400	-	23,01 €
RPC160/PL/PDB	160	40	196	135x110	105x80	11	268	500	-	34,36 €
RPC200/PL/PDB	200	50	241	135x110	105x80	11	318	600	-	39,31 €

Dimensions in mm

Our other products



BAG

Steel Clamping collar,
Steel




LINK64

Synchronous AC
Motor and- gearbox ,
from 1.3 to 6Nm



PTR

Idle chain sprocket,
For standard
applications

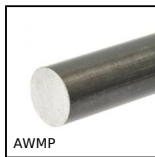

AWMP

Aluminium shaft for
linear guide,
Aluminium



GPLso

Brush, silk



PLM-SC

Magnetic stud with
threaded hole, With
threaded hole



G2

Steel spur gear, Steel
20NCD2



PRF_ART

Articulated bracket for
use with aluminium
profile, With clamping
ha...



LBE

Miniature closed
linear bearing,
Steel



UTKswrr

V shaped channel
UtiliTrak®, V rail



GE32

Sprung toggle latch
with connecting link,
Steel



MEB

Moulded plastic bevel
gear (nylon), 1:1

Complementary products



RPC

Wheel, Polyamide



RBNpl

Swivel castor with
plate, Steel - rubber



RBGpl

Swivel castor with
plate, Steel - grey
rubber



RURp

Wheel pivoting with
plate, Polyurethane -
Aluminium rim (Free
running)