

# Polyamide castor with mounting plate


## RPCPL For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:  
Top plate: pressed steel sheet, protected by bright zinc plating  
Polyamide wheel (see RPC)  
Working temperature range: - 30°C to + 80°C



### Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors

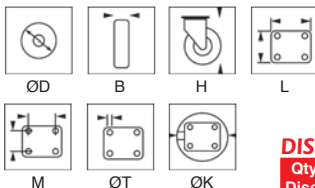

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max. load (kg)	Stock*	Price each 1 to 9
<b>Fixed</b>										
RPC60/PL/F	60	31	100	110x85	80x60	8	-	200	-	6,80 €
RPC80/PL/F	80	32	109	110x85	80x60	8	-	250	✓	6,36 €
RPC100/PL/F	100	32	126	110x85	80x60	8	-	300	✓	6,89 €
RPC125/PL/F	125	36	154	110x85	80x60	8	-	350	-	10,63 €
RPC150/PL/F	150	37	182	110x85	80x60	8	-	400	-	15,13 €
RPC160/PL/F	160	40	196	135x110	105x80	11	-	500	-	27,70 €
RPC200/PL/F	200	50	241	135x110	105x80	11	-	600	-	32,83 €
<b>Swivel</b>										
RPC60/PL/P	60	31	100	110x85	80x60	8	140	200	-	9,41 €
RPC80/PL/P	80	32	109	110x85	80x60	8	160	250	✓	7,49 €
RPC100/PL/P	100	32	126	110x85	80x60	8	184	300	✓	8,02 €
RPC125/PL/P	125	36	154	110x85	80x60	8	210	350	-	11,93 €
RPC150/PL/P	150	37	182	110x85	80x60	8	246	400	-	18,94 €
RPC160/PL/P	160	40	196	135x110	105x80	11	268	500	-	30,71 €
RPC200/PL/P	200	50	241	135x110	105x80	11	318	600	-	35,11 €
<b>Swivel with double brake</b>										
RPC80/PL/PDB	80	32	109	110x85	80x60	8	290	250	✓	10,80 €
RPC100/PL/PDB	100	32	126	110x85	80x60	8	290	300	✓	11,59 €
RPC125/PL/PDB	125	36	154	110x85	80x60	8	290	350	✓	16,07 €
RPC150/PL/PDB	150	37	182	110x85	80x60	8	290	400	-	23,01 €
RPC160/PL/PDB	160	40	196	135x110	105x80	11	268	500	-	34,36 €
RPC200/PL/PDB	200	50	241	135x110	105x80	11	318	600	-	39,31 €

Dimensions in mm

## Our other products



BAG

Steel Clamping collar,  
Steel




LINK64

Synchronous AC  
Motor and- gearbox ,  
from 1.3 to 6Nm



PTR

Idle chain sprocket,  
For standard  
applications

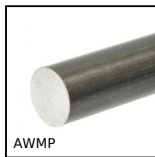

AWMP

Aluminium shaft for  
linear guide,  
Aluminium



GPLso

Brush, silk



PLM-SC

Magnetic stud with  
threaded hole, With  
threaded hole



G2

Steel spur gear, Steel  
20NCD2



PRF\_ART

Articulated bracket for  
use with aluminium  
profile, With clamping  
ha...



LBE

Miniature closed  
linear bearing,  
Steel



UTKswrr

V shaped channel  
UtiliTrak®, V rail



GE32

Sprung toggle latch  
with connecting link,  
Steel



MEB

Moulded plastic bevel  
gear (nylon), 1:1

## Complementary products



RPC

Wheel, Polyamide



RBNpl

Swivel castor with  
plate, Steel - rubber



RBGpl

Swivel castor with  
plate, Steel - grey  
rubber



RURp

Wheel pivoting with  
plate, Polyurethane -  
Aluminium rim (Free  
running)