

Polyamide castor with mounting plate **stainless steel**

RPCPLSS

For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
 - Top plate: pressed stainless steel sheet
 - Polyamide wheel (see RPC)
 - Working temperature range: - 30°C to + 80°C


Swivel with double locks

Stainless steel



Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)

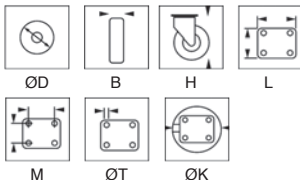

DISCOUNTS

Qty	1+	5+	15+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Price each 1 to 9
Fixed									
RPC60/PL/F/SS	60	31	96	115x83	80x60	11x9	-	200	17,74 €
RPC80/PL/F/SS	80	32	105	115x83	80x60	11x9	-	250	17,74 €
RPC100/PL/F/SS	100	32	124	115x83	80x60	11x9	-	300	19,01 €
RPC125/PL/F/SS	125	36	152	115x83	80x60	11x9	-	350	22,01 €
RPC150/PL/F/SS	150	37	179	115x83	80x60	11x9	-	400	39,42 €
RPC160/PL/F/SS	160	40	197	135x105	105x80	11	-	600	65,38 €
RPC200/PL/F/SS	200	50	240	135x105	105x80	11	-	700	69,61 €
Swivel									
RPC60/PL/P/SS	60	31	96	115x83	80x60	11x9	155	200	25,19 €
RPC80/PL/P/SS	80	32	105	115x83	80x60	11x9	173	250	25,19 €
RPC100/PL/P/SS	100	32	124	115x83	80x60	11x9	193	300	26,97 €
RPC125/PL/P/SS	125	36	152	115x83	80x60	11x9	221	350	31,46 €
RPC150/PL/P/SS	150	37	179	115x83	80x60	11x9	257	400	55,84 €
RPC160/PL/P/SS	160	40	197	135x105	105x80	11	268	600	73,72 €
RPC200/PL/P/SS	200	50	240	135x105	105x80	11	318	700	79,11 €
Swivel with double brake									
RPC80/PL/PDB/SS	80	32	105	115x83	80x60	11x9	293	250	34,45 €
RPC100/PL/PDB/SS	100	32	124	115x83	80x60	11x9	293	300	36,30 €
RPC125/PL/PDB/SS	125	36	152	115x83	80x60	11x9	293	350	38,70 €
RPC150/PL/PDB/SS	150	37	179	115x83	80x60	11x9	293	400	75,28 €
RPC160/PL/PDB/SS	160	40	197	135x105	105x80	11	268	600	89,61 €
RPC200/PL/PDB/SS	200	50	240	135x105	105x80	11	318	700	100,07 €

Dimensions in mm

Our other products



AT5P_AT10P
Connecting plate for AT type timing belts, AT5



TPEf
Castor for aluminium profile, Fixed



CHTRP
Single and dual output gearboxes, Up to 87,3 Nm



PW_PWG05
Worm - precision range, Steel



SCR
Suction cup threaded insert, Insert for suction cup - Socket screw



HLA28
Right angle spiro bevel gearbox, Up to 182Nm



T5P_T10P
Connecting plate for T type timing belts, T10



MCLred
Reducing sleeve female/female, Cylindrical - stainless steel



RFVcap
Stainless steel protective cover, Closed protective



AC156-157
Strike for toggle latch, 25.5mm



PGMT
Pull handle, Stainless steel



PRF-SCL
Lock for aluminium profile, Lock for sliding doors

Complementary products



RPC
Wheel, Polyamide



RBNpl
Swivel castor with double brake, Steel - rubber



RURp
Swivel castor with double brake, Polyurethane - Aluminium rim (Free

...



RPCpl

Swivel castor with
double brake, Steel -
Polyamide