

Polyamide castor with mounting plate **stainless steel**

RPCPLSS

For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
 - Top plate: pressed stainless steel sheet
 - Polyamide wheel (see RPC)
 - Working temperature range: - 30°C to + 80°C


Swivel with double locks

Stainless steel



Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)

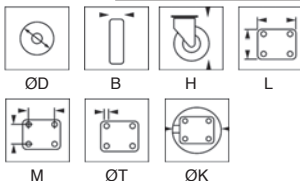

DISCOUNTS

Qty	1+	5+	15+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Price each 1 to 9
Fixed									
RPC60/PL/F/SS	60	31	96	115x83	80x60	11x9	-	200	17,74 €
RPC80/PL/F/SS	80	32	105	115x83	80x60	11x9	-	250	17,74 €
RPC100/PL/F/SS	100	32	124	115x83	80x60	11x9	-	300	19,01 €
RPC125/PL/F/SS	125	36	152	115x83	80x60	11x9	-	350	22,01 €
RPC150/PL/F/SS	150	37	179	115x83	80x60	11x9	-	400	39,42 €
RPC160/PL/F/SS	160	40	197	135x105	105x80	11	-	600	65,38 €
RPC200/PL/F/SS	200	50	240	135x105	105x80	11	-	700	69,61 €
Swivel									
RPC60/PL/P/SS	60	31	96	115x83	80x60	11x9	155	200	25,19 €
RPC80/PL/P/SS	80	32	105	115x83	80x60	11x9	173	250	25,19 €
RPC100/PL/P/SS	100	32	124	115x83	80x60	11x9	193	300	26,97 €
RPC125/PL/P/SS	125	36	152	115x83	80x60	11x9	221	350	31,46 €
RPC150/PL/P/SS	150	37	179	115x83	80x60	11x9	257	400	55,84 €
RPC160/PL/P/SS	160	40	197	135x105	105x80	11	268	600	73,72 €
RPC200/PL/P/SS	200	50	240	135x105	105x80	11	318	700	79,11 €
Swivel with double brake									
RPC80/PL/PDB/SS	80	32	105	115x83	80x60	11x9	293	250	34,45 €
RPC100/PL/PDB/SS	100	32	124	115x83	80x60	11x9	293	300	36,30 €
RPC125/PL/PDB/SS	125	36	152	115x83	80x60	11x9	293	350	38,70 €
RPC150/PL/PDB/SS	150	37	179	115x83	80x60	11x9	293	400	75,28 €
RPC160/PL/PDB/SS	160	40	197	135x105	105x80	11	268	600	89,61 €
RPC200/PL/PDB/SS	200	50	240	135x105	105x80	11	318	700	100,07 €

Dimensions in mm

Our other products



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



T5P_T10P

Connecting plate for T type timing belts, T10



 
H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



VAB

Flanged nut for ball screw, For VAB ballscrew



PTR

Idler chain sprocket, For standard applications



CHAuss

Screwed hinge, 270°



ACLBTS

Spherical ended stop for aluminium profile, Spherical ended stop



UGH25

H Type Guide units, For Ø25 actuators



NKXR

Combined bearing without inner ring,



Q6

Deep groove ball bearing, Steel



RFKfp

Stainless steel gearbox - accessories,



VTLF

3 lobed handle, Polyamide - Brass

Complementary products



RPC

Wheel, Polyamide



RBNpl

Swivel castor with double brake, Steel - rubber



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free)

...



RBGpl

Swivel castor with
double brake, Steel -
grey rubber