

Polyamide castor with mounting plate **stainless steel**

RPCPLSS

For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
 - Top plate: pressed stainless steel sheet
 - Polyamide wheel (see RPC)
 - Working temperature range: - 30°C to + 80°C


Swivel with double locks

Stainless steel



Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)

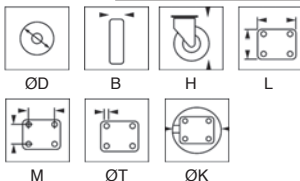

DISCOUNTS

Qty	1+	5+	15+
Disc.	List	-5%	On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Price each 1 to 9
Fixed									
RPC60/PL/F/SS	60	31	96	115x83	80x60	11x9	-	200	17,74 €
RPC80/PL/F/SS	80	32	105	115x83	80x60	11x9	-	250	17,74 €
RPC100/PL/F/SS	100	32	124	115x83	80x60	11x9	-	300	19,01 €
RPC125/PL/F/SS	125	36	152	115x83	80x60	11x9	-	350	22,01 €
RPC150/PL/F/SS	150	37	179	115x83	80x60	11x9	-	400	39,42 €
RPC160/PL/F/SS	160	40	197	135x105	105x80	11	-	600	65,38 €
RPC200/PL/F/SS	200	50	240	135x105	105x80	11	-	700	69,61 €
Swivel									
RPC60/PL/P/SS	60	31	96	115x83	80x60	11x9	155	200	25,19 €
RPC80/PL/P/SS	80	32	105	115x83	80x60	11x9	173	250	25,19 €
RPC100/PL/P/SS	100	32	124	115x83	80x60	11x9	193	300	26,97 €
RPC125/PL/P/SS	125	36	152	115x83	80x60	11x9	221	350	31,46 €
RPC150/PL/P/SS	150	37	179	115x83	80x60	11x9	257	400	55,84 €
RPC160/PL/P/SS	160	40	197	135x105	105x80	11	268	600	73,72 €
RPC200/PL/P/SS	200	50	240	135x105	105x80	11	318	700	79,11 €
Swivel with double brake									
RPC80/PL/PDB/SS	80	32	105	115x83	80x60	11x9	293	250	34,45 €
RPC100/PL/PDB/SS	100	32	124	115x83	80x60	11x9	293	300	36,30 €
RPC125/PL/PDB/SS	125	36	152	115x83	80x60	11x9	293	350	38,70 €
RPC150/PL/PDB/SS	150	37	179	115x83	80x60	11x9	293	400	75,28 €
RPC160/PL/PDB/SS	160	40	197	135x105	105x80	11	268	600	89,61 €
RPC200/PL/PDB/SS	200	50	240	135x105	105x80	11	318	700	100,07 €

Dimensions in mm

Our other products



SH0

Parallel axis helical gear, Steel 20NCD2



M1

Worm and wheel set, Non hardened steel



PTA100ssEB

Articulated foot with sheet metal base Ø100, Articulated foot



RPCplss

Swivel castor with plate, Stainless steel - Polyamide



DOMI30

Accessories, Plate




BABA

Ball pin lifting ring, Steel



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel

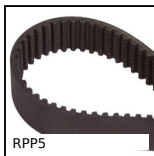

RPP5

RPP heavy duty timing belt, RPP5



G-ECO

Eco range Spur gear, Steel C45



J52

Spur gear coaxial gearbox, from 0.27 to



ACLEPP

Right angled bracket for aluminium profile,



BOXbeta

Box of assorted hitch pins, Boxed set - hitch

Complementary products



RPC

Wheel, Polyamide



RBNpl

Swivel castor with double brake, Steel - rubber



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free

...



RBGpl

Swivel castor with
double brake, Steel -
grey rubber