

- Light coloured Polyamide wheel
- Smooth central bore
- Working temperature range: -30°C to +80°C

Advantages

- Shock and abrasion resistant
- Does not stain floors
- Does not mark floors
- Resists most chemical agents
- Low rolling resistance
- For solid and hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)



For smooth surfaces



ØD



B



C



ØA

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | ØD | B | C | ØA | Maximum load (kg) | Stock* | Price each 1 to 9 |
|--------------|-----|----|----|----|-------------------|--------|-------------------|
| RPC60-31/ML | 60 | 31 | 40 | 12 | 200 | ✓ | 2,50 € |
| RPC80-32/ML | 80 | 32 | 40 | 12 | 250 | ✓ | 2,72 € |
| RPC100-32/ML | 100 | 32 | 40 | 12 | 300 | ✓ | 3,77 € |
| RPC100-35/ML | 100 | 35 | 48 | 15 | 350 | - | 11,29 € |
| RPC125-36/ML | 125 | 36 | 50 | 15 | 350 | - | 6,88 € |
| RPC125-41/ML | 125 | 41 | 59 | 20 | 400 | - | 13,27 € |
| RPC150-37/ML | 150 | 37 | 49 | 15 | 400 | - | 9,96 € |
| RPC160-40/ML | 160 | 40 | 58 | 20 | 500 | - | 27,31 € |
| RPC200-50/ML | 200 | 50 | 58 | 20 | 600 | - | 29,65 € |

*Depending on availability -Dimensions in mm

Polyamide castor with mounting plate Stock

RPCPL For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
Top plate: pressed steel sheet, protected by bright zinc plating
Polyamide wheel **RPC (tome 5 p.51)**
- Working temperature range: - 30°C to + 80°C



Fixed



Swivel

Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors



ØD



B



H



L



Swivel with double brake



M



ØT



ØK

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | L | M | ØT | ØK | Swivel interference | Max. load (kg) | Price each 1 to 9 |
|---------------------------------|-----|----|-----|---------|--------|----|-----|---------------------|----------------|-------------------|
| Fixed | | | | | | | | | | |
| RPC60/PL/F | 60 | 30 | 100 | 110x85 | 80x60 | 8 | - | 200 | - | 8,25 € |
| RPC80/PL/F | 80 | 32 | 109 | 110x85 | 80x60 | 8 | - | 250 | ✓ | 8,06 € |
| RPC100/PL/F | 100 | 32 | 126 | 110x85 | 80x60 | 8 | - | 300 | ✓ | 8,34 € |
| RPC125/PL/F | 125 | 36 | 154 | 110x85 | 80x60 | 8 | - | 350 | - | 13,47 € |
| RPC150/PL/F | 150 | 37 | 182 | 110x85 | 80x60 | 8 | - | 400 | - | 18,38 € |
| RPC160/PL/F | 160 | 40 | 196 | 135x110 | 105x80 | 11 | - | 500 | - | 32,06 € |
| RPC200/PL/F | 200 | 50 | 241 | 135x110 | 105x80 | 11 | - | 600 | - | 37,99 € |
| Swivel | | | | | | | | | | |
| RPC60/PL/P | 60 | 30 | 100 | 110x85 | 80x60 | 8 | 140 | 200 | - | 11,43 € |
| RPC80/PL/P | 80 | 32 | 109 | 110x85 | 80x60 | 8 | 160 | 250 | ✓ | 9,48 € |
| RPC100/PL/P | 100 | 32 | 126 | 110x85 | 80x60 | 8 | 184 | 300 | ✓ | 9,72 € |
| RPC125/PL/P | 125 | 36 | 154 | 110x85 | 80x60 | 8 | 210 | 350 | - | 14,45 € |
| RPC150/PL/P | 150 | 37 | 182 | 110x85 | 80x60 | 8 | 246 | 400 | - | 23,01 € |
| RPC160/PL/P | 160 | 40 | 196 | 135x110 | 105x80 | 11 | 268 | 500 | - | 35,54 € |
| RPC200/PL/P | 200 | 50 | 241 | 135x110 | 105x80 | 11 | 318 | 600 | - | 40,63 € |
| Swivel with double brake | | | | | | | | | | |
| RPC80/PL/PDB | 80 | 32 | 109 | 110x85 | 80x60 | 8 | 290 | 250 | ✓ | 12,49 € |
| RPC100/PL/PDB | 100 | 32 | 126 | 110x85 | 80x60 | 8 | 290 | 300 | ✓ | 13,41 € |
| RPC125/PL/PDB | 125 | 36 | 154 | 110x85 | 80x60 | 8 | 290 | 350 | ✓ | 18,60 € |
| RPC150/PL/PDB | 150 | 37 | 182 | 110x85 | 80x60 | 8 | 290 | 400 | - | 27,97 € |
| RPC160/PL/PDB | 160 | 40 | 196 | 135x110 | 105x80 | 11 | 268 | 500 | - | 39,76 € |
| RPC200/PL/PDB | 200 | 50 | 241 | 135x110 | 105x80 | 11 | 318 | 600 | - | 45,49 € |

*Depending on availability - Dimensions in mm

For heavy loads up to 600kg

RPCTC

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks:
simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
Top plate: pressed steel sheet, protected by bright zinc plating
Polyamide wheel **RPC (tome 5 p.51)**
- Working temperature range: - 30°C to + 80°C




Swivel



Swivel with double brake

Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors

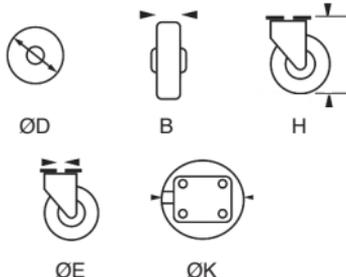

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Max load (kg) | Stock* | Price each 1 to 9 |
|---------------------------------|-----|----|-----|------|------------------------|---------------|--------|-------------------|
| Swivel | | | | | | | | |
| RPC60/TC/P | 60 | 30 | 97 | 12 | 140 | 200 | - | 11,12 € |
| RPC80/TC/P | 80 | 32 | 106 | 12 | 160 | 250 | ✓ | 12,04 € |
| RPC100/TC/P | 100 | 32 | 124 | 12 | 184 | 300 | ✓ | 12,96 € |
| RPC125/TC/P | 125 | 36 | 152 | 12 | 210 | 350 | - | 17,57 € |
| RPC150/TC/P | 150 | 37 | 181 | 12 | 246 | 400 | - | 24,69 € |
| RPC160/TC/P | 160 | 40 | 189 | 12,5 | 268 | 500 | - | 49,94 € |
| RPC200/TC/P | 200 | 50 | 232 | 12,5 | 318 | 600 | - | 57,40 € |
| Swivel with double brake | | | | | | | | |
| RPC80/TC/PDB | 80 | 32 | 106 | 12 | 290 | 250 | ✓ | 17,79 € |
| RPC100/TC/PDB | 100 | 32 | 124 | 12 | 290 | 300 | ✓ | 18,67 € |
| RPC125/TC/PDB | 125 | 36 | 152 | 12 | 290 | 350 | - | 23,74 € |
| RPC150/TC/PDB | 150 | 37 | 181 | 12 | 290 | 400 | - | 31,19 € |
| RPC160/TC/PDB | 160 | 40 | 189 | 12,5 | 268 | 500 | - | 62,99 € |
| RPC200/TC/PDB | 200 | 50 | 232 | 12,5 | 318 | 600 | - | 65,35 € |

*Depending on availability - Dimensions in mm

RPCPLSS

For heavy loads up to 600kg

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
 - Top plate: pressed stainless steel sheet
 - Polyamide wheel **RPC (tome 5 p.51)**
- Working temperature range: - 30°C to + 80°C



Fixed



Swivel

Stainless steel

Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)



ØD



B



H



L



M



ØT



ØK



Swivel with double brake

DISCOUNTS

| Qty | 1+ | 5+ | 15+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | L | M | ØT | Swivel interference ØK | Max load (kg) | Stock* | Price each 1 to 4 |
|---------------------------------|-----|----|-----|---------|--------|------|------------------------|---------------|--------|-------------------|
| Fixed | | | | | | | | | | |
| RPC60/PL/F/SS | 60 | 31 | 96 | 115x83 | 80x60 | 11x9 | - | 200 | - | 20,52 € |
| RPC80/PL/F/SS | 80 | 32 | 105 | 115x83 | 80x60 | 11x9 | - | 250 | ✓ | 21,50 € |
| RPC100/PL/F/SS | 100 | 32 | 124 | 115x83 | 80x60 | 11x9 | - | 300 | ✓ | 22,00 € |
| RPC125/PL/F/SS | 125 | 36 | 152 | 115x83 | 80x60 | 11x9 | - | 350 | - | 29,35 € |
| RPC150/PL/F/SS | 150 | 37 | 179 | 115x83 | 80x60 | 11x9 | - | 400 | - | 57,46 € |
| RPC160/PL/F/SS | 160 | 40 | 197 | 135x105 | 105x80 | 11 | - | 600 | - | 79,45 € |
| RPC200/PL/F/SS | 200 | 50 | 240 | 135x105 | 105x80 | 11 | - | 700 | - | 84,60 € |
| Swivel | | | | | | | | | | |
| RPC60/PL/P/SS | 60 | 31 | 96 | 115x83 | 80x60 | 11x9 | 155 | 200 | - | 30,61 € |
| RPC80/PL/P/SS | 80 | 32 | 105 | 115x83 | 80x60 | 11x9 | 173 | 250 | ✓ | 30,54 € |
| RPC100/PL/P/SS | 100 | 32 | 124 | 115x83 | 80x60 | 11x9 | 193 | 300 | ✓ | 32,77 € |
| RPC125/PL/P/SS | 125 | 36 | 152 | 115x83 | 80x60 | 11x9 | 221 | 350 | - | 38,23 € |
| RPC150/PL/P/SS | 150 | 37 | 179 | 115x83 | 80x60 | 11x9 | 257 | 400 | - | 77,85 € |
| RPC160/PL/P/SS | 160 | 40 | 197 | 135x105 | 105x80 | 11 | 268 | 600 | - | 89,60 € |
| RPC200/PL/P/SS | 200 | 50 | 240 | 135x105 | 105x80 | 11 | 318 | 700 | - | 96,15 € |
| Swivel with double brake | | | | | | | | | | |
| RPC80/PL/PDB/SS | 80 | 32 | 105 | 115x83 | 80x60 | 11x9 | 293 | 250 | ✓ | 39,86 € |
| RPC100/PL/PDB/SS | 100 | 32 | 124 | 115x83 | 80x60 | 11x9 | 293 | 300 | ✓ | 42,01 € |
| RPC125/PL/PDB/SS | 125 | 36 | 152 | 115x83 | 80x60 | 11x9 | 293 | 350 | - | 49,28 € |
| RPC150/PL/PDB/SS | 150 | 37 | 179 | 115x83 | 80x60 | 11x9 | 293 | 400 | - | 100,19 € |
| RPC160/PL/PDB/SS | 160 | 40 | 197 | 135x105 | 105x80 | 11 | 268 | 600 | - | 108,90 € |
| RPC200/PL/PDB/SS | 200 | 50 | 240 | 135x105 | 105x80 | 11 | 318 | 700 | - | 121,62 € |

*Depending on availability - Dimensions in mm

Polyamide castor with central hole, **stainless steel**

RPC TCSS

For heavy loads up to 600kg

- **Industrial wheel suitable for loads up to 600kg**
- Swivel system uses two ball races
- Swivel castor with double locks:
simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
Top plate: pressed stainless steel sheet
Polyamide wheel **RPC (tome 5 p.51)**
- Working temperature range: - 30°C to + 80°C



Swivel

 


Swivel with double brake

Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments
(fish markets, butcher shops, canneries)

Stainless steel



DISCOUNTS

| | | | |
|------------|-----|-----|------------|
| Qty | 1+ | 5+ | 15+ |
| Disc. List | -5% | -5% | On request |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Max load (kg) | Price each 1 to 4 |
|---------------------------------|-----|----|-----|----|---------------------------|---------------|----------------------|
| Swivel | | | | | | | |
| RPC60/TC/P/SS | 60 | 31 | 96 | 12 | 155 | 200 | 29,15 € |
| RPC80/TC/P/SS | 80 | 32 | 109 | 12 | 173 | 250 | 30,54 € |
| RPC100/TC/P/SS | 100 | 32 | 124 | 12 | 193 | 300 | 31,21 € |
| RPC125/TC/P/SS | 125 | 36 | 152 | 12 | 221 | 350 | 38,23 € |
| RPC150/TC/P/SS | 150 | 37 | 179 | 12 | 257 | 400 | 77,85 € |
| RPC160/TC/P/SS | 160 | 40 | 197 | 16 | 268 | 600 | 88,20 € |
| RPC200/TC/P/SS | 200 | 50 | 240 | 16 | 318 | 700 | 94,03 € |
| Swivel with double brake | | | | | | | |
| RPC80/TC/PDB/SS | 80 | 32 | 109 | 12 | 173 | 250 | 39,86 € |
| RPC100/TC/PDB/SS | 100 | 32 | 124 | 12 | 193 | 300 | 42,01 € |
| RPC125/TC/PDB/SS | 125 | 36 | 152 | 12 | 221 | 350 | 49,28 € |
| RPC150/TC/PDB/SS | 150 | 37 | 179 | 12 | 257 | 400 | 100,19 € |
| RPC160/TC/PDB/SS | 160 | 40 | 197 | 16 | 268 | 600 | 107,58 € |
| RPC200/TC/PDB/SS | 200 | 50 | 240 | 16 | 318 | 700 | 120,27 € |

Dimensions in mm

Grey rubber wheel

Stock

RBG

For medium loads up to 120kg

- **Light industrial wheel with a semi-elastic solid rubber tyre**

- **Material:**

85° Shore vulcanised grey rubber tyre

Polypropylene core

- **Smooth central bore**

- **Working temperature range - 20°C to + 60°C**

Advantages

- Soft and silent

- Absorbs shock and vibration

- Will not damage floors



Noise absorbing



Wheel and castor



ØD



B



C



ØA

DISCOUNTS

| | | | |
|------------|-----|------------|-----|
| Qty | 1+ | 10+ | 30+ |
| Disc. List | -5% | On request | |

| Part number | ØD | B | C | ØA | Maximum load (kg) | Stock* | Price each 1 to 9 |
|--------------|-----|----|----|----|-------------------|--------|-------------------|
| RBG50-22/ML | 50 | 22 | 28 | 8 | 40 | ✓ | 1,79 € |
| RBG60-24/ML | 60 | 24 | 28 | 8 | 50 | - | 2,29 € |
| RBG80-23/ML | 80 | 23 | 28 | 8 | 65 | ✓ | 3,61 € |
| RBG100-26/ML | 100 | 26 | 28 | 8 | 75 | ✓ | 4,28 € |
| RBG100-32/ML | 100 | 32 | 34 | 10 | 100 | - | 5,43 € |
| RBG125-32/ML | 125 | 32 | 34 | 10 | 120 | - | 6,71 € |

*Depending on availability - Dimensions in mm

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:

Top plate: pressed steel sheet, protected by bright zinc plating

Grey vulcanized rubber wheel 85°Shore

RBG (tome 5 p.56)

Smooth central bore

- Working temperature range: - 20°C to + 60°C

Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors




Fixed



Swivel



Swivel with double brake

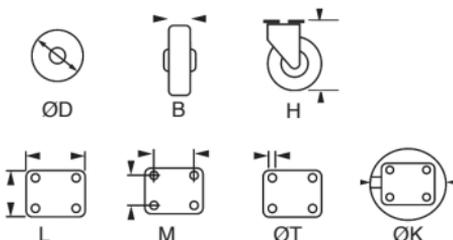

DISCOUNTS

| | | | |
|------------|-----|------------|-----|
| Qty | 1+ | 10+ | 30+ |
| Disc. List | -5% | On request | |

| Part number | ØD | B | H | L | M | ØT | Swivel interference ØK | Max load (kg) | Stock* | Price each 1 to 9 |
|--------------------------------|-----|----|-----|-------|-------|----|------------------------|---------------|--------|-------------------|
| Fixed | | | | | | | | | | |
| RBG50/PL/F | 50 | 22 | 76 | 52x67 | 36x50 | 6 | - | 45 | ✓ | 3,72 € |
| RBG60/PL/F | 60 | 24 | 85 | 52x67 | 36x50 | 6 | - | 55 | ✓ | 3,99 € |
| RBG80/PL/F | 80 | 23 | 106 | 52x67 | 36x50 | 6 | - | 65 | ✓ | 5,21 € |
| RBG100/PL/F | 100 | 26 | 122 | 52x67 | 36x50 | 6 | - | 75 | ✓ | 7,00 € |
| RBG125/PL/F | 125 | 32 | 157 | 68x95 | 44x73 | 8 | - | 110 | ✓ | 13,69 € |
| Swivel | | | | | | | | | | |
| RBG50/PL/P | 50 | 22 | 76 | 48x64 | 36x50 | 6 | 98 | 45 | ✓ | 4,96 € |
| RBG60/PL/P | 60 | 24 | 85 | 48x64 | 36x50 | 6 | 110 | 55 | ✓ | 5,87 € |
| RBG80/PL/P | 80 | 23 | 106 | 48x64 | 36x50 | 6 | 138 | 65 | ✓ | 7,52 € |
| RBG100/PL/P | 100 | 26 | 123 | 48x64 | 36x50 | 6 | 166 | 75 | ✓ | 9,03 € |
| RBG125/PL/P | 125 | 32 | 161 | 70x90 | 50x70 | 8 | 216 | 110 | ✓ | 17,33 € |
| Swivel with double lock | | | | | | | | | | |
| RBG50/PL/PDB | 50 | 22 | 76 | 48x64 | 36x50 | 6 | 172 | 45 | ✓ | 6,90 € |
| RBG60/PL/PDB | 60 | 24 | 85 | 48x64 | 36x50 | 6 | 172 | 55 | ✓ | 7,35 € |
| RBG80/PL/PDB | 80 | 23 | 106 | 48x64 | 36x50 | 6 | 188 | 65 | ✓ | 9,23 € |
| RBG100/PL/PDB | 100 | 26 | 123 | 48x64 | 36x50 | 6 | 188 | 75 | ✓ | 10,78 € |
| RBG125/PL/PDB | 125 | 32 | 161 | 70x90 | 50x70 | 8 | 220 | 110 | ✓ | 19,25 € |

* Depending on availability - Dimensions in mm

Castor with central hole

Stock

RBGTC For medium loads up to 110kg

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:

Top plate: pressed steel sheet, protected by bright zinc plating

Grey vulcanized rubber wheel 85°Shore

RBG (tome 5 p.56)

Smooth central bore

- Working temperature range: - 20°C to + 60°C

Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors



Swivel



Swivel with double brake



ØD



 
B



H



ØE



ØK

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Max load (kg) | Stock* | Price each 1 to 9 |
|--------------------------------|-----|----|-----|----|---------------------------|---------------|--------|----------------------|
| Swivel | | | | | | | | |
| RBG50/TC/P | 50 | 22 | 76 | 10 | 98 | 45 | ✓ | 4,67 € |
| RBG60/TC/P | 60 | 24 | 85 | 10 | 110 | 55 | ✓ | 5,29 € |
| RBG80/TC/P | 80 | 23 | 105 | 10 | 138 | 65 | ✓ | 6,80 € |
| RBG100/TC/P | 100 | 26 | 121 | 10 | 166 | 75 | ✓ | 8,30 € |
| RBG125/TC/P | 125 | 32 | 158 | 13 | 216 | 110 | ✓ | 12,73 € |
| Swivel with double lock | | | | | | | | |
| RBG50/TC/PDB | 50 | 22 | 76 | 10 | 172 | 45 | ✓ | 6,90 € |
| RBG60/TC/PDB | 60 | 24 | 85 | 10 | 172 | 55 | ✓ | 7,14 € |
| RBG80/TC/PDB | 80 | 23 | 105 | 10 | 188 | 65 | ✓ | 8,56 € |
| RBG100/TC/PDB | 100 | 26 | 121 | 10 | 188 | 75 | ✓ | 12,15 € |
| RBG125/TC/PDB | 125 | 32 | 158 | 13 | 220 | 110 | ✓ | 17,81 € |

*Depending on availability -Dimensions in mm

- Industrial castor with a semi-elastic solid rubber tyre
- Material:
 - 85° Shore vulcanised black rubber tyre
 - Polypropylene core
- Smooth central bore
- Working temperature range: - 20°C to + 60°C

Advantages

- Soft and silent
- Absorbs shock and vibration
- Will not damage floors



Noise absorbing



ØD



B



C



ØA

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | ØD | B | C | ØA | Maximum load (kg) | Stock* | Price each 1 to 9 |
|--------------|-----|----|----|----|-------------------|--------|-------------------|
| RBN80-34/ML | 80 | 34 | 40 | 12 | 75 | ✓ | 3,56 € |
| RBN100-35/ML | 100 | 35 | 39 | 12 | 100 | ✓ | 4,20 € |
| RBN125-38/ML | 125 | 38 | 45 | 15 | 125 | ✓ | 6,61 € |
| RBN150-40/ML | 150 | 40 | 45 | 15 | 150 | - | 9,36 € |
| RBN160-38/ML | 160 | 38 | 60 | 20 | 150 | - | 9,76 € |
| RBN200-47/ML | 200 | 47 | 60 | 20 | 215 | - | 12,78 € |

*Depending on availability -Dimensions in mm

Rubber castor with mounting plate Stock

RBNPL

For heavy loads up to 215kg

- Industrial wheel suitable for loads up to 215kg

- Swivel system uses two sets of ball bearings

- Swivel castor with double locks: simple to lock/unlock using foot operated pedal

- Materials:

Baseplate: pressed steel sheet, protected by bright zinc plating

Black vulcanized rubber wheel, 85° Shore

RBN (tome 5 p.65)

- Smooth central bore

- Working temperature range: - 20°C to + 60°C



Fixed



Swivel



Swivel with double brake

Advantages

- Soft, silent wheel

- Absorbs shock

and vibration

- Will not damage floors



ØD



B



H



L



M



ØT



ØK

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | L | M | ØT | ØK | Swivel interference | Max. load (kg) | Price each 1 to 9 |
|--------------------------------|-----|----|-----|---------|--------|----|-----|---------------------|----------------|-------------------|
| Fixed | | | | | | | | | | |
| RBN80/PL/F | 80 | 30 | 109 | 110x85 | 80x60 | 8 | - | 75 | - | 8,53 € |
| RBN100/PL/F | 100 | 35 | 126 | 110x85 | 80x60 | 8 | - | 100 | - | 9,71 € |
| RBN125/PL/F | 125 | 38 | 153 | 110x85 | 80x60 | 8 | - | 125 | - | 13,54 € |
| RBN150/PL/F | 150 | 40 | 180 | 110x85 | 80x60 | 8 | - | 150 | - | 17,36 € |
| RBN160/PL/F | 160 | 38 | 180 | 135x110 | 105x80 | 11 | - | 150 | ✓ | 23,81 € |
| RBN200/PL/F | 200 | 47 | 241 | 135x110 | 105x80 | 11 | - | 215 | - | 31,27 € |
| Swivel | | | | | | | | | | |
| RBN80/PL/P | 80 | 30 | 109 | 110x85 | 80x60 | 8 | 158 | 75 | ✓ | 11,37 € |
| RBN100/PL/P | 100 | 35 | 126 | 110x85 | 80x60 | 8 | 182 | 100 | ✓ | 12,55 € |
| RBN125/PL/P | 125 | 38 | 153 | 110x85 | 80x60 | 8 | 210 | 125 | - | 15,82 € |
| RBN150/PL/P | 150 | 40 | 180 | 110x85 | 80x60 | 8 | 242 | 150 | ✓ | 20,23 € |
| RBN160/PL/P | 160 | 38 | 180 | 135x110 | 105x80 | 11 | 267 | 150 | - | 30,62 € |
| RBN200/PL/P | 200 | 47 | 241 | 135x110 | 105x80 | 11 | 320 | 215 | - | 37,42 € |
| Swivel with double lock | | | | | | | | | | |
| RBN80/PL/PDB | 80 | 30 | 109 | 110x85 | 80x60 | 8 | 290 | 75 | ✓ | 16,98 € |
| RBN100/PL/PDB | 100 | 35 | 126 | 110x85 | 80x60 | 8 | 290 | 100 | - | 18,17 € |
| RBN125/PL/PDB | 125 | 38 | 153 | 110x85 | 80x60 | 8 | 290 | 125 | ✓ | 22,60 € |
| RBN150/PL/PDB | 150 | 40 | 180 | 110x85 | 80x60 | 8 | 290 | 150 | - | 26,41 € |
| RBN160/PL/PDB | 160 | 38 | 180 | 135x110 | 105x80 | 11 | 267 | 150 | - | 39,07 € |
| RBN200/PL/PDB | 200 | 47 | 241 | 135x110 | 105x80 | 11 | 320 | 215 | - | 46,80 € |

*Depending on availability - Dimensions in mm

Rubber castor with central hole

For heavy loads up to 215kg

RBNTC

- Industrial wheel suitable for loads up to 215kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:
 - Baseplate: pressed steel sheet, protected by bright zinc plating
 - Black vulcanized rubber wheel 85°Shore
 - RBN (tome 5 p.65)**
- Smooth central bore
- Working temperature range: - 20°C to + 60°C




Swivel



Swivel with double brake

Advantages

- Soft and silent
- Absorbs shock and vibration
- Will not damage floors

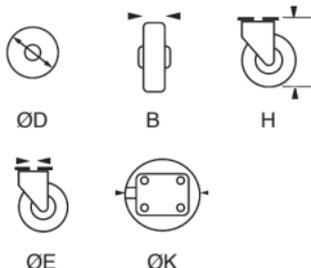

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Maximum load (kg) | Price each 1 to 9 |
|--------------------------------|-----|----|-----|------|------------------------|-------------------|-------------------|
| Swivel | | | | | | | |
| RBN80/TC/P | 80 | 30 | 105 | 12 | 158 | 75 | 11,29 € |
| RBN100/TC/P | 100 | 35 | 125 | 12 | 182 | 100 | 12,45 € |
| RBN125/TC/P | 125 | 38 | 152 | 12 | 210 | 125 | 16,17 € |
| RBN150/TC/P | 150 | 40 | 179 | 12 | 242 | 150 | 20,87 € |
| RBN160/TC/P | 160 | 38 | 188 | 12,5 | 267 | 150 | 29,51 € |
| RBN200/TC/P | 200 | 47 | 232 | 12,5 | 320 | 215 | 35,90 € |
| Swivel with double lock | | | | | | | |
| RBN80/TC/PDB | 80 | 30 | 105 | 12 | 290 | 75 | 17,31 € |
| RBN100/TC/PDB | 100 | 35 | 125 | 12 | 290 | 100 | 18,27 € |
| RBN125/TC/PDB | 125 | 38 | 152 | 12 | 290 | 125 | 22,35 € |
| RBN150/TC/PDB | 150 | 40 | 179 | 12 | 290 | 150 | 28,29 € |
| RBN160/TC/PDB | 160 | 38 | 188 | 12,5 | 267 | 150 | 44,23 € |
| RBN200/TC/PDB | 200 | 47 | 232 | 12,5 | 320 | 215 | 51,19 € |

Dimensions in mm

Free running wheel

Stock

RUR

For loads up to 275kg

- Light industrial wheel for loads up to 275kg
- Ball bearing hub
- Materials:
 - Polyurethane covered wheel 85 Shore
 - Aluminium core
- Working temperature range: -30 to +80°C

For rough floors



Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present



ØD



B



C



ØA

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | B | A | F | Max load (kg) | Stock* | Price each 1 to 9 |
|-------------|-----|----|----|----|---------------|--------|-------------------|
| RUR80 | 80 | 40 | 41 | 12 | 175 | ✓ | 20,58 € |
| RUR100 | 100 | 40 | 41 | 12 | 220 | - | 23,30 € |
| RUR125 | 125 | 38 | 50 | 15 | 250 | - | 26,62 € |
| RUR150 | 150 | 40 | 50 | 20 | 275 | - | 37,75 € |

*Depending on availability -Dimensions in mm

Free running wheel with mounting plate

For loads up to 275kg

RURP

- Light industrial castor for loads up to 275kg
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Hub with ball bearing
- Materials:
 - Top bracket/plate: Plated steel sheet
 - Polyurethane covered wheel 85 Shore
 - Aluminium core, (see RUR tome 5 p.62)
- Working temperature range: -30 to +80°C



Fixed



Swivel

Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present



ØD



B



H



L



M



ØT



ØK

For rough floors



Swivel with double brake

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | ØD | B | H | L | M | ØT | Swivel interference ØK | Max load (kg) | Price each 1 to 9 |
|---------------------------------|-----|----|-----|--------|-------|----|------------------------|---------------|-------------------|
| Fixed | | | | | | | | | |
| RURP80/F | 80 | 40 | 110 | 110x85 | 80x60 | 8 | - | 175 | 31,10 € |
| RURP100/F | 100 | 40 | 127 | 110x85 | 80x60 | 8 | - | 220 | 34,16 € |
| RURP125/F | 125 | 38 | 155 | 110x85 | 80x60 | 8 | - | 250 | 38,38 € |
| RURP150/F | 150 | 40 | 181 | 110x85 | 80x60 | 8 | - | 275 | 49,59 € |
| Swivel | | | | | | | | | |
| RURP80/P | 80 | 40 | 110 | 110x85 | 80x60 | 8 | 162 | 175 | 35,76 € |
| RURP100/P | 100 | 40 | 127 | 110x85 | 80x60 | 8 | 184 | 220 | 39,07 € |
| RURP125/P | 125 | 38 | 155 | 110x85 | 80x60 | 8 | 216 | 250 | 43,74 € |
| RURP150/P | 150 | 40 | 181 | 110x85 | 80x60 | 8 | 244 | 275 | 54,75 € |
| Swivel with double brake | | | | | | | | | |
| RURP80/PDB | 80 | 40 | 110 | 110x85 | 80x60 | 8 | 290 | 175 | 27,46 € |
| RURP100/PDB | 100 | 40 | 127 | 110x85 | 80x60 | 8 | 290 | 220 | 30,33 € |
| RURP125/PDB | 125 | 38 | 155 | 110x85 | 80x60 | 8 | 290 | 250 | 35,01 € |
| RURP150/PDB | 150 | 40 | 181 | 110x85 | 80x60 | 8 | 290 | 275 | 48,92 € |

Dimensions in mm

Free running wheel with central hole

RURT

For loads up to 275kg

- Light industrial castor for loads up to 275kg
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Hub with ball bearing
- Materials:
 - Top bracket/plate: Plated steel sheet
 - Polyurethane covered wheel, 85 Shore
 - Aluminium core (see RUR tome 5 p.62)
- Working temperature range: -30 to +80°C



Swivel



Swivel with double brake

For rough floors

Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present



ØD



B



H



ØE



ØK

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|------------|-----|------------|-----|
| Disc. List | -5% | On request | |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Max load (kg) | Price each 1 to 9 |
|---------------------------------|-----|----|-----|----|------------------------|---------------|-------------------|
| Swivel | | | | | | | |
| RURT80/P | 80 | 40 | 106 | 12 | 162 | 175 | 30,18 € |
| RURT100/P | 100 | 40 | 126 | 12 | 184 | 220 | 32,89 € |
| RURT125/P | 125 | 38 | 153 | 12 | 216 | 250 | 37,38 € |
| RURT150/P | 150 | 40 | 180 | 12 | 244 | 275 | 37,38 € |
| Swivel with double brake | | | | | | | |
| RURT80/PDB | 80 | 40 | 106 | 12 | 290 | 175 | 36,10 € |
| RURT100/PDB | 100 | 40 | 126 | 12 | 290 | 220 | 39,15 € |
| RURT125/PDB | 125 | 38 | 153 | 12 | 290 | 250 | 43,58 € |
| RURT150/PDB | 150 | 40 | 180 | 12 | 290 | 275 | 58,08 € |

Dimensions in mm



High temperature wheel

 
 
 
 
Load up to 200kg

RHT

- Phenolic resin castor wheel
- Slide bearings
- Working temp.: -30°C to +280°C

Advantages

- Large storage capacity
- Resists high temperatures



DISCOUNTS

| | | | |
|-------------|----|-----|------------|
| Qty | 1+ | 5+ | 15+ |
| Disc. Price | | -5% | On request |

| Part number | ØD | B | C | ØA | Load capacity (kg) | Price per unit |
|--------------|-----|----|----|----|--------------------|----------------|
| | | | | | | 1 to 4 |
| RHT80-35/ML | 80 | 35 | 40 | 12 | 125 | 19,39 € |
| RHT100-35/ML | 100 | 35 | 40 | 12 | 150 | 19,63 € |
| RHT125-40/ML | 125 | 40 | 48 | 15 | 200 | 71,40 € |

Dimensions in mm

High Temperature Castors with plate

RHT_{PLSS}

Load up to 200kg

- **High temperature industrial castor**
- Swivel system on 2 crowns of balls
- Double-locking swivel castor:
use the foot pedal to lock and unlock.
- Slide bearings
- Materials:
304 stainless steel sheet
Polyamide wheel **RHT**
(**tome 5 p.65**)
- Working temp.: -30°C to +280°C



Fixed



Swivel



Swivel with double broke

Advantages

- Large storage capacity
- Resists high temperatures



ØD



B



H



L



M



ØT



ØK

DISCOUNTS

| | | | |
|-------------|-----|------------|-----|
| Qty | 1+ | 5+ | 15+ |
| Disc. Price | -5% | On request | |

| Part number | ØD | B | H | L | M | ØT | Swivel interference ØK | Load maximum (kg) | Price per unit 1 to 4 |
|------------------------------|-----|----|-----|--------|-------|------|---------------------------|----------------------|--------------------------|
| Fixed | | | | | | | | | |
| RHT80/PL/F/SS | 80 | 35 | 105 | 115x83 | 80x60 | 11x9 | - | 125 | 37,11 € |
| RHT100/PL/F/SS | 100 | 35 | 126 | 115x83 | 80x60 | 11x9 | - | 150 | 37,82 € |
| RHT125/PL/F/SS | 125 | 40 | 153 | 115x83 | 80x60 | 11x9 | - | 200 | 86,29 € |
| Swivel | | | | | | | | | |
| RHT80/PL/P/SS | 80 | 35 | 105 | 115x83 | 80x60 | 11x9 | 173 | 125 | 46,27 € |
| RHT100/PL/P/SS | 100 | 35 | 126 | 115x83 | 80x60 | 11x9 | 193 | 150 | 47,58 € |
| RHT125/PL/P/SS | 125 | 40 | 153 | 115x83 | 80x60 | 11x9 | 221 | 200 | 96,78 € |
| Double locking swivel | | | | | | | | | |
| RHT80/PL/PDB/SS | 80 | 35 | 105 | 115x83 | 80x60 | 11x9 | 293 | 125 | 55,98 € |
| RHT100/PL/PDB/SS | 100 | 35 | 126 | 115x83 | 80x60 | 11x9 | 293 | 150 | 57,30 € |
| RHT125/PL/PDB/SS | 125 | 40 | 153 | 115x83 | 80x60 | 11x9 | 293 | 200 | 106,49 € |

Dimensions in mm



High Temperature Castor with central hole

Load up to 200kg

RHTTCSS

- High temperature industrial castor
- Swivel system on 2 crowns of balls
- Double-locking swivel castor:
use the foot pedal to lock and unlock.
- Slide bearings
- Materials:
304 stainless steel sheet
Polyamide wheel (see RHT (tome 5 p.65)
Working temp. range: -30°C to +280°C

Advantages

- Large storage capacity
- Resists high temperatures



Swivel



Double locking swivel



ØD



B



H



ØE



ØK

DISCOUNTS

| | | | |
|-------------|-----|-----|------------|
| Qty | 1+ | 5+ | 15+ |
| Disc. Price | -5% | -5% | On request |

| Part number | ØD | B | H | ØE | Swivel interference ØK | Load maximum (kg) | Price per unit 1 to 4 |
|------------------------------|-----|----|-----|----|---------------------------|----------------------|--------------------------|
| Swivel | | | | | | | |
| RHT80/TC/P/SS | 80 | 35 | 105 | 12 | 173 | 125 | 46,27 € |
| RHT100/TC/P/SS | 100 | 35 | 126 | 12 | 193 | 150 | 47,58 € |
| RHT125/TC/P/SS | 125 | 40 | 153 | 12 | 221 | 200 | 96,78 € |
| Double locking swivel | | | | | | | |
| RHT80/PL/P/SS | 80 | 35 | 105 | 12 | 173 | 125 | 55,99 € |
| RHT100/PL/P/SS | 100 | 35 | 126 | 12 | 193 | 150 | 57,30 € |
| RHT125/PL/P/SS | 125 | 40 | 153 | 12 | 221 | 200 | 106,49 € |

Dimensions in mm

Stem support for caster

New

TSRTC For swivel caster with central hole

- Threaded stem for swivel castor with central hole

- Material:

Stem: Stainless steel 304

Washer: Stainless steel 304


Mounting

- Pass the $\varnothing F$ thread through the center hole of the castor plate and secure with a washer and a M12 lock nut (not supplied)
- If necessary, the length A can be shortened by yourself.
- The protection of the caster can be improved with the stainless steel protective washer **TSR-ROND**


Accessories

- Swivel castor with central hole **RPC/TC** Tome 5 (p. 53), **RBN/TC** 5 (p. 61), **RHT/TC** 5 (p. 67) et **RURT** 5 (p. 64)

Example of assembly with protective washer

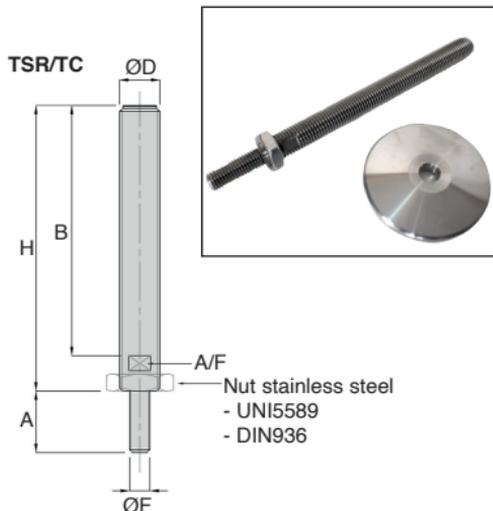

TSR-ROND

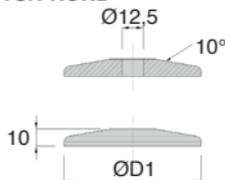

DISCOUNTS

| Qty | 1+ | 10+ | 30+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØD | ØF | A | B | H | A/F | ØD1 | Price each |
|--------------------------|---------|----------|----|-----|-----|-----|-----|------------|
| | | | | | | | | 1 to 9 |
| Threaded stem | | | | | | | | |
| TSR16-150/TC/SS | M16x2 | M12x1,75 | 37 | 150 | 171 | 13 | - | 18,69 € |
| TSR16-200/TC/SS | M16x2 | M12x1,75 | 37 | 200 | 221 | 13 | - | 22,21 € |
| TSR20-150/TC/SS | M20x2,5 | M12x1,75 | 37 | 150 | 172 | 17 | - | 24,74 € |
| TSR20-200/TC/SS | M20x2,5 | M12x1,75 | 37 | 200 | 222 | 17 | - | 30,30 € |
| TSR24-150/TC/SS | M24x3 | M12x1,75 | 37 | 150 | 172 | 20 | - | 32,31 € |
| TSR24-200/TC/SS | M24x3 | M12x1,75 | 37 | 200 | 222 | 20 | - | 39,89 € |
| Protective washer | | | | | | | | |
| TSR-ROND12-60/SS | - | - | - | - | - | - | 60 | 14,84 € |
| TSR-ROND12-80/SS | - | - | - | - | - | - | 80 | 19,79 € |

Dimensions in mm

Retractable castor for aluminum section

Load up to 200kg

RESC



- Retractable castor with foot, allowing easy transition from a rolling position to a fixed position.
- Materials:
 - Black PU tread
 - Wheel centre PA grey sim. RAL7001
 - Die-cast aluminium base plate
 - Steel wheel support

Advantages

- Allows the wheel to be shifted effortlessly into a fixed position thanks to the lever arm.
- Standing position more stable than a caster with brake.
- Prevents deformation of the tread under prolonged load.
- Can be mounted with the aluminium section in several different combinations.

Accessories

- Compatible with sections that have a width of 45mm PRF4545 and 90mm PRF4590 (tome 5 p.299)
- Compatible with section widths measuring 40mm, 80mm and 90mm
- CHC8-40/SS/B screw (tome 1 p.559)
- PRF-ECL-M8 nut (tome 5 p.315)

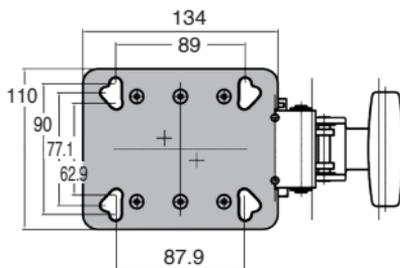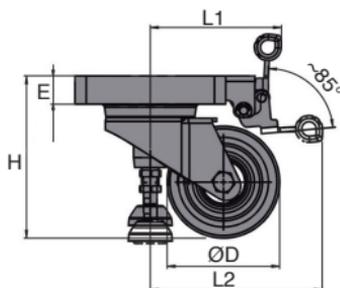

Application examples

DISCOUNTS

| | | | |
|-------|-------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | Price | -5% | On request |

| Part number | ØD | E | H | L1 | L2 | Max load (N) | Weight (kg) | Price per unit 1 to 9 |
|-------------|-----|------|-----|-----|-----|--------------|-------------|-----------------------|
| RESC80-125 | 80 | 25.3 | 125 | 117 | 153 | 1500 | 1.64 | 192.56 € |
| RESC100-145 | 100 | 25.3 | 145 | 117 | 153 | 2000 | 1.94 | 195.13 € |

Dimensions in mm

Locking castor with central hole



RIM

For loads up to 1000kg

 

- A combination of a swivel castor and an adjustable locking support
- Used to easily support and moving machines or other heavy equipment and then positioning them in a very stable manner.
- Installation starts by lowering the locking support using a nut.
- With the wheel no longer resting on the ground, the supported unit can be levelled despite any irregularities in the floor.
- Operating temperature range: -30 to +80°C

Materials

- Polyamide central control cross nut
- Anti-skid rubber mount allowing absorption of vibration and noise
- Body: Moulded cast aluminium body, hammered ivory paint finish
- Swivel system provided by 2 ball rings
- Mounting plate has a threaded central hole, threaded rod and nut supplied.
- Wheel: Black polyamide Shore D 70



Adjusting nut

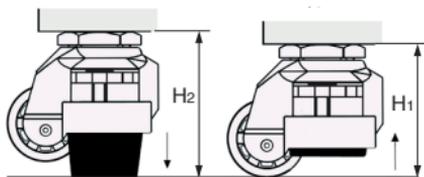

DISCOUNTS

| Qty | 1+ | 5+ | 14+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | ØA | B | H1 | H2 | ØT | ØK | Swivel interference | Load (kg) | Price each 1 to 4 |
|----------------|----|----|-----|-----|-----|-----|---------------------|-----------|-------------------|
| RIM42-60/TCE | 42 | 20 | 71 | 81 | M8 | 84 | | 60 | 43,46 € |
| RIM50-280/TCE | 50 | 25 | 82 | 92 | M12 | 101 | | 280 | 69,03 € |
| RIM63-550/TCE | 63 | 28 | 103 | 118 | M12 | 125 | | 550 | 93,81 € |
| RIM75-800/TCE | 75 | 30 | 120 | 132 | M16 | 142 | | 800 | 126,19 € |
| RIM75-1000/TCE | 75 | 30 | 120 | 132 | M16 | 142 | | 1000 | 123,65 € |

Dimensions in mm

Locking castor with mounting plate

For loads up to 1000kg

RIM

 

- A combination of a swivel castor and an adjustable locking support
- Used to easily support and moving machines or other heavy equipment and then positioning them in a very stable manner.
- Installation starts by lowering the locking support using a nut.
- With the wheel no longer resting on the ground, the supported unit can be levelled despite any irregularities in the floor.
- Operating temperature range: -30 to +80°C



Adjusting nut

Materials

- Polyamide central control cross nut
- Anti-skid rubber mount allowing absorption of vibration and noise
- Body: Moulded cast aluminium body, hammered ivory paint finish
- Swivel system provided by 2 ball rings
- Mounting plate square
- Wheel: Black polyamide Shore D 70

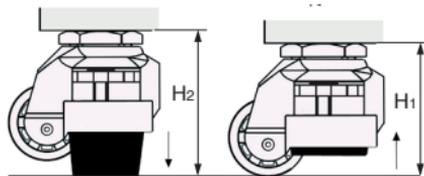

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 5+ | 14+ |
| Disc. | List | -5% | On request |

| Part number | ØA | B | H1 | H2 | L | M | ØT | Swivel interference ØK | Load (kg) | Price each 1 to 4 |
|----------------|----|----|-----|-----|-------|-------|-----|---------------------------|-----------|----------------------|
| RIM42-60/PLE | 42 | 20 | 71 | 81 | 55x55 | 42x42 | 6,5 | 84 | 60 | 43,46 € |
| RIM50-280/PLE | 50 | 25 | 82 | 92 | 73x73 | 58x58 | 7 | 101 | 280 | 69,03 € |
| RIM63-550/PLE | 63 | 28 | 103 | 118 | 90x90 | 70x70 | 9 | 125 | 550 | 93,81 € |
| RIM75-800/PLE | 75 | 30 | 120 | 132 | 95x95 | 70x70 | 11 | 142 | 800 | 126,19 € |
| RIM75-1000/PLE | 75 | 30 | 120 | 132 | 95x95 | 70x70 | 11 | 142 | 1000 | 123,65 € |

Dimensions in mm