

# Polyamide castor with central hole, stainless steel


For heavy loads up to 600kg

RPC TCSS

- Industrial wheel suitable for loads up to 600kg
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Smooth central bore
- Materials:
  - Top plate: pressed stainless steel sheet
  - Polyamide wheel (see RPC)
  - Working temperature range: - 30°C to + 80°C

## Advantages

- Light
- Will not mark or stain floor
- Low rolling resistance
- For solid, hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)

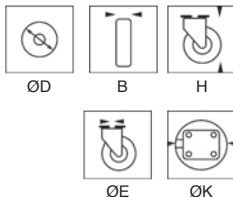

## DISCOUNTS

Qty	1+	5+	15+
Disc.	List	-5%	On request

Part number	ØD	B	H	ØE	Swivel interference	Max load (kg)	Price each 1 to 9
<b>Swivel</b>							
RPC60/TC/P/SS	60	31	96	12	155	200	25,19 €
RPC80/TC/P/SS	80	32	109	12	173	250	25,19 €
RPC100/TC/P/SS	100	32	124	12	193	300	26,97 €
RPC125/TC/P/SS	125	36	152	12	221	350	31,46 €
RPC150/TC/P/SS	150	37	179	12	257	400	55,84 €
RPC160/TC/P/SS	160	40	197	12,5	268	600	72,57 €
RPC200/TC/P/SS	200	50	240	12,5	318	700	77,38 €
<b>Swivel with double brake</b>							
RPC80/TC/PDB/SS	80	32	109	12	173	250	34,45 €
RPC100/TC/PDB/SS	100	32	124	12	193	300	36,30 €
RPC125/TC/PDB/SS	125	36	152	12	221	350	38,70 €
RPC150/TC/PDB/SS	150	37	179	12	257	400	75,28 €
RPC160/TC/PDB/SS	160	40	197	12,5	268	600	88,52 €
RPC200/TC/PDB/SS	200	50	240	12,5	318	700	98,97 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

269

## Our other products



NK40

Drylin®N miniature guiding system, Width 40 mm




CHAR

Spring hinge, screwed



CHAK

Hi-Klik™ indent hinge, Hi-Klik™ - Detent hinge

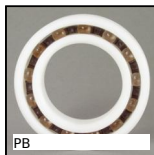

PB

Plastic deep groove ball bearing, Plastic - glass balls material




HTD14M\_85

HTD Heavy duty timing pulley, HTD14 Steel



ES

Bipod support base, Plastic

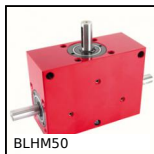

BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



SEH

Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...



AFM

Flanged polymer bush, Food grade




NCT

Square tube connector, Fixed



T5-10ECO

T type timing pulley, Economy range - T5

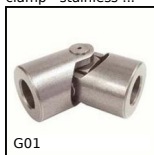

G01

Single universal joint, Normal duty

## Complementary products



TSRTC

Stem support for caster, For swivel caster with central hole



RPC

Wheel, Polyamide



RBGtc

Swivel caster with central hole, Steel - grey rubber



RBNtc

Swivel caster with central hole, Steel - rubber