

# Connecting plate

Pitch

RPP5

RPP8

RPP14

For open belts RPP5M, RPP8M  
and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material :  
aluminium



## Applications

- For closing an open belt
- To attach an open belt to a structure


## Accessories

- RPP../P belts
- HTD pulleys

Until  
**-40%\*\***

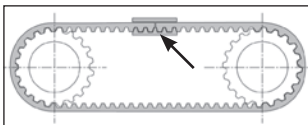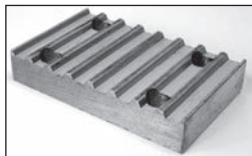

Typical application

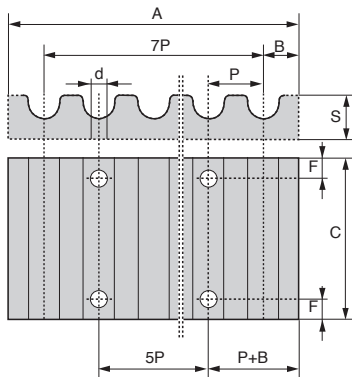

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request


Part number	Pas	F	d	B	A	S	C	Belt width	Stock*	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	✓	12,33 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	✓	12,84 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	-	20,86 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	✓	22,14 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	✓	24,55 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	-	56,78 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	-	64,91 €

\*Depending on availability - Dimensions in mm

## Our other products



 PM4  
Worm and wheel set,  
Bronze



M1  
Worm and wheel set,  
Machined plastic  
(delrin)




PF60  
Worm and wheel gear  
reducer, up to 118  
Nm



RBG  
Wheel, Grey rubber -  
Polypropylene rim



 DOMI30  
Accessories, Plate



CDRs  
Retaining cable for  
ball pin, Retaining  
cable



AC156-157  
Strike for toggle latch,  
25.5mm




BLHB40  
Right angled gearbox,  
bored shafts, up to  
10.3 Nm



CHAR5050\_Z  
Spring hinge, screwed



 PLB  
Cylindrical spacer,  
Brass




RPP  
Connecting plate for  
RPP type timing belts,



DOMI120  
Accessories, Turntable

## Complementary products

 

RPPM  
RPP type belt per  
metre, RPP8 Steel  
cored polyurethane