

Connecting plate

Pitch

RPP5

RPP8

RPP14

For open belts RPP5M, RPP8M and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium



Applications

- For closing an open belt
- To attach an open belt to a structure


Accessories

- RPP../P belts
- HTD pulleys

Until
-40%**

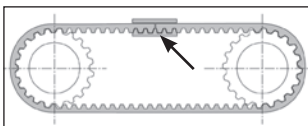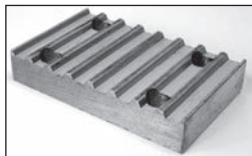

Typical application

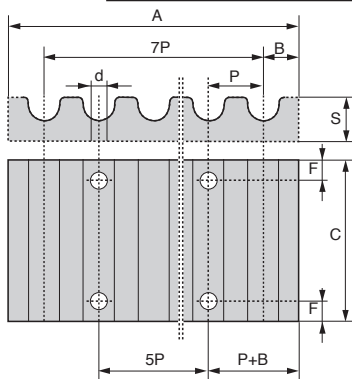

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pas	F	d	B	A	S	C	Belt width	Stock*	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	✓	12,33 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	✓	12,84 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	-	20,86 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	✓	22,14 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	✓	24,55 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	-	56,78 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	-	64,91 €

*Depending on availability - Dimensions in mm

Our other products



ACLALF
Adjustable foot for aluminium profile, Ideal for workstations



VAP
Magnetic stud with central hole, With central hole




BPHT
Ball transfer unit bolt fitting, Heavy



SUA4
Single chain supplied by the metre, Steel



 FGWA
End support, With base



AC
Strike for toggle latch, 15mm



RURp
Swivel castor with double brake, Polyurethane - Aluminium rim (Free



CHINV
Invisible hinge, Invisible - 90° opening



RTT
Locking Assembly, Medium/high torque



BMM
Knurled knob - male, Knurled




EBM
Steel U bolt, Steel



RLXAC8
Free roller, Steel

 Complementary products



RPPM
RPP type belt per metre, RPP8 Steel cored polyurethane