

Connecting plate

Pitch

RPP5

RPP8

RPP14

For open belts RPP5M, RPP8M
and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material :
aluminium



Applications

- For closing an open belt
- To attach an open belt to a structure


Accessories

- RPP../P belts
- HTD pulleys

Until
-40%**

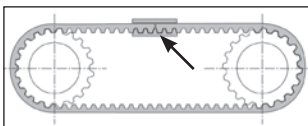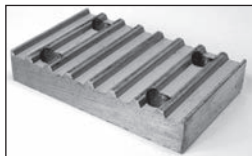

Typical application

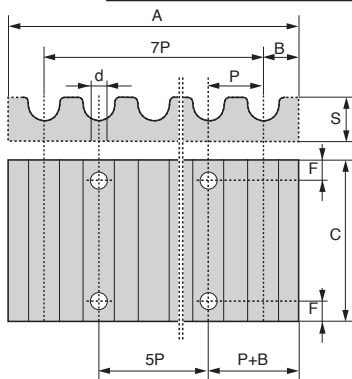

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pas	F	d	B	A	S	C	Belt width	Stock*	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	✓	12,33 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	✓	12,84 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	-	20,86 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	✓	22,14 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	✓	24,55 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	-	56,78 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	-	64,91 €

*Depending on availability - Dimensions in mm

Our other products



Magnetic label holder for aluminium profile, Label holder



Parallel axis helical gear, Steel 20NCD2



Connecting kits, XZ linking kit



Tool for thread repair inserts, Assembly tool



Stainless steel closed precision linear bearing, Precision - stainle...



Adjusting rod for clamp - Male, Threaded



Single and dual output gearboxes, Up to 28,8 Nm



Sealed flange bearing unit for Food Industry, cover



AT type tooth bar stock, AT10



Machined plastic bevel gear , 2:1

 


Actuator guide kit, Short bearing



Precision locknut, Precision locknut

Complementary products



RPP type belt per metre, RPP8 Steel cored polyurethane