

# RPP timing belt

Size **XS** Stock

## Pitch RPP3

## Chloroprene rubber belt with glass fibre tension members

 
- To be used with HTD3M-09F pulley
- Pitch 3mm
- Efficiency: up to 98%
- Materials:  
chloroprene rubber reinforced with glass fibres  
nylon protective film

### Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- Pulleys HTD3M
- Belt tension rollers GTC



### DISCOUNTS

Qty	1+	6+	20+
Disc. List	-7%	On request	

Part number	Length	No. of teeth	Stock*	Price each 1 to 5 for 9mm width
RPP3/90	90	30	✓	5,33 €
RPP3/105	105	35	✓	5,51 €
RPP3/129	129	43	✓	5,69 €
RPP3/141	141	47	-	5,87 €
RPP3/144	144	48	✓	5,87 €
RPP3/147	147	49	✓	5,87 €
RPP3/150	150	50	✓	5,87 €
RPP3/159	159	53	✓	5,87 €
RPP3/168	168	56	✓	5,87 €
RPP3/174	174	58	✓	6,04 €
RPP3/177	177	59	✓	6,04 €
RPP3/180	180	60	✓	6,04 €
RPP3/186	186	62	✓	6,04 €
RPP3/195	195	65	✓	6,04 €
RPP3/201	201	67	✓	6,20 €
RPP3/204	204	68	✓	6,20 €
RPP3/210	210	70	✓	6,20 €
RPP3/213	213	71	✓	6,20 €
RPP3/225	225	75	✓	6,20 €
RPP3/231	231	77	✓	6,20 €
RPP3/240	240	80	✓	6,40 €
RPP3/243	243	81	✓	6,40 €
RPP3/246	246	82	✓	6,40 €
RPP3/249	249	83	✓	6,40 €
RPP3/252	252	84	✓	6,40 €

\*Depending on availability - Dimensions in mm

Part number	Length	No. of teeth	Stock*	Price each 1 to 5 for 9mm width
RPP/255	255	85	✓	6,40 €
RPP3/261	261	87	✓	6,40 €
RPP3/264	264	88	✓	6,40 €
RPP3/267	267	89	-	6,40 €
RPP3/270	270	90	✓	6,40 €
RPP3/276	276	92	✓	6,40 €
RPP3/285	285	95	✓	6,40 €
RPP3/288	288	96	✓	6,55 €
RPP3/291	291	97	✓	6,55 €
RPP3/297	297	99	✓	6,55 €
RPP3/300	300	100	✓	6,55 €
RPP3/312	312	104	✓	6,88 €
RPP3/318	318	106	✓	6,88 €
RPP3/327	327	109	-	6,88 €
RPP3/330	330	110	✓	6,88 €
RPP3/333	333	111	✓	6,88 €
RPP3/336	336	112	-	6,88 €
RPP3/339	339	113	✓	6,88 €
RPP3/345	345	115	✓	6,88 €
RPP3/357	357	119	✓	6,88 €
RPP3/363	363	121	-	7,05 €
RPP3/375	375	125	-	7,05 €
RPP3/384	384	128	✓	7,05 €
RPP3/390	390	130	-	7,29 €
RPP3/393	393	131	✓	7,29 €
RPP3/405	405	135	✓	7,29 €
RPP3/420	420	140	✓	7,29 €
RPP3/432	432	144	✓	7,42 €
RPP3/447	447	149	✓	7,42 €
RPP3/474	474	158	✓	7,60 €
RPP3/480	480	160	-	7,60 €
RPP3/486	486	162	-	7,78 €
RPP3/489	489	163	-	7,78 €
RPP3/501	501	167	-	7,78 €
RPP3/510	510	170	-	7,78 €
RPP3/513	513	171	-	7,78 €
RPP3/522	522	174	✓	7,92 €
RPP3/531	531	177	-	7,92 €
RPP3/537	537	179	-	7,92 €
RPP3/564	564	188	-	8,14 €
RPP3/570	570	190	✓	8,27 €
RPP3/576	576	192	-	8,27 €
RPP3/579	579	193	-	8,27 €
RPP3/597	597	199	✓	8,47 €
RPP3/600	600	200	✓	8,47 €
RPP3/633	633	211	✓	8,47 €
RPP3/648	648	216	-	8,63 €
RPP3/669	669	223	✓	8,79 €

\*Depending on availability - Dimensions in mm

# RPP timing belt

Size **XS** Stock

## Pitch RPP3

## Chloroprene rubber belt with glass fibre tension members


- To be used with HTD3M-09F pulley
- Pitch 3mm
- Efficiency: up to 98%
- Materials:  
Chloroprene rubber reinforced with glass fibres  
nylon protective film

### Advantages

- **Shock-resistant**
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- Pulleys HTD3M
- Belt tension rollers GTC

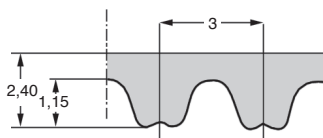

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Stock*	Price each. 1 to 5 for 9mm width
RPP3/711	711	237	✓	9,66 €
RPP3/735	735	245	-	10,02 €
RPP3/738	738	246	-	10,23 €
RPP3/756	756	252	-	10,37 €
RPP3/804	804	268	-	10,77 €
RPP3/882	882	294	✓	10,95 €
RPP3/945	945	315	✓	11,17 €
RPP3/1062	1062	354	✓	11,36 €
RPP3/1125	1125	373	✓	11,73 €
RPP3/1245	1245	415	✓	12,46 €
RPP3/1263	1263	421	✓	12,46 €
RPP3/1500	1500	500	✓	14,13 €
RPP3/1530	1530	510	-	14,13 €
RPP3/1863	1863	621	✓	15,65 €