

RPP timing belt

Stock

Pitch RPP8

Chloroprene rubber belt with glass fibre tension members

- To be used with HTD8M pulley
- Pitch 8mm
- Efficiency: up to 98%
- Materials:
Chloroprene rubber reinforced with glass fibres
nylon protective film



Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

Accessories

- Pulleys HTD8
- Belt tension rollers GTC


DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	N. of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			20mm	30mm	20mm	30mm	50mm
RPP8/288	288	36	-	-	10,23 €	15,83 €	26,85 €
RPP8/320	320	40	-	-	10,95 €	17,11 €	28,50 €
RPP8/352	352	44	-	-	11,73 €	18,24 €	30,72 €
RPP8/360	360	45	-	-	12,09 €	18,63 €	31,69 €
RPP8/384	384	48	✓	-	12,85 €	19,92 €	33,70 €
RPP8/408	408	51	-	✓	13,79 €	21,22 €	35,96 €
RPP8/456	456	57	-	-	15,65 €	24,01 €	40,66 €
RPP8/480	480	60	-	✓	16,39 €	25,33 €	42,89 €
RPP8/536	536	67	✓	-	17,70 €	27,01 €	45,29 €
RPP8/544	544	68	-	-	18,63 €	28,32 €	47,72 €
RPP8/560	560	70	✓	-	18,78 €	28,72 €	48,65 €
RPP8/600	600	75	-	✓	19,56 €	29,45 €	49,78 €
RPP8/608	608	76	-	-	19,71 €	29,83 €	50,52 €
RPP8/632	632	79	✓	-	19,92 €	29,99 €	51,45 €
RPP8/640	640	80	-	-	20,50 €	30,96 €	52,57 €
RPP8/680	680	85	-	-	20,91 €	31,69 €	53,91 €
RPP8/720	720	90	✓	✓	22,16 €	33,57 €	56,88 €
RPP8/800	800	100	-	✓	23,45 €	35,96 €	61,18 €
RPP8/840	840	105	✓	✓	24,41 €	37,12 €	62,89 €
RPP8/880	880	110	-	-	24,99 €	38,05 €	64,16 €
RPP8/896	896	112	-	-	25,15 €	38,25 €	65,09 €
RPP8/920	920	115	-	-	25,89 €	39,32 €	66,79 €
RPP8/960	960	120	✓	-	26,85 €	40,66 €	69,01 €

*Depending on availability - Dimensions in mm

Pitch RPP8

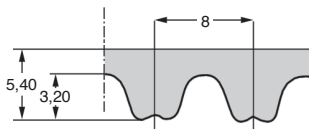

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	N. of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			20mm	30mm	20mm	30mm	50mm
RPP8/1000	1000	125	-	-	27,77 €	41,76 €	71,07 €
RPP8/1040	1040	130	-	✓	28,86 €	43,44 €	73,85 €
RPP8/1080	1080	135	-	-	29,63 €	44,75 €	76,28 €
RPP8/1120	1120	140	✓	-	30,37 €	46,22 €	78,50 €
RPP8/1200	1200	150	✓	-	32,23 €	48,65 €	82,46 €
RPP8/1224	1224	153	-	-	32,84 €	49,61 €	84,15 €
RPP8/1280	1280	160	✓	-	33,93 €	51,45 €	86,91 €
RPP8/1352	1352	169	✓	-	34,48 €	52,42 €	88,79 €
RPP8/1424	1424	178	-	-	36,21 €	55,70 €	92,68 €
RPP8/1440	1440	180	✓	✓	36,73 €	55,94 €	94,77 €
RPP8/1464	1464	183	-	-	38,39 €	58,38 €	98,51 €
RPP8/1600	1600	200	✓	-	40,10 €	60,45 €	102,81 €
RPP8/1680	1680	210	-	-	41,57 €	63,03 €	106,90 €
RPP8/1760	1760	220	-	-	43,09 €	65,69 €	111,00 €
RPP8/1800	1800	225	-	-	44,01 €	66,79 €	113,46 €
RPP8/2000	2000	250	-	-	48,65 €	73,69 €	124,45 €
RPP8/2200	2200	275	-	-	52,78 €	79,85 €	135,26 €
RPP8/2272	2272	284	-	-	54,52 €	81,65 €	138,58 €
RPP8/2400	2400	300	-	-	57,07 €	86,36 €	146,09 €
RPP8/2520	2520	315	-	-	58,59 €	88,79 €	150,37 €
RPP8/2600	2600	325	-	-	60,45 €	91,59 €	155,26 €
RPP8/2800	2800	350	-	-	65,28 €	98,51 €	167,19 €
RPP8/3048	3048	381	-	-	76,28 €	116,23 €	195,17 €
RPP8/3280	3280	410	-	-	82,06 €	124,85 €	209,55 €
RPP8/3600	3600	450	-	-	90,12 €	136,79 €	230,86 €
RPP8/4400	4400	550	-	-	109,93 €	167,19 €	282,36 €

*Depending on availability - Dimensions in mm