

RPP type belt by **the metre**



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories



- RPP.../P connecting plates
- HTD pulleys

Info.

- Minimum length 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and width (I) to the part number (**RPP5M/L/I**)
- E.g. : **RPP5M/1000/15**

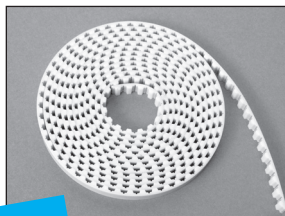

For linear positioning

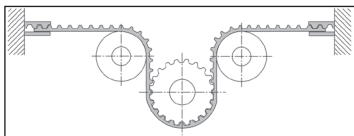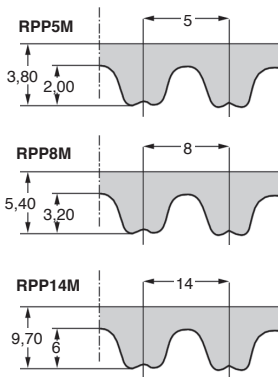

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

 
Dimensions in mm

Our other products



PRF-SCREEN-1

Screen support, Basic support



M1

Worm and wheel set, Bronze



G0

Steel spur gear, Steel 20NCD2




CSSSS

Stainless steel spherical bearing, Stainless steel / PTFE



GAL_20

 Conveyor roller for $\varnothing 20$ mm spindle, Self-lubricating polyamide



T0

Torsion spring, Stainless steel



PARF80

Pressed steel base rigid foot, Swivelling - $\varnothing 80$



SSDB

Stainless steel bevel gear, 2:1



RTTss

Locking assembly, Medium/high torque




SLH-M

Nut for toggle clamp, Round ended nut for



NT122

Spur gear coaxial gearbox, from 32 to

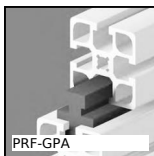

PRF-GPA

 
Guide for aluminium profile, Parallel rails

Complementary products



RPP

Connecting plate for RPP type timing belts, RRP5



RPP3

RPP heavy duty timing belt, RPP3