

## Chloroprene rubber belt with glass fibre tension members

# Pitch RPP3


- To be used with HTD3M-09F pulley
- Pitch 3mm
- Efficiency: up to 98%
- Materials: chloroprene rubber reinforced with glass fibres nylon protective film

### Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- HTD3M-09F pulleys (tome 4 p.14)
- GTC belt tension roller (tome 4 p.146)

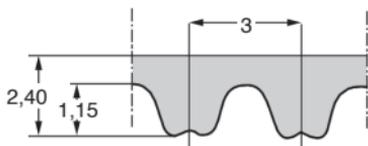

### DISCOUNTS

Qty	1+	6+	20+
Disc. List		-7%	On request

Part number	Length	N° of teeth	Stock*	Price each 1 to 5 for 9mm width
RPP3/90	90	30	✓	7,70 €
RPP3/105	105	35	✓	7,95 €
RPP3/129	129	43	✓	8,22 €
RPP3/141	141	47	✓	8,49 €
RPP3/144	144	48	-	8,49 €
RPP3/147	147	49	-	8,49 €
RPP3/150	150	50	✓	8,49 €
RPP3/159	159	53	✓	8,49 €
RPP3/168	168	56	✓	8,49 €
RPP3/174	174	58	✓	8,71 €
RPP3/177	177	59	-	8,71 €
RPP3/180	180	60	✓	8,71 €
RPP3/186	186	62	✓	8,71 €
RPP3/195	195	65	✓	8,71 €
RPP3/201	201	67	✓	8,96 €
RPP3/204	204	68	-	8,96 €
RPP3/210	210	70	✓	8,96 €
RPP3/213	213	71	✓	8,96 €
RPP3/225	225	75	✓	8,96 €
RPP3/231	231	77	✓	8,96 €
RPP3/240	240	80	✓	9,24 €
RPP3/243	243	81	-	9,24 €
RPP3/246	246	82	-	9,24 €
RPP3/249	249	83	✓	9,24 €
RPP3/252	252	84	✓	9,24 €

\*Depending on availability - Dimensions in mm

# RPP timing belt

Size **XS** Stock

## Pitch RPP3

## Chloroprene rubber belt with glass fibre tension members


- To be used with HTD3M-09F pulley
- Pitch 3mm
- Efficiency: up to 98%
- Materials:  
Chloroprene rubber reinforced with glass fibres  
nylon protective film

### Advantages

- **Shock-resistant**
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- HTD3M-09F pulleys (tome 4 p.14)
- GTC belt tension roller (tome 4 p.146)

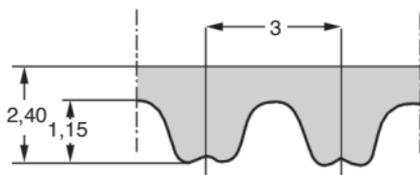

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	N° of teeth	Stock*	Price each. 1 to 5 for 9mm width
RPP3/255	255	85	-	9,24 €
RPP3/261	261	87	✓	9,24 €
RPP3/264	264	88	✓	9,24 €
RPP3/267	267	89	-	9,24 €
RPP3/270	270	90	✓	9,24 €
RPP3/276	276	92	✓	9,24 €
RPP3/285	285	95	✓	9,24 €
RPP3/288	288	96	✓	9,47 €
RPP3/291	291	97	✓	9,47 €
RPP3/297	297	99	✓	9,47 €
RPP3/300	300	100	✓	9,47 €
RPP3/312	312	104	✓	9,93 €
RPP3/318	318	106	-	9,93 €
RPP3/327	327	109	✓	9,93 €

\*Depending on availability - Dimensions in mm

Part number	Length	N° of teeth	Stock*	Price each. 1 to 5 for 9mm width
RPP3/330	330	110	✓	9,93 €
RPP3/333	333	111	✓	9,93 €
RPP3/336	336	112	-	9,93 €
RPP3/339	339	113	✓	9,93 €
RPP3/345	345	115	✓	9,93 €
RPP3/357	357	119	✓	9,93 €
RPP3/363	363	121	-	10,19 €
RPP3/375	375	125	✓	10,19 €
RPP3/384	384	128	✓	10,19 €
RPP3/390	390	130	-	10,52 €
RPP3/393	393	131	✓	10,52 €
RPP3/405	405	135	✓	10,52 €
RPP3/420	420	140	✓	10,52 €
RPP3/432	432	144	✓	10,72 €
RPP3/447	447	149	✓	10,72 €
RPP3/474	474	158	✓	10,99 €
RPP3/480	480	160	-	10,99 €
RPP3/486	486	162	-	11,26 €
RPP3/489	489	163	-	11,26 €
RPP3/501	501	167	-	11,26 €
RPP3/510	510	170	-	11,26 €
RPP3/513	513	171	-	11,26 €
RPP3/522	522	174	✓	11,44 €
RPP3/531	531	177	-	11,44 €
RPP3/537	537	179	-	11,44 €
RPP3/564	564	188	-	11,77 €
RPP3/570	570	190	✓	11,95 €
RPP3/576	576	192	-	11,95 €
RPP3/579	579	193	-	11,95 €
RPP3/597	597	199	-	12,25 €
RPP3/600	600	200	-	12,25 €
RPP3/633	633	211	✓	12,25 €
RPP3/648	648	216	-	12,47 €
RPP3/669	669	223	✓	12,72 €
RPP3/711	711	237	✓	13,00 €
RPP3/735	735	245	-	13,47 €
RPP3/738	738	246	-	13,76 €
RPP3/756	756	252	-	13,96 €
RPP3/804	804	268	-	14,46 €
RPP3/882	882	294	✓	14,75 €
RPP3/945	945	315	✓	15,02 €
RPP3/1062	1062	354	✓	15,27 €
RPP3/1125	1125	373	✓	15,77 €
RPP3/1245	1245	415	-	16,77 €
RPP3/1263	1263	421	-	16,77 €
RPP3/1500	1500	500	✓	19,02 €
RPP3/1530	1530	510	-	19,02 €
RPP3/1863	1863	621	✓	21,06 €

\*Depending on availability - Dimensions in mm

# RPP timing belt



## Pitch RPP5

## Chloroprene rubber belt with glass fibre tension members


- To be used with HTD5M pulley
- Pitch 5mm
- Efficiency: up to 98%
- Materials:  
Chloroprene rubber reinforced with glass fibres  
nylon protective film

### Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- HTD5M pulleys (tome 4 p.15)
- GTC belt tension rollers (tome 4 p.146)

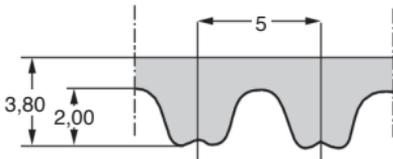

### DISCOUNTS

Qty	1+	6+	20+
Disc. List	-7%	-7%	On request

Part number	Length	N° of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			9mm	15mm	9mm	15mm	25mm
RPP5/180	180	36	✓	✓	9,73 €	16,01 €	-
RPP5/225	225	45	✓	✓	9,93 €	16,01 €	-
RPP5/235	235	47	✓	-	9,93 €	16,26 €	23,32 €
RPP5/245	245	49	✓	-	10,19 €	16,26 €	23,32 €
RPP5/255	255	51	✓	-	10,52 €	16,54 €	24,55 €
RPP5/265	265	53	-	-	10,52 €	16,54 €	25,25 €
RPP5/270	270	54	✓	-	10,52 €	16,76 €	-
RPP5/280	280	56	✓	-	10,72 €	16,76 €	25,53 €
RPP5/285	285	57	-	-	10,72 €	16,76 €	25,53 €
RPP5/295	295	59	✓	-	10,72 €	16,76 €	25,53 €
RPP5/300	300	60	✓	✓	10,99 €	16,76 €	25,83 €
RPP5/305	305	61	-	✓	10,99 €	16,99 €	25,83 €
RPP5/325	325	65	✓	✓	10,99 €	17,28 €	-
RPP5/345	345	69	✓	✓	11,26 €	18,03 €	27,06 €
RPP5/350	350	70	✓	✓	11,26 €	18,03 €	27,06 €
RPP5/375	375	75	✓	✓	11,44 €	18,55 €	27,79 €
RPP5/400	400	80	✓	✓	11,95 €	18,77 €	28,59 €
RPP5/420	420	84	✓	✓	11,95 €	19,02 €	28,84 €
RPP5/425	425	85	-	-	12,26 €	19,54 €	29,57 €
RPP5/450	450	90	✓	✓	12,48 €	19,99 €	30,10 €
RPP5/455	455	91	-	✓	12,48 €	19,99 €	30,10 €
RPP5/460	460	92	✓	✓	12,48 €	19,99 €	-
RPP5/465	465	93	-	-	12,48 €	20,30 €	30,35 €
RPP5/475	475	95	-	✓	12,71 €	20,30 €	30,63 €
RPP5/500	500	100	✓	✓	13,00 €	21,06 €	31,35 €

\*Depending on availability - Dimensions in mm

Part number	Length	N° of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			9mm	15mm	9mm	15mm	25mm
RPP5/525	525	105	-	✓	13,23 €	21,30 €	31,84 €
RPP5/535	535	107	-	✓	13,76 €	21,56 €	32,41 €
RPP5/565	565	113	✓	✓	13,76 €	22,06 €	33,64 €
RPP5/575	575	115	-	✓	13,96 €	22,06 €	33,64 €
RPP5/580	580	116	-	✓	13,96 €	22,32 €	-
RPP5/600	600	120	-	-	14,26 €	22,78 €	34,39 €
RPP5/610	610	122	-	-	14,46 €	23,05 €	34,91 €
RPP5/615	615	123	-	-	14,74 €	23,32 €	-
RPP5/635	635	127	-	-	14,74 €	23,32 €	35,64 €
RPP5/640	640	128	✓	-	15,02 €	24,02 €	35,89 €
RPP5/670	670	134	✓	-	15,27 €	24,32 €	36,63 €
RPP5/675	675	135	-	-	15,27 €	24,32 €	36,63 €
RPP5/700	700	140	-	-	15,77 €	25,07 €	37,89 €
RPP5/705	705	141	-	-	15,77 €	25,07 €	-
RPP5/710	710	142	-	-	15,77 €	25,25 €	37,89 €
RPP5/725	725	145	-	-	16,01 €	25,60 €	38,39 €
RPP5/740	740	148	-	-	16,26 €	25,83 €	38,69 €
RPP5/750	750	150	-	✓	16,26 €	25,83 €	38,92 €
RPP5/755	755	151	✓	-	16,26 €	25,83 €	38,92 €
RPP5/800	800	160	-	✓	16,76 €	26,82 €	40,38 €
RPP5/835	835	167	✓	✓	16,99 €	27,36 €	41,17 €
RPP5/850	850	170	✓	-	17,52 €	27,79 €	41,95 €
RPP5/890	890	178	-	-	18,03 €	28,59 €	43,22 €
RPP5/900	900	180	-	-	18,03 €	28,84 €	43,40 €
RPP5/935	935	187	-	✓	18,55 €	29,35 €	44,22 €
RPP5/940	940	188	-	-	18,55 €	29,57 €	44,92 €
RPP5/950	950	190	-	-	18,77 €	29,85 €	45,21 €
RPP5/980	980	196	-	-	19,02 €	30,35 €	45,70 €
RPP5/1000	1000	200	-	-	19,54 €	31,11 €	46,71 €
RPP5/1025	1025	205	-	-	19,99 €	31,35 €	-
RPP5/1050	1050	210	-	-	20,30 €	31,84 €	48,21 €
RPP5/1100	1100	220	-	-	20,79 €	32,67 €	49,99 €
RPP5/1125	1125	225	✓	✓	21,30 €	33,36 €	50,97 €
RPP5/1135	1135	227	-	-	21,42 €	34,11 €	51,98 €
RPP5/1195	1195	239	-	-	21,56 €	35,09 €	-
RPP5/1200	1200	240	-	-	22,06 €	35,64 €	53,26 €
RPP5/1240	1240	248	-	-	22,32 €	35,89 €	54,03 €
RPP5/1270	1270	254	-	-	22,78 €	35,89 €	54,79 €
RPP5/1420	1420	284	✓	-	24,55 €	39,20 €	59,30 €
RPP5/1595	1595	319	-	-	26,82 €	42,67 €	64,54 €
RPP5/1690	1690	338	✓	-	27,60 €	44,22 €	66,34 €
RPP5/1790	1790	358	-	-	29,35 €	46,44 €	70,37 €
RPP5/1800	1800	360	-	✓	29,57 €	46,71 €	70,37 €
RPP5/1870	1870	374	-	-	30,35 €	47,95 €	-
RPP5/1895	1895	379	-	-	30,79 €	48,72 €	73,39 €
RPP5/1945	1945	389	✓	-	31,11 €	49,20 €	-
RPP5/2000	2000	400	✓	-	31,84 €	50,72 €	76,63 €
RPP5/2250	2250	450	-	✓	35,64 €	56,01 €	91,00 €
RPP5/2525	2525	505	✓	✓	38,69 €	61,01 €	92,25 €

\*Depending on availability - Dimensions in mm

# RPP timing belt

Stock

## Pitch RPP8

## Chloroprene rubber belt with glass fibre tension members

- To be used with HTD8M pulley
- Pitch 8mm
- Efficiency: up to 98%
- Materials:  
Chloroprene rubber reinforced with glass fibres  
nylon protective film



### Advantages

- **Shock-resistant**
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- HTD8 pulleys (tome 4 p.18)
- GTC belt tension rollers (tome 4 p.146)


### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	N° of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			20mm	30mm	20mm	30mm	50mm
RPP8/288	288	36	-	-	13,76 €	21,30 €	36,15 €
RPP8/320	320	40	-	-	14,74 €	23,05 €	38,39 €
RPP8/352	352	44	-	-	15,77 €	24,55 €	41,39 €
RPP8/360	360	45	-	-	16,26 €	25,07 €	42,67 €
RPP8/384	384	48	✓	-	17,28 €	26,82 €	45,39 €
RPP8/408	408	51	-	-	18,55 €	28,59 €	48,43 €
RPP8/456	456	57	✓	-	21,06 €	32,33 €	54,79 €
RPP8/480	480	60	-	-	22,06 €	34,11 €	57,78 €
RPP8/536	536	67	✓	-	23,82 €	36,36 €	61,01 €
RPP8/544	544	68	-	-	25,07 €	38,14 €	64,29 €
RPP8/560	560	70	✓	-	25,25 €	38,69 €	65,53 €
RPP8/600	600	75	-	✓	26,32 €	39,66 €	67,05 €
RPP8/608	608	76	-	-	26,53 €	40,18 €	68,06 €
RPP8/632	632	79	✓	-	26,82 €	40,38 €	69,31 €
RPP8/640	640	80	-	-	27,60 €	41,67 €	70,81 €
RPP8/680	680	85	-	-	28,13 €	42,67 €	72,63 €
RPP8/720	720	90	✓	-	29,85 €	45,21 €	76,63 €
RPP8/800	800	100	-	-	31,57 €	48,43 €	82,45 €
RPP8/840	840	105	✓	-	32,86 €	49,99 €	84,71 €
RPP8/880	880	110	-	-	33,64 €	51,27 €	86,45 €
RPP8/896	896	112	-	-	33,89 €	51,51 €	87,71 €
RPP8/920	920	115	-	-	34,87 €	52,97 €	89,97 €
RPP8/960	960	120	✓	-	36,15 €	54,79 €	92,97 €

\*Depending on availability - Dimensions in mm

# Pitch RPP8

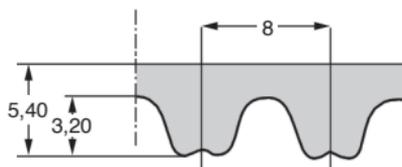

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request


Part number	Length	N° of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			20mm	30mm	20mm	30mm	50mm
RPP8/1000	1000	125	-	-	37,41 €	56,24 €	95,77 €
RPP8/1040	1040	130	-	-	38,86 €	58,52 €	99,49 €
RPP8/1080	1080	135	-	-	39,88 €	60,30 €	102,78 €
RPP8/1120	1120	140	-	-	40,89 €	62,28 €	105,77 €
RPP8/1200	1200	150	-	-	43,40 €	65,53 €	111,09 €
RPP8/1224	1224	153	-	-	44,22 €	66,84 €	113,38 €
RPP8/1280	1280	160	-	-	45,70 €	69,31 €	117,10 €
RPP8/1352	1352	169	-	-	46,44 €	70,62 €	119,65 €
RPP8/1424	1424	178	-	-	48,75 €	75,04 €	124,88 €
RPP8/1440	1440	180	-	-	49,49 €	75,35 €	127,70 €
RPP8/1464	1464	183	-	-	51,70 €	78,66 €	132,74 €
RPP8/1600	1600	200	✓	-	54,03 €	81,46 €	138,53 €
RPP8/1680	1680	210	-	-	56,01 €	84,94 €	144,03 €
RPP8/1760	1760	220	-	-	58,04 €	88,52 €	149,60 €
RPP8/1800	1800	225	-	-	59,30 €	89,97 €	152,89 €
RPP8/2000	2000	250	-	-	65,53 €	99,28 €	167,69 €
RPP8/2200	2200	275	-	-	71,10 €	107,58 €	182,27 €
RPP8/2272	2272	284	-	-	73,44 €	110,01 €	186,74 €
RPP8/2400	2400	300	-	-	76,90 €	116,35 €	196,87 €
RPP8/2520	2520	315	-	-	78,93 €	119,65 €	202,65 €
RPP8/2600	2600	325	-	-	81,46 €	123,41 €	209,25 €
RPP8/2800	2800	350	-	-	87,96 €	132,74 €	225,32 €
RPP8/3048	3048	381	-	-	102,78 €	156,62 €	263,02 €
RPP8/3280	3280	410	-	-	110,58 €	168,24 €	282,38 €
RPP8/3600	3600	450	-	-	121,45 €	184,33 €	311,12 €
RPP8/4400	4400	550	-	-	148,13 €	225,32 €	380,56 €

\*Depending on availability - Dimensions in mm

# RPP timing belt

## Pitch RPP14 Chloroprene rubber belt with glass fibre tension members

- To be used with HTD14M pulley
- Pitch 14mm
- Efficiency: up to 98%
- Materials:  
chloroprene rubber reinforced  
with glass fibres  
nylon protective film

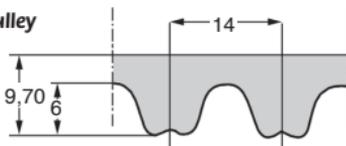

### Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- HTD8 pulleys (tome 4 p.21)
- GTC belt tension rollers (tome 4 p.146)

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	N° of teeth	Price each 1 to 5 for a width of	
			55mm	85mm
RPP14/966	966	69	241.69 €	395.36 €
RPP14/994	994	71	243.16 €	398.42 €
RPP14/1092	1092	78	244.44 €	401.64 €
RPP14/1106	1106	79	247.71 €	406.96 €
RPP14/1190	1190	85	260.53 €	408.48 €
RPP14/1260	1260	90	261.80 €	410.22 €
RPP14/1288	1288	92	264.56 €	414.75 €
RPP14/1344	1344	96	273.65 €	432.84 €
RPP14/1400	1400	100	284.88 €	446.43 €
RPP14/1442	1442	103	293.48 €	459.78 €
RPP14/1568	1568	112	303.04 €	471.35 €
RPP14/1610	1610	115	311.12 €	483.95 €
RPP14/1764	1764	126	331.43 €	510.08 €
RPP14/1778	1778	127	335.25 €	514.12 €
RPP14/1848	1848	132	340.24 €	520.40 €
RPP14/1890	1890	135	347.80 €	532.20 €
RPP14/1904	1904	136	350.36 €	536.28 €
RPP14/1960	1960	140	352.58 €	538.71 €
RPP14/2100	2100	150	372.24 €	577.04 €
RPP14/2240	2240	160	383.30 €	582.30 €
RPP14/2310	2310	165	395.36 €	600.43 €
RPP14/2380	2380	170	399.39 €	619.79 €
RPP14/2450	2450	175	408.48 €	637.88 €
RPP14/2590	2590	185	419.81 €	655.99 €
RPP14/2660	2660	190	431.10 €	689.00 €
RPP14/2800	2800	200	453.77 €	725.22 €
RPP14/2968	2968	212	471.51 €	734.38 €
RPP14/3150	3150	225	489.22 €	743.51 €
RPP14/3360	3360	240	521.40 €	792.60 €
RPP14/3500	3500	250	525.93 €	818.27 €
RPP14/3850	3850	275	570.72 €	886.95 €
RPP14/3920	3920	280	572.72 €	903.04 €
RPP14/4326	4326	309	632.13 €	973.23 €
RPP14/4578	4578	327	662.04 €	1 021.34 €
RPP14/4956	4956	354	707.59 €	1 099.75 €

Dimensions in mm



MINIMUM  
ORDER  
20€\*

FREE  
DELIVERY  
FOR ORDERS  
100€\* OR MORE



VOLUME  
DISCOUNT

1,2,3  
PRODUCTS  
SOLD  
INDIVIDUALLY



FAST  
QUOTES  
& ORDERS



FREE  
CATALOGUES



CAD FILES  
STEP, IGES...



MADE TO  
MEASURE  
AVAILABLE



# DELIVERY

# 24/48 H\*

\* Certain conditions apply - Deliveries to mainland France only

# RPP type belt by **the metre**



## Pitch

## Polyurethane with steel core

### RPP5

### RPP8

### RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

### Applications

- Reciprocating movements



### Info.

- Minimum length 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and width (l) to the part number (RPP5M/L/l)
- E.g. : RPP5M/1000/15


### Accessoires

- RPP.../P connecting plates (**tome 4 p.33**)
- HTD pulleys (**tome 4 p.15**)

**For linear positioning**

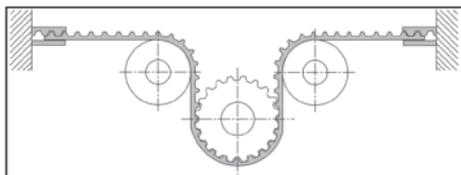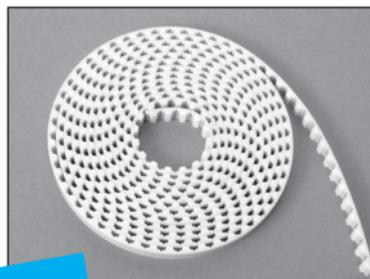

Typical application

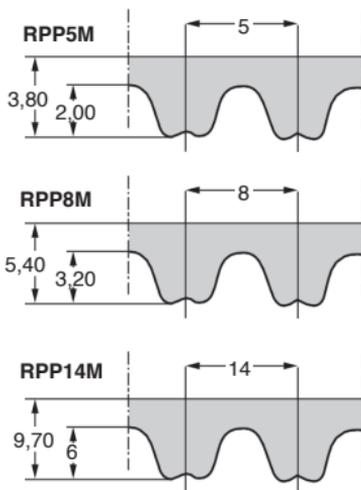

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	29,40 €	-	53,85 €	-	-	-	-
RPP8M	RPP8	-	48,66 €	-	48,73 €	74,61 €	-	-
RPP14M	RPP14	-	-	-	-	-	127,94 €	211,52 €

Dimensions in mm

For open belts RPP5M, RPP8M  
and RPP14M

Pitch  
**RPP5**  
**RPP8**  
**RPP14**


- For linear movements
- 5mm, 8mm and 14mm pitches
- Rigid connecting plates
- Material :  
aluminium

## Applications


- For closing an open belt
- To attach an open belt to a structure

## Accessories

- RPP../P belts (tome 4 p.32)
- HTD pulleys (tome 4 p.15)

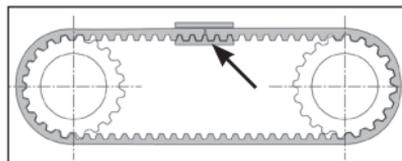

Typical application

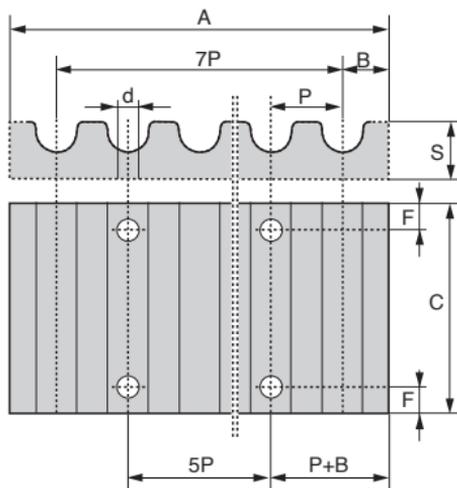

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Stock*	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	✓	12,87 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	✓	12,59 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	-	19,95 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	-	21,05 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	-	23,37 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	-	54,19 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	-	72,00 €

\* Depending on availability - Dimensions in mm