

# RPP type belt by **the metre**



## Pitch

## Polyurethane with steel core

# RPP5

# RPP8

# RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

### Applications


- Reciprocating movements

### Accessories



- RPP.../P connecting plates
- HTD pulleys

### Info.

- Minimum length 1000mm
  - Supplied in multiples of 1 metre
  - When ordering, add the length (L) and width (I) to the part number (RPP5M/L/I)
- E.g. : RPP5M/1000/15

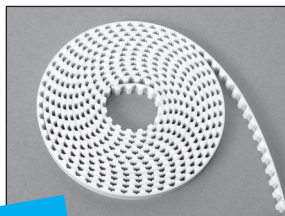

**For linear positioning**

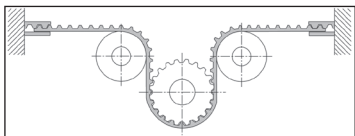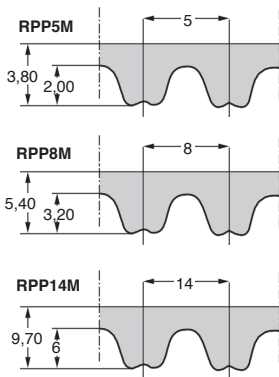

Typical application


### DISCOUNTS

 Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

## Our other products



CM  
Bearing locknut,  
Locknut KM



BLHM50  
Right angled gearbox,  
double output shafts,  
up to 30 Nm



CHM110  
Worm and wheel gear  
reducer, up to 980  
Nm



PRF4590  
Standard aluminium  
profile, 45 x 90 mm



CFF  
Female rod ends DIN  
ISO12240-4, Steel /  
bronze



BPHF  
Ball transfer unit push  
fit, Heavy



CHTRB  
Single and dual  
output gearboxes, Up  
to 4,7 Nm



CHM40-MOT  
Asynchronous AC  
motorgearboxes 0.18  
to 0.55kW, 0.18 to  
0.55kW



SA\_SAKH  
Housing for linear  
bearing, Closed - light  
load



PW\_PWG3  
Wheel - precision  
range, Bronze




PRF4545  
Standard stainless  
steel profile, 45 x 45  
mm



GTCSS  
Belt tensioner, For use  
in hostile  
environments

## Complementary products

 

RRP5  
Connecting plate for  
RPP type timing belts,  
RRP5