

# RPP type belt by **the metre**



## Pitch

## Polyurethane with steel core

# RPP5

# RPP8

# RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

### Applications


- Reciprocating movements

### Accessories



- RPP.../P connecting plates
- HTD pulleys

### Info.

- Minimum length 1000mm
  - Supplied in multiples of 1 metre
  - When ordering, add the length (L) and width (I) to the part number (**RPP5M/L/I**)
- E.g. : **RPP5M/1000/15**

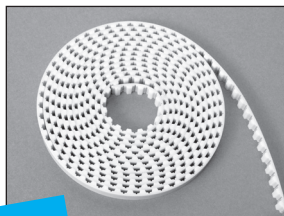

**For linear positioning**

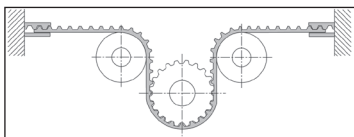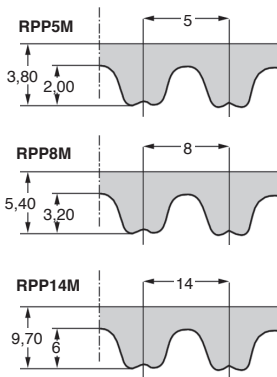

Typical application

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

## Our other products



GE\_ES\_2RS  
Spherical bushing,  
Steel / steel with seals



HLUMss  
Revolving handle for  
handwheel, Stainless  
steel 316



T2,5-BAR  
T type tooth bar  
stock, T2.5



UTKpwcr  
Utilitrak® 3 wheels  
carriage, Polymer  
roller carriage



MHXred  
Reducing sleeve  
male/female,  
Hexagonal - stainless  
steel



RFK58B  
Hypoid gearbox -  
Stainless steel, up to  
500 Nm



HLA24  
Right angle spiro  
bevel gearbox, Up to  
78Nm



BAC105  
Storage bin, 8mm



CLB\_T  
Die cast zinc clamping  
lever - male, Zamak



SDA  
Locking bolt support  
bracket, Mounting

 


MBEX  
Hexagonal ended  
handle, Hexagonal




MRA  
Quick link, Steel

## Complementary products



RRP5  
Connecting plate for  
RPP type timing belts,  
RRP5

 

RPP3  
RPP heavy duty  
timing belt, RPP3