

RPP type belt by the metre



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements

- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories


- RPP.../P connecting plates
- HTD pulleys

Info.




- Minimum length 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and width (l) to the part number (RPP5M/l/L)
- E.g. : RPP5M/1000/15

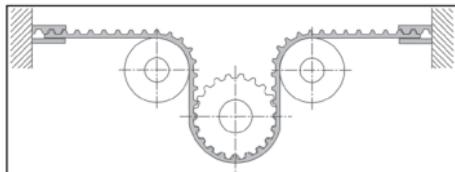

Typical application

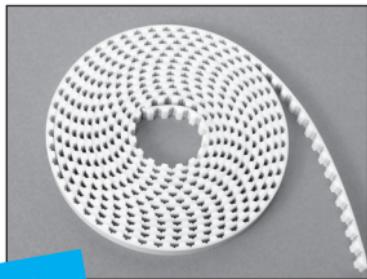

For linear
positioning

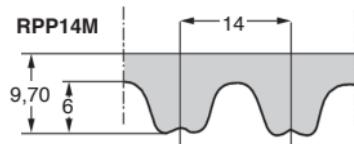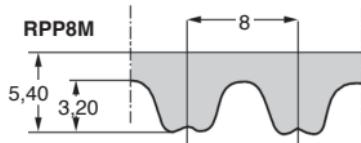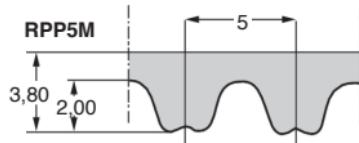

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	22,51 €	-	29,90 €	35,70 €	-	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

Our other products



GLT2-27

Telescopic drawer runners for groove mounting, Partial extension



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



HG5

Steel spur gear, Steel 20NCD2



SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



RTL450

Self-centering locking assembly, High torque



BPHR

Ball transfer unit housed spring loaded, High



BTCW

Cap for square tube to be welded, To be welded



GPB

Threaded spherical knob, With brass insert



BAC105

Storage bin, 8mm



CHINV2

Invisible hinge, Invisible - Opening up to 125°



CHM110


Worm and wheel gear reducer, up to 980 Nm



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket

Complementary products

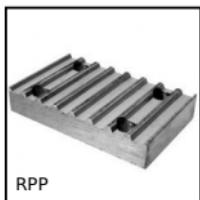

RPP

Connecting plate for RPP type timing belts, RRP5