

RPP type belt by **the metre**



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories



- RPP.../P connecting plates
- HTD pulleys

Info.

- Minimum length 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and width (I) to the part number (**RPP5M/L/I**)
- E.g. : **RPP5M/1000/15**

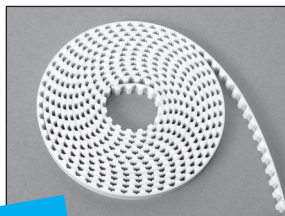

For linear positioning

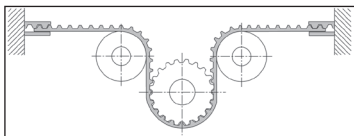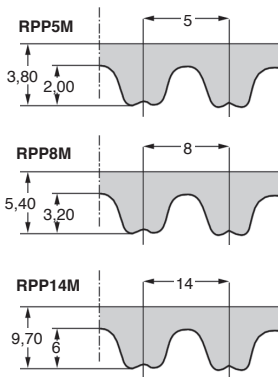

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

Our other products



EX

Optional shaft for E-type gear reducers, E Gearboxes double sided ou...



D-PAR_SS

Stainless steel elastomeric mount, stainless steel



HK

Manual locking clamp, Manual locking clamp T



 
BTC20_10

End cap for rectangular tube, Standard



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



M0

Worm and wheel set, Bronze



T10_30_AL

T type timing pulley, Economy range - T10 aluminium



DTR

Chain idler sprocket, Chain idler sprocket - Plastic



RAS

90° ball and socket joints DIN71802, Stainless steel



GMK17_RG

Joint for guiding profile, Rounded



VLBG

Lifting ring, Rotating



DCG

Suction cup, 2.5 bellows, natural rubber

Complementary products



RPP

Connecting plate for RPP type timing belts, RPP8