

Free running wheel

RUR

For loads up to 350kg

- **Light industrial wheel for loads up to 350kg**

- Ball bearing hub

- Materials:

Polyurethane covered wheel 85 Shore

Aluminium rim

Working temperature range: -30 to +80°C

For rough floors



Advantages

- Smooth and quiet running

- Resists wear

- Very strong

- Recommended for its exceptional resistance and its long-term service

- Low risk of flat spots developing if the wheel is not used

Applications

- Rough floors

- Can be used where metal chips, solvents, oil or grease is present



ØD



B



F



ØA



DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	A	F	Max load (kg)	Price each 1 to 9
RUR80	80	40	12	41	180	17,79 €
RUR100	100	40	12	41	220	20,14 €
RUR125	125	40	15	41	260	21,97 €
RUR150	150	40	20	50	350	31,13 €

Dimensions in mm

Our other products




LVT
Miniature motorised
actuator 4A, 4 ampers



LWL
Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



H1
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

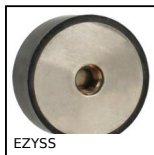

EZYSS
Stainless steel
cylindrical stop,
stainless steel



SBF
Sealed flange bearing
unit for Food Industry,
cover



MFBC
Flexible Bellows
coupling, Aluminium
and Bronze - with
clamping jaw



SRP
Slotted spring pin
ISO8752, Split ISO
8752



V3RA_PT
3-spoked handwheel
with handle,
Polyamide



PSG125
Spur gear - precision
range, Pre-hardened



SH2
Parallel axis helical
gear, Steel 20NCD2



ASM
Cylindrical polymer
bush, Food grade



NPTF30
Fixed tube carrier,
Fixed Ø14 to Ø20

Complementary products



RURp
Fixed castor with
plate, Polyurethane -
Aluminium rim (Free
running)



RURp
Wheel pivoting with
plate, Polyurethane -
Aluminium rim (Free
running)



RURp
Swivel castor with
double brake,
Polyurethane -
Aluminium rim (Free
running)

...



RURt
Swivel castor with
central hole,
Polyurethane -
Aluminium rim (Free

