

Free running wheel

RUR

For loads up to 350kg

- Light industrial wheel for loads up to 350kg
- Ball bearing hub
- Materials:
 - Polyurethane covered wheel 85 Shore
 - Aluminium rim
 - Working temperature range: -30 to +80°C

For rough floors

 


Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present




DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	A	F	Max load (kg)	Price each 1 to 9
RUR80	80	40	12	41	180	17,79 €
RUR100	100	40	12	41	220	20,14 €
RUR125	125	40	15	41	260	21,97 €
RUR150	150	40	20	50	350	31,13 €

Dimensions in mm

Our other products

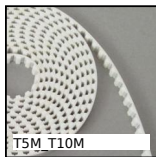

T5M T10M
T type timing belt per metre, T10 Steel cored polyurethane



B5M
Spring plunger with internal hexagonal socket, stainless steel 303 b...



UTKswc
Utiltrak® 3 wheels carriage, Series V precision steel wheel



TCL-ECL
Support rod for heavy loads, Support spindle



TAC_SS
Stainless steel rigging screw (hook/eye), Stainless steel



CHAE4060PA
Decorative asymmetric screwed hinge, Polyamide



 
MDB_MTB
Moulded plastic bevel gear (nylon), 3:1



ACL-FPA
Panel mounting block for aluminium structures, Support block



J66
Spur gear coaxial gearbox, from 0.90 to



M0
Worm and wheel set, Machined plastic



ALIDRP240
24V DC power supply, 10 A



AZY
Cylindrical elastomer mount, Steel

Complementary products



RURp
Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



RURp
Wheel pivoting with plate, Polyurethane - Aluminium rim (Free running)



RURp
Swivel castor with double brake, Polyurethane - Aluminium rim (Free

...



RURt

Swivel castor with
central hole,
Polyurethane -
Aluminium rim (Free

