

Free running wheel with mounting plate

For loads up to 350kg

RURP

- Light industrial castor for loads up to 350kg
- Materials:
 - Top bracket/plate: Plated steel sheet
 - Polyurethane covered wheel 85 Shore
 - Aluminium rim
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Hub with ball bearing
- Working temperature range: -30 to +80°C

Swivel with double lock




Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

For rough floors

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present

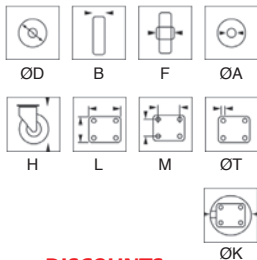

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Références	ØD	H	B	A	F	L	M	ØT	Swivel inter-farence ØK	Max load (kg)	Price each 1 to 9
Swivel											
RURP80/P	80	110	40	12	41	110x85	80x60	8	162	180	26,87 €
RURP100/P	100	127	40	12	41	110x85	80x60	8	184	220	29,51 €
RURP125/P	125	155	40	15	41	110x85	80x60	8	216	260	33,17 €
RURP150/P	150	181	40	20	50	110x85	80x60	8	244	350	42,85 €
Swivel with double brake											
RURP80/PDB	80	110	40	12	41	110x85	80x60	8	290	180	30,91 €
RURP100/PDB	100	127	40	12	41	110x85	80x60	8	290	220	33,76 €
RURP125/PDB	125	155	40	15	41	110x85	80x60	8	290	260	37,79 €
RURP150/PDB	150	181	40	20	50	110x85	80x60	8	290	350	47,31 €
Fixed											
RURP80/F	80	110	40	12	41	110x85	80x60	8	-	180	23,73 €
RURP100/F	100	127	40	12	41	110x85	80x60	8	-	220	26,21 €
RURP125/F	125	155	40	15	41	110x85	80x60	8	-	260	30,25 €
RURP150/F	150	181	40	20	50	110x85	80x60	8	-	350	40,35 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



STL
Guidance brush - Rail,
Rail



CHAE4060PA
Decorative
asymmetric screwed
hinge, Polyamide




SBF
Sealed flange bearing
unit for Food Industry,
cover



BAC110
Swivel storage bin,
Adjustable support



 SH2
Parallel axis helical
gear, Machined plastic
(delrin)



BLHM30
Right angled gearbox,
double output shafts,
up to 4.4 Nm



RT25
Self-centering flanged
locking assembly,
Medium/high torque




PAP
Handle for aluminium
profile, Ergonomic
handle



NPTR10
Adjustable cross
clamp, Adjustable



 BIMSS
Indexing plunger mini,
miniature - Stainless
steel



GP
Spring loaded toggle
latch, With padlock-
holder



CHTRP
Single and dual
output gearboxes, Up
to 28,8 Nm

Complementary products



RPCpl
Fixed castor with
plate, Steel -
Polyamide



RUR
Wheel, Polyurethane -
Aluminium rim (Free
running)



RBNpl
Fixed castor with
plate, Steel - rubber



RBGpl
Fixed castor with
plate, Steel - grey
rubber