

Free running wheel with mounting plate

For loads up to 350kg

RURP

- Light industrial castor for loads up to 350kg
- Materials:
 - Top bracket/plate: Plated steel sheet
 - Polyurethane covered wheel 85 Shore
 - Aluminium rim
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Hub with ball bearing
- Working temperature range: -30 to +80°C

Swivel with double lock




Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

For rough floors

Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present

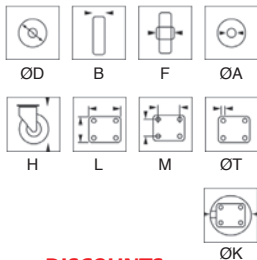

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Références	ØD	H	B	A	F	L	M	ØT	Swivel inter-farence ØK	Max load (kg)	Price each 1 to 9
Swivel											
RURP80/P	80	110	40	12	41	110x85	80x60	8	162	180	26,87 €
RURP100/P	100	127	40	12	41	110x85	80x60	8	184	220	29,51 €
RURP125/P	125	155	40	15	41	110x85	80x60	8	216	260	33,17 €
RURP150/P	150	181	40	20	50	110x85	80x60	8	244	350	42,85 €
Swivel with double brake											
RURP80/PDB	80	110	40	12	41	110x85	80x60	8	290	180	30,91 €
RURP100/PDB	100	127	40	12	41	110x85	80x60	8	290	220	33,76 €
RURP125/PDB	125	155	40	15	41	110x85	80x60	8	290	260	37,79 €
RURP150/PDB	150	181	40	20	50	110x85	80x60	8	290	350	47,31 €
Fixed											
RURP80/F	80	110	40	12	41	110x85	80x60	8	-	180	23,73 €
RURP100/F	100	127	40	12	41	110x85	80x60	8	-	220	26,21 €
RURP125/F	125	155	40	15	41	110x85	80x60	8	-	260	30,25 €
RURP150/F	150	181	40	20	50	110x85	80x60	8	-	350	40,35 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



AT5P_AT10P
Connecting plate for AT type timing belts, AT10



INS150
Self tapping insert with collar-coarse thread, With collar-coarse t...



BAG-MISS
Split shaft collar with clamp lever, Stainless steel



PFC
Fixed rubber levelling foot, Levelling support for small parts



MDR_SS
Stainless steel Dee shackle with eye bolt, Stainless steel



CHM90
Worm and wheel gear reducer, up to 540 Nm



CHB
Worm and wheel gear reducer, up to 73 Nm



GAL48_OMNI
Omni-directional roller, Omni-directional



CABma
Swaging sleeve for fitting cable, To crimp a wire rope



PCP
Cell carrier assembly, Ready assembled



PRF_P
Anchor foot for 45x45 profile, Anchor foot



OP7
Mechanical digital position indicator, 5 numbers

Complementary products



RUR
Wheel, Polyurethane - Aluminium rim (Free running)



RPCpl
Swivel castor with plate, Steel - Polyamide



RBNpl
Swivel castor with plate, Steel - rubber



RURp
Fixed castor with plate, Polyurethane - Aluminium rim (Free running)