

Manual worm/wheel gearbox



RVM14

Manual torque up to 5 Nm



- **Manually operated bevel gearbox**
- Ratios from 1:1 to 23:1
- **Materials:**
 - Housing: die cast zinc
 - Worm/wheel: Case hardened steel

Accessories

- MBEX handle
- AHX hexagonal shaft

Info

- Not suitable for motorised applications

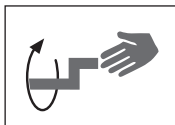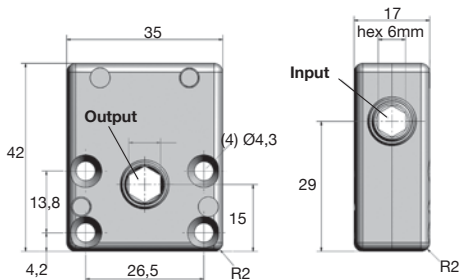

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input/ Output	Max torque (Nm)	Self locking	Price each 1 to 9
RVM14-1	1:1	hex 6mm	2,0	No	78,14 €
RVM14-2	2:1	hex 6mm	2,0	No	78,14 €
RVM14-2.8	2,8:1	hex 6mm	2,5	No	78,14 €
RVM14-4.33	4,33:1	hex 6mm	2,0	Yes	78,14 €
RVM14-10	10:1	hex 6mm	4,0	Yes	78,14 €
RVM14-14	14:1	hex 6mm	5,0	Yes	78,14 €
RVM14-15	15:1	hex 6mm	4,0	Yes	78,14 €
RVM14-23	23:1	hex 6mm	3,0	Yes	78,14 €

 
Dimensions in mm

Our other products



PRF-SCREEN-1

Screen support, Basic support



AF

Shaft clamp with keyway, Set screw



UTKpwrr

V shaped channel UtiliTrak®, V rail



RGS

Rotex® GS backlash free jaw coupling, from 0.5 to 190Nm



PRF_PL_9090

Joining plate for aluminium profile, joint plate - 90x90 mm



LVT

Miniature motorised actuator 4A, 4 amperes



DIA

Ring operated locking bolt, with ring



PSG05

Spur gear - precision range, Pre-hardened Steel 35NCD6



RVM25

Manually operated gearbox, Bevel



VTA

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



BPFss

Pressed stainless steel flange bearing, Stainless steel



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2

Complementary products



AHx

Hexagonal shaft, Hexagonal shaft



MBEX

Hexagonal ended handle, Hexagonal ended handle