

# Manual worm/wheel gearbox



## RVM14

## Manual torque up to 5 Nm



- **Manually operated bevel gearbox**
- Ratios from 1:1 to 23:1
- **Materials:**
  - Housing: die cast zinc
  - Worm/wheel: Case hardened steel

### Accessories

- MBEX handle
- AHX hexagonal shaft

### Info

- Not suitable for motorised applications

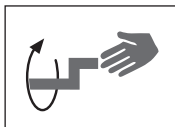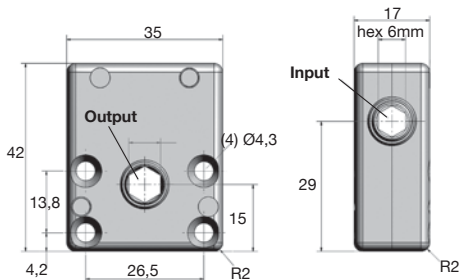

For manual applications

### DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty   | 1+   | 10+ | 25+  | 50+        |
| Disc. | List | -5% | -15% | On request |

| Part number | Ratio  | Input/ Output | Max torque (Nm) | Self locking | Price each 1 to 9 |
|-------------|--------|---------------|-----------------|--------------|-------------------|
| RVM14-1     | 1:1    | hex 6mm       | 2,0             | No           | 78,14 €           |
| RVM14-2     | 2:1    | hex 6mm       | 2,0             | No           | 78,14 €           |
| RVM14-2.8   | 2,8:1  | hex 6mm       | 2,5             | No           | 78,14 €           |
| RVM14-4.33  | 4,33:1 | hex 6mm       | 2,0             | Yes          | 78,14 €           |
| RVM14-10    | 10:1   | hex 6mm       | 4,0             | Yes          | 78,14 €           |
| RVM14-14    | 14:1   | hex 6mm       | 5,0             | Yes          | 78,14 €           |
| RVM14-15    | 15:1   | hex 6mm       | 4,0             | Yes          | 78,14 €           |
| RVM14-23    | 23:1   | hex 6mm       | 3,0             | Yes          | 78,14 €           |

Dimensions in mm

## Our other products



SSG2\_304L  
Stainless steel spur gear, Stainless steel 304L



ADL\_F  
Female eye bolt conforms to DIN582, Steel



YG3  
HEAVY DUTY spur gear, Steel 35NCD6



PTA50  
Articulated levelling foot, pressed base Ø50, Ø 50



KITbuh  
24V DC motorisation kit, Planetary gears



RCX-6  
Spherical tilt washer - DIN6319, convex



SR  
Narrow spur rack, Stainless steel



UTKswr  
Utilitak® V rail, V rail



HTD5M\_09  
HTD Heavy duty timing pulley, HTD5



CLA  
Clamping lever Hygienic Usit® -



HDSS  
Needle roller double universal joint -



EFSM  
Igubal® flange bearing, Polymer

## Complementary products



AHEx  
Hexagonal shaft, Hexagonal shaft



MBEx  
Hexagonal ended handle, Hexagonal ended handle