



Manually operated gearbox

Manual torque up to 17 Nm

RVM25



- Compact manually operated gearbox
- Ratios from 1:1 to 30:1
- Material:
Housing: die cast zinc

Accessories

- MBEX handle
- AHX hexagonal shaft

Info

- Not suitable for motorised applications

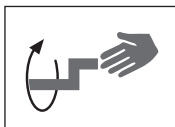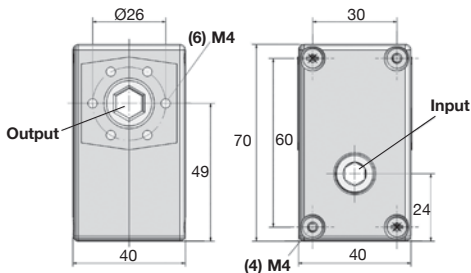

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-15%		On request

Part number	Ratio	Input	Output	Max torque (Nm)	Self locking	Price each 1 to 9
RVM25-1	1:1	hex 6mm	hex 9mm	2,0	No	115,00 €
RVM25-2	2:1	hex 6mm	hex 9mm	3,0	No	115,00 €
RVM25-3.25	3,25:1	hex 6mm	hex 9mm	4,0	Yes	115,00 €
RVM25-4.33	4,33:1	hex 6mm	hex 9mm	5,0	Yes	115,00 €
RVM25-7	7:1	hex 6mm	hex 9mm	7,0	Yes	115,00 €
RVM25-8.5	8,5:1	hex 6mm	hex 9mm	9,0	Yes	115,00 €
RVM25-17	17:1	hex 6mm	hex 9mm	12,0	Yes	115,00 €
RVM25-20	20:1	hex 6mm	hex 9mm	15,0	Yes	115,00 €
RVM25-30	30:1	hex 6mm	hex 9mm	17,0	Yes	115,00 €

Dimensions in mm

Our other products



HW_HT

Half-rail guide, Rail



ACLBMC

Detector support for aluminium profile, Sensor holder



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...



SHSS

Shoulder screw 416, Pre-treated 416 stainless steel



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



PSEC

Security pull handle, Thermoplastic



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot



PM2

Worm and wheel set, Bronze



BABPass

Hardened stainless steel ball pin with ring, With grip ring



AFSE

Locking pin with interlocking safety latch, with



BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



SUP

Self-centering clamping hub steel, Without locknut

Complementary products



AHEX

Hexagonal shaft, Hexagonal shaft



MBEX

Hexagonal ended handle, Hexagonal ended handle