



Manually operated gearbox

Manual torque up to 17 Nm

RVM25



- Compact manually operated gearbox
- Ratios from 1:1 to 30:1
- Material:
Housing: die cast zinc

Accessories

- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

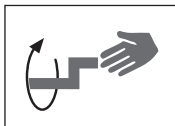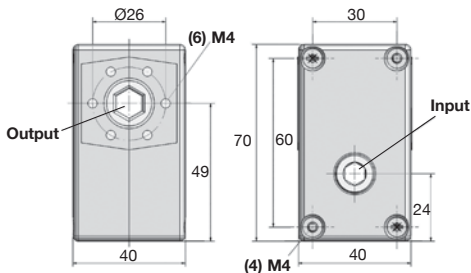

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-15%		On request

Part number	Ratio	Input	Output	Max torque (Nm)	Self locking	Price each 1 to 9
RVM25-1	1:1	hex 6mm	hex 9mm	2,0	No	115,00 €
RVM25-2	2:1	hex 6mm	hex 9mm	3,0	No	115,00 €
RVM25-3.25	3,25:1	hex 6mm	hex 9mm	4,0	Yes	115,00 €
RVM25-4.33	4,33:1	hex 6mm	hex 9mm	5,0	Yes	115,00 €
RVM25-7	7:1	hex 6mm	hex 9mm	7,0	Yes	115,00 €
RVM25-8.5	8,5:1	hex 6mm	hex 9mm	9,0	Yes	115,00 €
RVM25-17	17:1	hex 6mm	hex 9mm	12,0	Yes	115,00 €
RVM25-20	20:1	hex 6mm	hex 9mm	15,0	Yes	115,00 €
RVM25-30	30:1	hex 6mm	hex 9mm	17,0	Yes	115,00 €

Dimensions in mm

Our other products



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



 
DB

Steel bevel gear, 2:1



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



ZR

Plastic rack, Delrin



HD

Double needle roller universal joint, Heavy duty



GPB

Threaded spherical knob, Moulded thread



SR

Narrow spur rack, Stainless steel



ACAss

Stainless steel splined shaft, Stainless steel



HBM

Adjustment bushing for half-rail guide,



RBGtc

Swivel castor with central hole, Steel -



FF15

Offset spur gear reducer, from 2.20 to 22.0



VTH

Hexagonal headed bolts, Steel class 8.8

Complementary products



AHEx

Hexagonal shaft, Hexagonal shaft



MBEx

Hexagonal ended handle, Hexagonal ended handle