


Narrow spur rack



Module 0.4-2.0


Steel

- Pressure angle 20°
- Max length from 400 to 1800 depending on module
- 1 metre lengths can be joined end to end
- Materials:
 - Module 0.4 to 0.7 mild steel
 - Module 0.8 to 2.0 steel 60C40 or C35/C45
- Max. pitch error up to module 0.7:
1mm/300mm
- Max. pitch error from module 0.8:
0.1mm/300mm

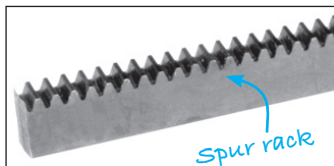

Option

 - Other lengths available for quantities of 5 or more, please contact us



DISCOUNTS

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
R0.4-400	0,4	11,60	6	12	400	✓	91,49 €
R0.5-400	0,5	11,50	6	12	400	✓	34,14 €
R0.8-1000	0,8	11,20	6	12	1000	✓	179,63 €
R1-1000	1	14,00	8	15	1000	✓	92,71 €
R1.25-1000	1,25	13,75	8	15	1000	✓	161,08 €
RR1.5-1000	1,5	16,50	18	18	1000	✓	147,23 €
RR2-1000	2	16,00	18	18	1000	✓	157,19 €

*Depending on availability - Dimensions in mm

Our other products



BAC105

Storage bin, 8mm



GPB55

Threaded spherical knob, Stainless steel 304



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



CAP815

Slim slat top chain stainless steel, Narrow range 815



PCS6255

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)



PLN

Cylindrical spacer, Thermoplastic



NANO

Speed controller 3A, 3 A



P55

Worm and wheel gear reducer, up to 57 Nm



PMC150_M16

Anti-vibration machine mount, Square base plate



SHA_PT

Handwheel with handle, Polyamide



DCG

Suction cup, 2.5 bellows, silicon



ADL_M

Male eye bolt conforms to DIN580, Stainless steel

Complementary products



SR

Narrow spur rack, Stainless steel