




Standard linear **closed** bearing housing **Alu Stock**

NSB For KB, TK and RJUM bearings

- For linear guiding
- Housing for closed bearing
- Bearing not included
- Material : Aluminium

Accessories

- See possible combinations (tome 3 p.242)

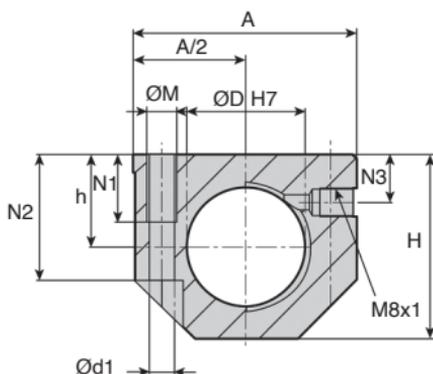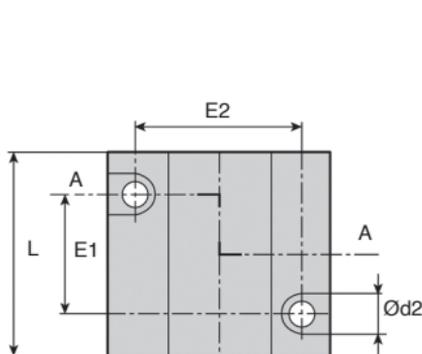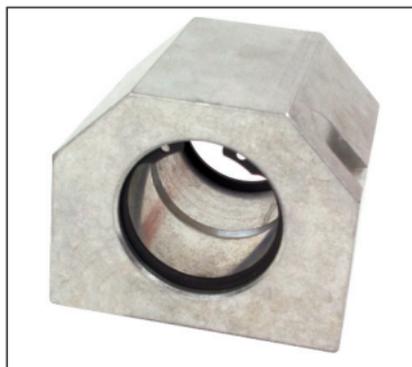

DISCOUNTS

Qty	1+	5+	10+	25+
Disc. List	-6%	-12%	On request	



Part number	For shaft Ød	ØD	H	h +0,01/-0,02	L +0,3					E1 +/-0,2	E2 +/-0,2	Ød1	Ød2	ØM	Stock*	Price each 1 to 4
						N1	N2	N3								
NSB12	12	22	35	18	43	39	13	25	10	23	32	4,2	8	M5	✓	43,00 €
NSB16	16	26	42	22	53	43	13	30	12	26	40	5,2	10	M6	✓	48,83 €
NSB20	20	32	50	25	60	54	18	34	13	32	45	6,8	11	M8	✓	53,47 €
NSB25	25	40	60	30	78	67	22	40	15	40	60	8,6	15	M10	✓	67,46 €
NSB30	30	47	70	35	87	79	22	48	16	45	68	8,6	15	M10	✓	77,95 €
NSB40	40	62	90	45	108	91	26	60	20	58	86	10,3	18	M12	-	125,66 €

*Depending on availability - Dimensions in mm

- For linear guiding
- Housing for closed bearing
- Bearing not supplied
- Material : Aluminium

Accessories

- See possible combinations (tome 3 p.242)

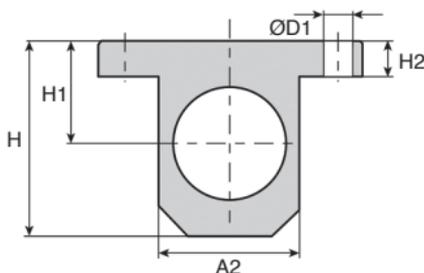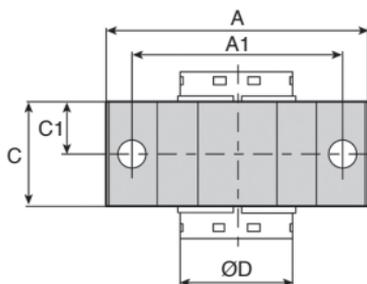

Typical application

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	for shaft		H	C	A	A1 +/-0,15	C1	H1 +/-0,015	H2	A2	ØD1	Stock*	Price each 1 to 4
	Ød	ØD											
S2B12	12	22	35,0	20	52	42	10	18	6	30	5,3	✓	26,68 €
S2B16	16	26	40,5	22	56	46	11	22	7	34	5,3	✓	30,22 €
S2B20	20	32	48,0	28	70	58	14	25	8	40	6,4	✓	32,54 €
S2B25	25	40	58,0	40	80	68	20	30	10	50	6,4	✓	41,83 €
S2B30	30	47	67,0	48	88	76	24	35	10	58	6,4	✓	53,47 €
S2B40	40	62	85,0	56	108	94	28	45	12	74	8,4	-	65,15 €
S2B50	50	75	100,0	72	135	116	36	50	12	96	10,5	-	111,04 €

*Depending on availability - Dimensions in mm

Housing for **open** linear bearing **Alu** **Stock**

NSO For KB-OP and TK-OP bearings



- For linear guiding
- Open housing for open bearing
- Bearing not included
- Material:
Aluminium
- Mount using circlips (except NSO12, secured by set screw)
- Circlips used for assembly

Advantages

- Use with long, supported shafts to avoid any flexing.

Accessories

- See possible combinations (**tome 3 p.276**)

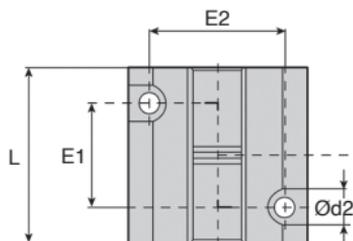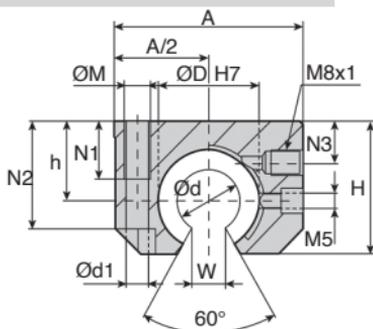

DISCOUNTS

Qty	1+	5+	10+	25+
Disc. List	-6%	-12%	On request	

Part number	For shaft Ød	ØD	H	h	A	L	E1	E2	N1
NSO12	12	22	28	18	43	39	23	32	11
NSO16	16	26	35	22	53	43	26	40	13
NSO20	20	32	42	25	60	54	32	45	18
NSO25	25	40	51	30	78	67	40	60	22
NSO30	30	47	60	35	87	79	45	68	22
NSO40	40	62	77	45	108	91	58	86	26

Part number	N2	N3	Ød1	Ød2	ØM	W	Weight (g)	Stock*	Price each 1 to 4
NSO12	23,5	8	4,2	8	M5	7,0	110	✓	65,14 €
NSO16	30,0	12	5,2	10	M6	9,4	170	✓	32,19 €
NSO20	34,0	13	6,8	11	M8	10,2	300	✓	26,84 €
NSO25	40,0	15	8,6	15	M10	12,5	570	✓	55,91 €
NSO30	48,0	16	8,6	15	M10	13,9	860	-	65,09 €
NSO40	60,0	20	10,3	18	M12	18,0	1600	✓	115,28 €

*Depending on availability - Dimensions in mm

Alu Slim housing for open linear bearing

For KB-OP and TK-OP bearings

S20



- For linear guiding
- Open housing for open bearing
- Bearing not included
- Material : Aluminium

Advantages

- Use with long, supported shafts to avoid any flexing.

Accessories

- See possible combinations (tome 3 p.276)

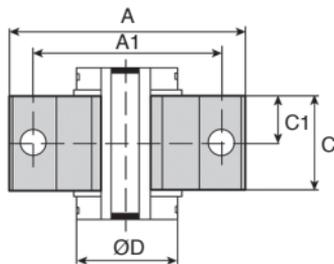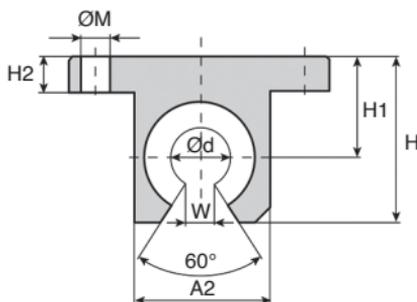

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft						A1 ±0.15
	Ød	ØD	H	C	A		
S2O12	12	22	28,0	20	52	42	
S2O16	16	26	33,5	22	56	46	
S2O20	20	32	42,0	28	70	58	
S2O25	25	40	51,0	40	80	68	
S2O30	30	47	60,0	48	88	76	
S2O40	40	62	77,0	56	108	94	
S2O50	50	75	93,0	72	135	116	

Part number	C1	H1 ±0.015	H2	W	A2	ØM	Price
							each 1 to 4
S2O12	10	18	6	7,0	30	5,3	On request
S2O16	11	22	7	9,4	34	5,3	48,09 €
S2O20	14	25	8	10,0	40	6,4	50,26 €
S2O25	20	30	10	12,5	50	6,4	65,73 €
S2O30	24	35	10	12,5	58	6,4	89,18 €
S2O40	28	45	12	16,8	74	8,4	112,55 €
S2O50	36	50	12	21,0	96	10,5	158,41 €

Dimensions in mm