



- Open housing for open bearing
- Bearing not supplied
- Material : Aluminium

Options

- Compatible with KB-OP and TK-OP ranges

Advantages

- Use with long supported shafts to avoid flexing.

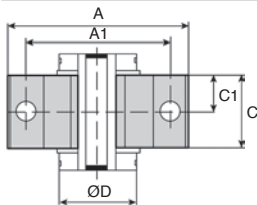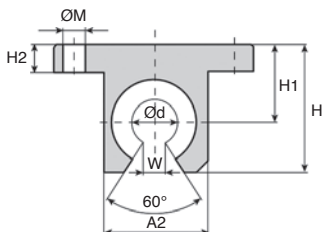

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft					
	Ød	ØD	H	C	A	A1 ±0.15
S2O12	12	22	28,0	20	52	42
S2O16	16	26	33,5	22	56	46
S2O20	20	32	42,0	28	70	58
S2O25	25	40	51,0	40	80	68
S2O30	30	47	60,0	48	88	76
S2O40	40	62	77,0	56	108	94
S2O50	50	75	93,0	72	135	116

Part number	C1	H1 ±0.015	H2	W	A2	ØM	Price
							each 1 to 4
S2O12	10	18	6	7,0	30	5,3	On request
S2O16	11	22	7	9,4	34	5,3	43,11 €
S2O20	14	25	8	10,0	40	6,4	45,05 €
S2O25	20	30	10	12,5	50	6,4	58,91 €
S2O30	24	35	10	12,5	58	6,4	79,92 €
S2O40	28	45	12	16,8	74	8,4	100,86 €
S2O50	36	50	12	21,0	96	10,5	141,95 €

*Depending on availability - Dimensions in mm

Our other products



PSG3
Spur gear - precision range, Pre-hardened Steel 35NCD6



KH
Linear bearing, Light



PR821
Idle sprocket for slat top chain, Ranges 821 and 805



DB
Steel bevel gear, 2:1




RFK38C
Hypoid gearbox - Stainless steel, up to 200 Nm




NCT
Square tube connector, Fixed angle



 ACLEPP
Right angled bracket for aluminium profile, 8 holes



 
PRT
Rotary table iglidur®, aluminium and stainless steel



MRS
Stainless steel metric section rack, Stainless steel



 DOMI50
Domino 50 adjustable slide, Slide DOMILINE 50 with counter and



ZR
Plastic rack, Delrin

 


J66
Spur gear coaxial gearbox, from 0.90 to 2.80 Nm - In-line

Complementary products



KB_OP
Open precision linear bearing, Precision - steel



FTSN
Supported shaft for linear guide, Steel shaft / Aluminium support



NSO
Housing for open linear bearing, Opened - long



TK_UUOP
Topball self-aligning linear bearing, Topball self-aligning