



- Open housing for open bearing
- Bearing not supplied
- Material : Aluminium

Options

- Compatible with KB-OP and TK-OP ranges

Advantages

- Use with long supported shafts to avoid flexing.

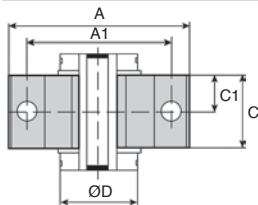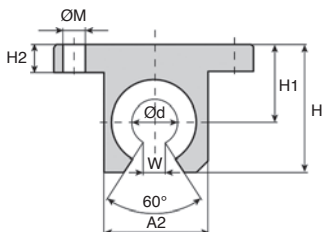

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft						A1 ±0.015
	Ød	ØD	H	C	A		
S2O12	12	22	28,0	20	52	42	
S2O16	16	26	33,5	22	56	46	
S2O20	20	32	42,0	28	70	58	
S2O25	25	40	51,0	40	80	68	
S2O30	30	47	60,0	48	88	76	
S2O40	40	62	77,0	56	108	94	
S2O50	50	75	93,0	72	135	116	

Part number	C1	H1 ±0.015	H2	W	A2	ØM	Price
							each 1 to 4
S2O12	10	18	6	7,0	30	5,3	On request
S2O16	11	22	7	9,4	34	5,3	43,11 €
S2O20	14	25	8	10,0	40	6,4	45,05 €
S2O25	20	30	10	12,5	50	6,4	58,91 €
S2O30	24	35	10	12,5	58	6,4	79,92 €
S2O40	28	45	12	16,8	74	8,4	100,86 €
S2O50	36	50	12	21,0	96	10,5	141,95 €

*Depending on availability - Dimensions in mm

Our other products



LWL

Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



RT61

Self-centering locking
Assembly,
Medium/low torque



CHMR63

Worm and wheel gear
reducer, up to 196
Nm



RBG

Wheel, Grey rubber -
Polypropylene rim



RT70

Self-centering locking
Assembly,
Medium/high torque



KK

Rounded end feather
key, Steel



NCT

Square tube
connector, Fixed
angle



DTR

Chain idler sprocket,
Chain idler sprocket -
Steel



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



DOMI120

Domino 120
adjustable slide, Slide



NANO

Speed controller 3A, 3
A



GGB

 
Female wing knob,
Fully threaded

Complementary products



KB_OP

Open precision linear
bearing, Precision -
steel



FTSN

Supported shaft for
linear guide, Steel
shaft / Aluminium
support



NSO

Housing for open
linear bearing,
Opened - long



TK_UUOP

Topball self-aligning
linear bearing, Topball
self-aligning