

Stainless steel

Pitch 4mm


- Pitch 4mm
- Roller diameter 2.5mm
- Material: stainless steel (303) Z10CNF 18.09

Accessory

- SUA-4 chain



Smallest size

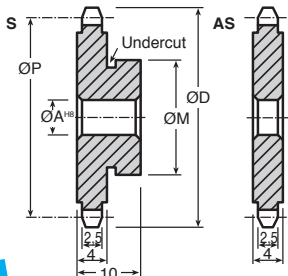

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Z Teeth	ØP	ØD	ØM	ØA	Undercut Ø x width	Price each 1 to 5	
							S	AS
S 4-10	10	12,94	14,71	12	4	8,00 x 2,5	11,97 €	9,54 €
S 4-11	11	14,20	16,02	12	4	8,00 x 2,5	12,72 €	10,11 €
S 4-12	12	15,45	17,32	12	4	8,00 x 2,5	13,36 €	10,61 €
S 4-13	13	16,71	18,62	12	4	9,05 x 2,5	14,03 €	11,18 €
S 4-14	14	17,97	19,92	12	4	10,33 x 2,5	15,21 €	12,13 €
S 4-15	15	19,23	21,21	12	4	11,60 x 2,5	15,59 €	12,43 €
S 4-16	16	20,50	22,50	12	4	-	16,56 €	13,17 €
S 4-17	17	21,76	23,79	12	4	-	17,93 €	14,30 €
S 4-18	18	23,06	25,08	12	4	-	18,72 €	14,94 €
S 4-19	19	24,29	26,37	12	4	-	19,56 €	15,92 €
S 4-20	20	25,57	27,65	15	5	-	20,47 €	16,32 €
S 4-21	21	26,83	28,94	15	5	-	21,33 €	16,98 €
S 4-23	23	29,37	31,50	15	5	-	22,22 €	17,71 €
S 4-25	25	31,91	34,06	15	5	-	23,09 €	18,43 €
S 4-27	27	34,45	36,62	15	5	-	25,18 €	20,14 €
S 4-30	30	38,26	40,45	15	5	-	28,11 €	22,44 €
S 4-33	33	42,08	44,29	15	5	-	29,62 €	23,67 €
S 4-35	35	44,62	46,84	15	5	-	30,47 €	24,88 €
S 4-36	36	45,89	48,12	15	5	-	31,30 €	24,60 €
S 4-38	38	48,43	50,67	15	5	-	31,52 €	25,19 €
S 4-40	40	50,98	53,22	20	6	-	31,76 €	25,36 €
S 4-42	42	53,52	55,77	20	6	-	31,88 €	25,48 €
S 4-44	44	56,07	58,32	20	6	-	32,17 €	25,75 €
S 4-48	48	61,12	63,42	20	6	-	32,47 €	25,97 €
S 4-50	50	63,66	65,98	20	6	-	32,77 €	26,18 €
S 4-60	60	76,39	78,72	20	6	-	34,06 €	27,22 €
S 4-80	80	101,86	104,20	20	6	-	105,59 €	102,81 €

Dimensions in mm

Our other products



SHA_PT
Handwheel with handle, Polyamide



PSPT
Flexible tube handle, PVC



SLB
Indexing plunger, steel class 5.8



MFB
Flexible bellows coupling, Aluminium and Bronze - With set screw



FF40
Offset spur gear reducer, from 59 to 210 Nm



GCB880
Curved track for slat top chain, Ranges 880 and 881



SLBS
Stainless steel indexing plunger, Stainless steel



UTKswc
Utilitrak® 3 wheels carriage, Series V precision steel wheel



SLBE
Indexing plunger - Spacer, Spacer for



MAX26
Motor-gearbox 12V and 24V DC, from



J53
Spur gear coaxial gearbox, from 0.43 to




DOMI50
Accessories, Plate

Complementary products



 SUA4
Single chain supplied by the metre, Steel



SBS_M
Single chain supplied by the metre, Stainless steel