

## Stainless steel

# Pitch 4mm


- Pitch 4mm
- Roller diameter 2.5mm
- Material: stainless steel (303) Z10CNF 18.09

### Accessory

- SUA-4 chain



**Smallest size**

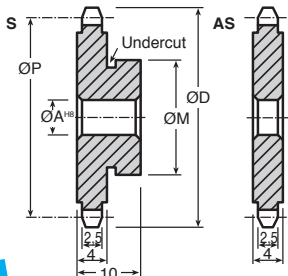

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Z Teeth	ØP	ØD	ØM	ØA	Undercut Ø x width	Price each 1 to 5	
							S	AS
S 4-10	10	12,94	14,71	12	4	8,00 x 2,5	11,97 €	9,54 €
S 4-11	11	14,20	16,02	12	4	8,00 x 2,5	12,72 €	10,11 €
S 4-12	12	15,45	17,32	12	4	8,00 x 2,5	13,36 €	10,61 €
S 4-13	13	16,71	18,62	12	4	9,05 x 2,5	14,03 €	11,18 €
S 4-14	14	17,97	19,92	12	4	10,33 x 2,5	15,21 €	12,13 €
S 4-15	15	19,23	21,21	12	4	11,60 x 2,5	15,59 €	12,43 €
S 4-16	16	20,50	22,50	12	4	-	16,56 €	13,17 €
S 4-17	17	21,76	23,79	12	4	-	17,93 €	14,30 €
S 4-18	18	23,06	25,08	12	4	-	18,72 €	14,94 €
S 4-19	19	24,29	26,37	12	4	-	19,56 €	15,92 €
S 4-20	20	25,57	27,65	15	5	-	20,47 €	16,32 €
S 4-21	21	26,83	28,94	15	5	-	21,33 €	16,98 €
S 4-23	23	29,37	31,50	15	5	-	22,22 €	17,71 €
S 4-25	25	31,91	34,06	15	5	-	23,09 €	18,43 €
S 4-27	27	34,45	36,62	15	5	-	25,18 €	20,14 €
S 4-30	30	38,26	40,45	15	5	-	28,11 €	22,44 €
S 4-33	33	42,08	44,29	15	5	-	29,62 €	23,67 €
S 4-35	35	44,62	46,84	15	5	-	30,47 €	24,88 €
S 4-36	36	45,89	48,12	15	5	-	31,30 €	24,60 €
S 4-38	38	48,43	50,67	15	5	-	31,52 €	25,19 €
S 4-40	40	50,98	53,22	20	6	-	31,76 €	25,36 €
S 4-42	42	53,52	55,77	20	6	-	31,88 €	25,48 €
S 4-44	44	56,07	58,32	20	6	-	32,17 €	25,75 €
S 4-48	48	61,12	63,42	20	6	-	32,47 €	25,97 €
S 4-50	50	63,66	65,98	20	6	-	32,77 €	26,18 €
S 4-60	60	76,39	78,72	20	6	-	34,06 €	27,22 €
S 4-80	80	101,86	104,20	20	6	-	105,59 €	102,81 €

Dimensions in mm

## Our other products



HTD5M\_25  
HTD Heavy duty timing pulley, HTD5 Steel



BABA  
Ball pin lifting ring, Steel



GMK17\_BR  
Clamp for guiding profile, Rounded only - single



RPCpl  
Fixed castor with plate, Steel - Polyamide



 
CNA-CNG  
Right angled mounting plate, Right angled mounting plate for clevis



FBL6000\_K1  
Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide 6 -...



NSO  
Housing for open linear bearing, Opened - long



SLVHlok  
Vertical toggle clamp, Vertical toggle clamp / horizontal foot



CM\_CO  
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



PSG3  
Spur gear - precision range, Case hardened steel 20NCD2




PRF\_CLIP\_45  
Cable clip for aluminium profile, For cable chute



UGAC\_UGET  
Connection for threaded actuator rod, Connection for threaded actuat...

## Complementary products

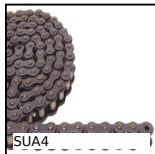

SUA4  
Single chain supplied by the metre, Steel



SBS\_M  
Single chain supplied by the metre, Stainless steel