

Sealed flange bearing unit for Food Industry

SBFop

With 4 fixing holes

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- **Materials**
 - 316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives

NEW !

open



 
Application

- For the highly challenging food and beverage industry


Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal.

Blue foodgrade cover seal





Blue foodgrade back seal

 

O-ring

DHRGS foodgrade hygienic seal

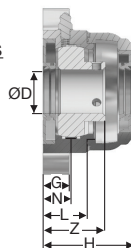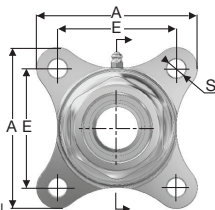

Type of load (N)	SBF 204	SBF 205	SBF 206	SBF 207	SBF 208	SBF 209	SBF 210
------------------	---------	---------	---------	---------	---------	---------	---------

P	15950	13000	18000	18500	19100	19350	19650
---	-------	-------	-------	-------	-------	-------	-------

P	10250	12150	17700	18500	19250	19350	19620
---	-------	-------	-------	-------	-------	-------	-------

P	3650	3350	3350	3520	3790	3850	3990
---	------	------	------	------	------	------	------

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	E	G	H	L	N	S	Z	Price each 1 to 3
SBF204/OP	20	88	64	15	51,9	24	15	12	33,0	135,74 €
SBF205/OP	25	95	70	15	52,4	25	16	12	35,5	155,14 €
SBF206/OP	30	108	83	15	58,7	29	18	12	40,0	179,38 €
SBF207/OP	35	117	92	17	62,4	31	19	14	42,5	208,46 €
SBF208/OP	40	130	102	17	70,7	32	21	16	46,0	252,10 €
SBF209/OP	45	135	105	18	69,2	33	22	16	53,7	300,58 €
SBF210/OP	50	143	111	20	72,7	38	25	16	55,0	358,75 €

Dimensions in mm

HPC

WEB
04/2024

www.hpceurope.com


Tel. +33(0)4 37 496 496

Sealed flange bearing unit for Food Industry

With 4 fixing holes

SBFCL

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- Materials
 - 316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives

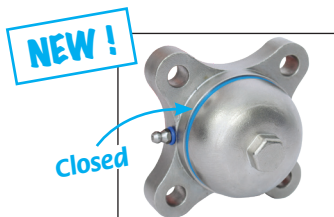


Application

- For the highly challenging food and beverage industry

Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal.


 
Blue foodgrade cover seal



Blue foodgrade back seal



O-ring
DHRGS foodgrade hygienic seal

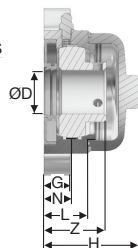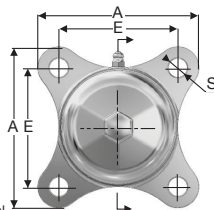

Type	SBF	SBF	SBF	SBF	SBF	SBF	SBF
of load (N)	204	205	206	207	208	209	210

P	15950	13000	18000	18500	19100	19350	19650
---	-------	-------	-------	-------	-------	-------	-------

P	10250	12150	17700	18500	19250	19350	19620
---	-------	-------	-------	-------	-------	-------	-------

P	3650	3350	3350	3520	3790	3850	3990
---	------	------	------	------	------	------	------

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	E	G	H	L	N	S	Z	Price each 1 to 3
SBF204/CL	20	88	64	15	54,2	24	15	12	33,0	126,05 €
SBF205/CL	25	95	70	15	54,7	25	16	12	35,5	140,59 €
SBF206/CL	30	108	83	15	61,0	29	18	12	40,0	174,53 €
SBF207/CL	35	117	92	17	64,7	31	19	14	42,5	198,77 €
SBF208/CL	40	130	102	17	70,0	32	21	16	46,0	237,55 €
SBF209/CL	45	135	105	18	71,5	33	22	16	53,7	286,03 €
SBF210/CL	50	143	111	20	71,0	38	25	16	55,0	353,90 €

Dimensions in mm

Sealed flange bearing unit for Food Industry

SBFLOP

With 2 fixing holes

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- **Materials**
 - 316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives

NEW !

open



 
Application

- For the highly challenging food and beverage industry


Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal

Blue foodgrade cover seal





Blue foodgrade back seal

 

O-ring

DHRGS foodgrade hygienic s

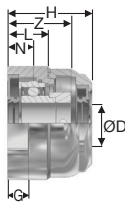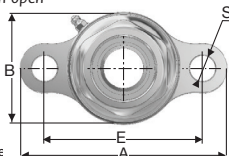

Type of load (N)	SBFL 204	SBFL 205	SBFL 206	SBFL 207	SBFL 208	SBFL 209	SBFL 210
------------------	----------	----------	----------	----------	----------	----------	----------

	11750	11375	16450	16900	17350	17600	17950
--	-------	-------	-------	-------	-------	-------	-------

	11000	13850	13350	13950	14050	14300	14550
--	-------	-------	-------	-------	-------	-------	-------

	8500	1100	14200	14900	15150	15350	15650
--	------	------	-------	-------	-------	-------	-------

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	B	E	G	H	L	N	S	Z	Price each 1 to 3
SBFL204/OP	20	115	65	90	11	51,9	24	15	12	33,0	130,90 €
SBFL205/OP	25	130	70	99	13	52,4	25	16	16	35,5	145,44 €
SBFL206/OP	30	148	80	117	13	58,7	29	18	16	40,0	164,83 €
SBFL207/OP	35	161	90	130	15	62,4	31	19	16	42,5	193,92 €
SBFL208/OP	40	175	100	144	15	70,7	32	21	16	46,0	237,55 €
SBFL209/OP	45	188	110	148	16	69,2	33	22	19	53,7	276,34 €
SBFL210/OP	50	197	120	157	16	72,7	38	22	19	55,0	324,82 €

Dimensions in mm

HPC

WEB
04/2024

www.hpceurope.com

Tel. +33(0)4 37 496 496

Sealed flange bearing unit for Food Industry

With 2 fixing holes

SBFLCL

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- Materials
 - 316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives



 
Application

- For the highly challenging food and beverage industry

Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal

Blue foodgrade cover seal




Blue foodgrade back seal



O-ring

DHRGS foodgrade hygienic seal

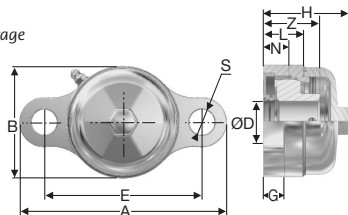

Type	SBFL 204	SBFL 205	SBFL 206	SBFL 207	SBFL 208	SBFL 209	SBFL 210
of load (N)							

	11750	11375	16450	16900	17350	17600	17950
--	-------	-------	-------	-------	-------	-------	-------

	11000	13850	13350	13950	14050	14300	14550
--	-------	-------	-------	-------	-------	-------	-------

	8500	1100	14200	14900	15150	15350	15650
--	------	------	-------	-------	-------	-------	-------

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	B	E	G	H	L	N	S	Z	Price each 1 to 3
SBFL204/CL	20	115	65	90	11	54,2	24	15	12	33,0	121,20 €
SBFL205/CL	25	130	70	99	13	54,7	25	16	16	35,5	130,90 €
SBFL206/CL	30	148	80	117	13	61,0	29	18	16	40,0	155,14 €
SBFL207/CL	35	161	90	130	15	64,7	31	19	16	42,5	184,22 €
SBFL208/CL	40	175	100	144	15	70,0	32	21	16	46,0	223,01 €
SBFL209/CL	45	188	110	148	16	71,5	33	22	19	53,7	261,79 €
SBFL210/CL	50	197	120	157	16	71,0	38	22	19	55,0	315,12 €


Dimensions in mm

Sealed flange bearing unit for Food Industry

SBFBop

With 3 offset fixing points

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- **Materials**
 - 316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives

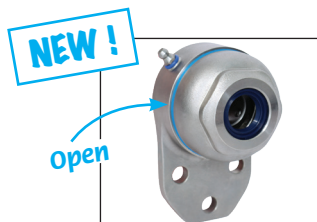


Application

- For the highly challenging food and beverage industry

Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal.

Blue foodgrade cover seal

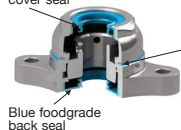


Blue foodgrade back seal



O-ring

DHRGS foodgrade hygienic seal

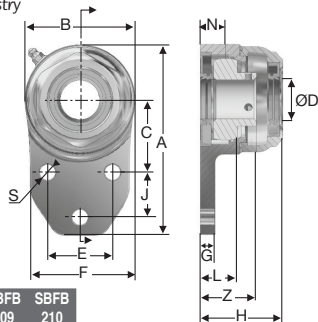

Type of load (N)	SBFB 204	SBFB 205	SBFB 206	SBFB 207	SBFB 208	SBFB 209	SBFB 210
P	-	-	-	7200	9100	12200	12900
P	-	-	-	9200	11100	11800	11900
P	-	-	-	2600	2800	2900	3100

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	B	C	E	F	G	H	J	L	N	S	Z	Price each 1 to 3
SBFB204/OP	20	108	65	43,3	38,1	60,3	8,0	51,9	22,0	24	15	10	33,0	140,59 €
SBFB205/OP	25	121	70	46,0	41,3	63,5	9,5	52,9	28,5	25	16	10	35,5	164,83 €
SBFB206/OP	30	137	80	52,4	47,6	70,0	9,5	58,7	31,7	29	18	10	40,0	184,22 €
SBFB207/OP	35	156	90	60,3	50,8	83,0	12,7	62,4	31,7	31	19	13	42,5	227,86 €
SBFB208/OP	40	164	100	60,3	50,0	78,0	15,9	70,7	41,3	32	21	12	46,0	271,49 €
SBFB209/OP	45	176	110	65,0	54,0	80,0	18,3	69,2	42,9	33	22	12	53,7	324,82 €
SBFB210/OP	50	190	120	74,6	70,0	102,0	12,7	72,5	41,3	38	22	13	55,0	373,30 €

Dimensions in mm

Sealed flange bearing unit for Food Industry

With 3 offset fixing points

SBFBCL

- **Sealed bearing**
- Massive, without retention surface
- Resistant to frequent washing and detergents
- Materials
 - B316 stainless steel housing
 - 440 stainless steel bearing
 - Optical and detectable blue hygienic seals
- Complies with EHEDGE hygiene directives

 
 
Application

- For the highly challenging food and beverage industry


Info

- Stainless steel bearings for the food and beverage industry are completely sealed units with an open or closed cover and a rear seal.

Blue foodgrade cover seal



Blue foodgrade back seal

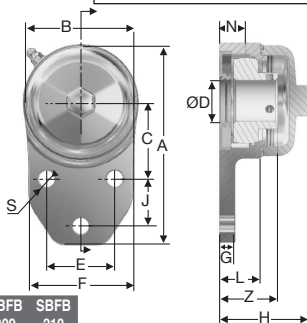

Type of load (N)	SBFB 204	SBFB 205	SBFB 206	SBFB 207	SBFB 208	SBFB 209	SBFB 210
	-	-	-	7200	9100	12200	12900
	-	-	-	9200	11100	11800	11900
	-	-	-	2600	2800	2900	3100


DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part Number	Diameter ØD	A	B	C	E	F	G	H	J	L	N	S	Z	Price each 1 to 3
SBFB204/CL	20	108	65	43,3	38,1	60,3	8,0	54,2	22,0	24	15	10	33,0	130,90 €
SBFB205/CL	25	121	70	46,0	41,3	63,5	9,5	54,7	28,5	25	16	10	35,5	150,29 €
SBFB206/CL	30	137	80	52,4	47,6	70,0	9,5	61,0	31,7	29	18	10	40,0	179,38 €
SBFB207/CL	35	156	90	60,3	50,8	83,0	12,7	64,7	31,7	31	19	13	42,5	218,16 €
SBFB208/CL	40	164	100	60,3	50,0	78,0	15,9	70,0	41,3	32	21	12	46,0	256,94 €
SBFB209/CL	45	176	110	65,0	54,0	80,0	18,3	71,5	42,9	33	22	12	53,7	310,27 €
SBFB210/CL	50	190	120	74,6	70,0	102,0	12,7	71,0	41,3	38	22	13	55,0	363,60 €

Dimensions in mm

 Our other products



QNJ
Single row cylindrical roller bearing, Single flange on inner ring



TBEBASE10
Economic mini-table with trapezoidal leadscrew, 1kg




DOMI30
Connecting kits, XZ linking kit



GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel



T39_T49
Extension spring in metre length stainless steel, by the metre

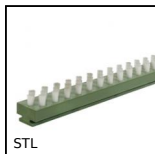

STL
Guidance brush - Brush, Brush



LVT
Miniature motorised actuator 1A, 1 amper



PCS37SS
Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)



CHALss
Piano hinge, Stainless steel



SLV
Vertical toggle clamp, Vertical Lever Clamp -



P70
Worm and wheel gear reducer, up to 164



PCS37
Chain sprocket - steel, 9.525mm (DIN06B-1)

Complementary products



UCFL_SS
Stainless steel flanged bearing, Stainless steel



UCFL_PBT
Stainless steel/Polymer flanged bearing, Polymer and stainless steel



UCFL_PBT
Stainless steel/Polymer flanged bearing, Polymer and stainless steel



UCFL
Cast iron flanged bearing, Cast iron