


Single chain supplied by the metre **Ste** **DIN** **Stock**

Pitch 4.0 to 19.05 mm

Steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of either 1 or 5 metre lengths depending on model

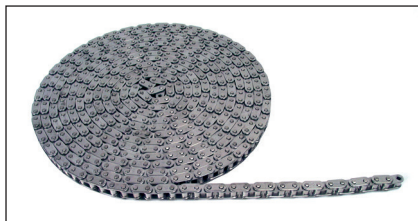


Accessories

- TRE arm and PTR sprocket idlers
- Roll-Ring® RLR idler

Option

- American pitch (ASA) available on request

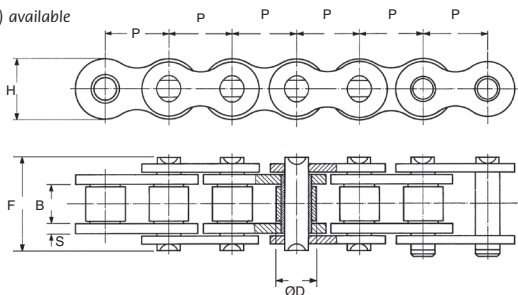

DISCOUNTS

No. metres	1+	10+	25+	45+
Discount	List	-5%	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Stock*	Price per metre
SUA-4	-	4,00	2,70	2,50	6,8	4,1	-	1,8	1 metre	✓	183,45 €
SUA-6/M	04-1	6,00	2,80	4,00	7,8	5,0	0,60	3	5 metres	✓	12,53 €
SUA-250/M	-	6,35	3,30	3,30	8,0	6,0	-	4	5 metres	✓	15,35 €
SBR-8/M	05B-1	8,00	3,00	5,00	8,9	7,1	0,80	5	5 metres	✓	10,40 €
SBR-375/M	06B-1	9,52	5,72	6,35	14,1	8,2	1,30	9	5 metres	✓	8,01 €
SBR-500/M	08B-1	12,70	7,75	8,51	18,2	11,8	1,60	18	5 metres	✓	7,74 €
SBR-625/M	10B-1	15,88	9,65	10,16	20,9	14,7	1,70	22,4	5 metres	✓	9,65 €
SBR-750/M	12B-1	19,05	11,68	12,07	24,2	16,0	1,85	29	5 metres	✓	12,42 €

*Depending on availability - Dimensions in mm

Steel

Pitch
4.0 to
19.05 mm

- Quick fitting
- Connecting link: e.g.: SUA-4/L
Offset link: from pitch of 9,52mm,
e.g.: SBR-375/LC
- Not sold individually,
please contact us for details

Accessories

 
- Compatible with SUA and SBR chains




SUA/L SBR/L



SBR/LC



Connecting link

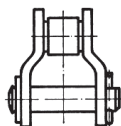

Offset link

DISCOUNTS

Qty	1+	10+	25+	45+
Disc.	List	-5%	-10%	On request

Part number		DIN	Pitch P (mm)	For chain	Stock*	Stock*	Price each 1 to 9	
Connecting link	Offset link				Connecting link	Offset link	Connecting link	Offset link
SUA-4/L	-	-	4,00	SUA-4	✓	-	10,74 €	-
SUA-6/L	-	04-1	6,00	SUA-6	✓	-	0,89 €	-
SUA-250/L	-	-	6,35	SUA-250	✓	-	1,03 €	-
SBR-8/L	-	05B-1	8,00	SBR-8	✓	-	0,89 €	-
SBR-375/L	SBR-375/LC	06B-1	9,53	SBR-375	✓	✓	0,74 €	1,44 €
SBR-500/L	SBR-500/LC	08B-1	12,70	SBR-500	✓	✓	1,04 €	1,44 €
SBR-625/L	SBR-625/LC	10B-1	15,88	SBR-625	✓	✓	0,74 €	1,75 €
SBR-750/L	SBR-750/LC	12B-1	19,05	SBR-750	✓	✓	1,13 €	2,27 €

*Depending on availability - Dimensions in mm

Single chain supplied by the metre **Sta** **DIN** **Stock**


Pitch 9.52 to 19.05 mm

Stainless steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of 5 metres

Accessories

- BTE/SS arm and PTR/SS idler
- Roll-Ring® RLR idler

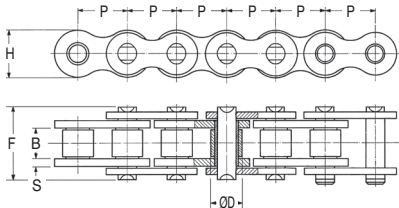

DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Price per metre
SBS-375/M 06B-1		9,52	5,72	6,35	14,0	8,3	1,3	9	5 metres	✓ 32,72 €
SBS-500/M 08B-1		12,70	7,75	8,51	18,7	11,8	1,6	18	5 metres	✓ 37,77 €
SBS-625/M 10B-1		15,88	9,65	10,16	21,1	14,7	1,70	22,4	5 metres	✓ 52,66 €
SBS-750/M 12B-1		19,05	11,68	12,07	24,5	16,1	1,85	29	5 metres	✓ 60,38 €

*Depending on availability - Dimensions in mm


Stainless steel

Pitch 9.52 to 19.05 mm

- Quick fitting
- Connecting link: e.g. **SBS-375/L**
Offset link: e.g. **SBS-375/LC**
- Not sold individually, please contact us for details


Accessorie

- Compatible with **SBS** stainless steel chains

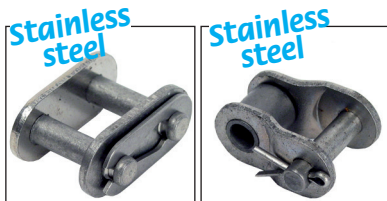

SBS/L

 SBS/LC



Connecting link

Offset link

DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number		DIN	Pitch P (mm)	For chain	Stock*	Stock*	Price each 1 to 9	
Connecting link	Offset link				Connecting link	Offset link	Connecting link	Offset link
SBS-375/L	SBS-375/LC	06B-1	9,52	SBS-375	✓	✓	2,24 €	2,78 €
SBS-500/L	SBS-500/LC	08B-1	12,70	SBS-500	✓	✓	2,63 €	3,04 €
SBS-625/L	SBS-625/LC	10B-1	15,88	SBS-625	✓	✓	4,23 €	3,21 €
SBS-750/L	SBS-750/LC	12B-1	19,05	SBS-750	✓	✓	2,18 €	6,88 €

*Depending on availability - Dimensions in mm