


# Single chain supplied by the metre

## Pitch 4.0 to 19.05 mm

## Steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of either 1 metre, 5 metres (in box) or in chain reel (50 metres or 30 metres) lengths depending on model

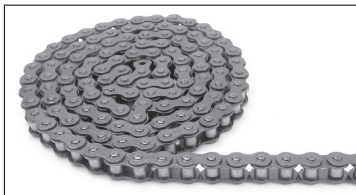

### Option


- American pitch (ASA) available on request

### Accessories

- TRE arm and PTR sprocket idlers
- Roll-Ring® RLR idler (tome 4 p.128 to p.141)



New in chain reel

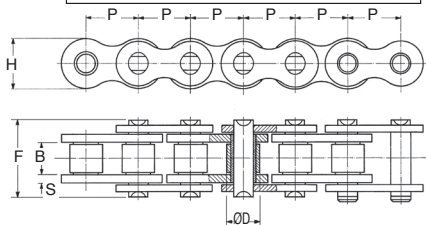

### DISCOUNTS **A**

No. metres	1+	10+	25+	55+
Discount	List	-5%	-10%	On request

### DISCOUNTS **B**

No. metres	1+	100+
Discount	List	On request

Part number	Pitch DIN	Pitch		Roller ØD	F	H	S	Breaking strength (kN)	Sold in multiples of	Price per metre
		P (mm)	B (mm)							
SUA-4	-	4,00	2,70	2,50	6,8	4,1	-	1,8	1 metre	✓ <b>A</b> 250,08 €
SUA-6/M	04-1	6,00	2,80	4,00	7,8	5,0	0,60	3	5 mètres	✓ <b>A</b> 12,77 €
SUA-250/M	-	6,35	3,30	3,30	8,0	6,0	-	4	5 mètres	✓ <b>A</b> 15,64 €
SBR-8/M	05B-1	8,00	3,00	5,00	8,9	7,1	0,80	5	5 mètres	✓ <b>A</b> 12,74 €
SBR-375/M	06B-1	9,52	5,72	6,35	14,1	8,2	1,30	9	5 mètres	✓ <b>A</b> 8,16 €
SBR-500/M	08B-1	12,70	7,75	8,51	18,2	11,8	1,60	18	5 mètres	✓ <b>A</b> 7,89 €
SBR-625/M	10B-1	15,88	9,65	10,16	20,9	14,7	1,70	22,4	5 mètres	✓ <b>A</b> 9,84 €
SBR-750/M	12B-1	19,05	11,68	12,07	24,2	16,0	1,85	29	5 mètres	✓ <b>A</b> 12,66 €

### In chain reel

SUA-6/M/T	04-1	6,00	2,80	4,00	7,8	5,0	0,60	3	50 mètres	- <b>B</b> 11,19 €
SBR-8MT	05B-1	8,00	3,00	5,00	8,9	7,1	0,80	5	50 mètres	- <b>B</b> 10,18 €
SBR-375/M/T	06B-1	9,52	5,72	6,35	14,1	8,2	1,30	9	50 mètres	- <b>B</b> 6,24 €
SBR-500/M/T	08B-1	12,70	7,75	8,51	18,2	11,8	1,60	18	50 mètres	- <b>B</b> 5,93 €
SBR-625/M/T	10B-1	15,88	9,65	10,16	20,9	14,7	1,70	22,4	30 mètres	- <b>B</b> 8,11 €
SBR-750/M/T	12B-1	19,05	11,68	12,07	24,2	16,0	1,85	29	30 mètres	- <b>B</b> 11,49 €

\*Depending on availability - Dimensions in mm

## Steel

# Pitch 4.0 to 19.05 mm

- Quick fitting
- Connecting link: e.g.: SUA-4/L  
Offset link: from pitch of 9,52mm,  
e.g.: SBR-375/LC
- Not sold individually,  
please contact us for details

### Accessories

 
- Compatible with SUA and SBR chains  
([tome 4](#) p.120)




SUA/L SBR/L



SBR/LC



Connecting link

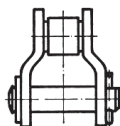

Offset link

### DISCOUNTS

Qty	1+	10+	25+	45+
Disc.	List	-5%	-10%	On request

Part number		DIN	Pitch P (mm)	For chain	Stock*	Stock*	Price each 1 to 9	
Connecting link	Offset link				Connecting link	Offset link	Connecting link	Offset link
SUA-4/L	-	-	4,00	SUA-4	✓	-	10,74 €	-
SUA-6/L	-	04-1	6,00	SUA-6	✓	-	0,89 €	-
SUA-250/L	-	-	6,35	SUA-250	✓	-	1,03 €	-
SBR-8/L	-	05B-1	8,00	SBR-8	✓	-	0,89 €	-
SBR-375/L	SBR-375/LC	06B-1	9,53	SBR-375	✓	✓	0,74 €	1,44 €
SBR-500/L	SBR-500/LC	08B-1	12,70	SBR-500	✓	✓	1,04 €	1,44 €
SBR-625/L	SBR-625/LC	10B-1	15,88	SBR-625	✓	✓	0,74 €	1,75 €
SBR-750/L	SBR-750/LC	12B-1	19,05	SBR-750	✓	✓	1,13 €	2,27 €

\*Depending on availability - Dimensions in mm

# Single chain supplied by the metre **Sta** **DIN** **Stock**



## Pitch 9.52 to 19.05 mm

## Stainless steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of 5 metres

### Accessories

- Chain tensioner section (tome 4 p.128 to p.141)

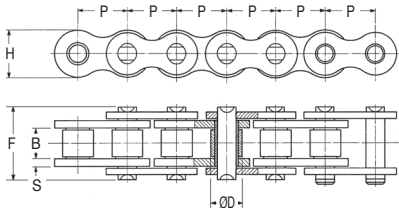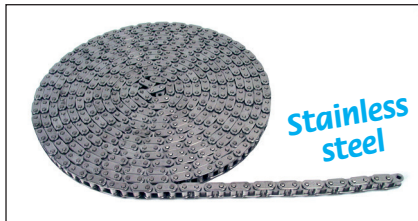

### DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Price per metre
SBS-375/M 06B-1		9,52	5,72	6,35	14,0	8,3	1,3	9	5 metres	✓ 32,72 €
SBS-500/M 08B-1		12,70	7,75	8,51	18,7	11,8	1,6	18	5 metres	✓ 37,77 €
SBS-625/M 10B-1		15,88	9,65	10,16	21,1	14,7	1,70	22,4	5 metres	✓ 52,66 €
SBS-750/M 12B-1		19,05	11,68	12,07	24,5	16,1	1,85	29	5 metres	✓ 60,38 €

\*Depending on availability - Dimensions in mm


## Stainless steel

## Pitch 9.52 to 19.05 mm

- Quick fitting
- Connecting link: e.g. **SBS-375/L**  
Offset link: e.g. **SBS-375/LC**
- Not sold individually, please contact us for details


### Accessories

- Compatible with **SBS** stainless steel chains (**tome 4 p.122**)

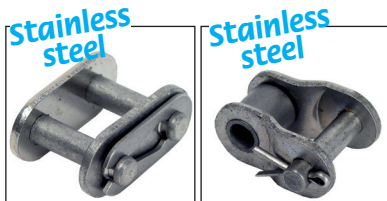

SBS/L

 SBS/LC



Connecting link

Offset link

### DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number		DIN	Pitch P (mm)	For chain	Stock*	Stock*	Price each 1 to 9	
Connecting link	Offset link				Connecting link	Offset link	Connecting link	Offset link
SBS-375/L	SBS-375/LC	06B-1	9,52	SBS-375	✓	✓	2,24 €	2,78 €
SBS-500/L	SBS-500/LC	08B-1	12,70	SBS-500	✓	✓	2,63 €	3,04 €
SBS-625/L	SBS-625/LC	10B-1	15,88	SBS-625	✓	✓	4,23 €	3,21 €
SBS-750/L	SBS-750/LC	12B-1	19,05	SBS-750	✓	✓	2,18 €	6,88 €

\*Depending on availability - Dimensions in mm