



Pitch 9.52 to 19.05 mm

Stainless steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of 5 metres

Accessories

- BTE/SS arm and PTR/SS idler
- Roll-Ring® RLR idler

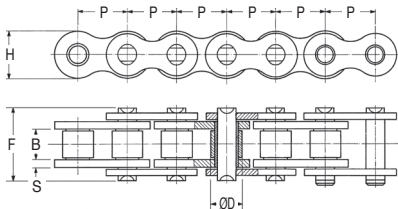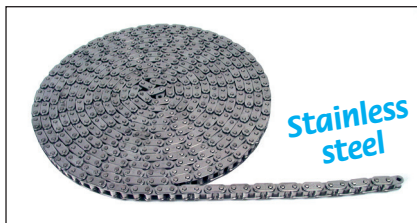

DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Stock*	Price per metre
SBS-375/M 06B-1		9,52	5,72	6,35	14,0	8,3	1,3	9	5 metres	✓	32,72 €
SBS-500/M 08B-1		12,70	7,75	8,51	18,7	11,8	1,6	18	5 metres	✓	37,77 €
SBS-625/M 10B-1		15,88	9,65	10,16	21,1	14,7	1,70	22,4	5 metres	✓	52,66 €
SBS-750/M 12B-1		19,05	11,68	12,07	24,5	16,1	1,85	29	5 metres	✓	60,38 €

*Depending on availability - Dimensions in mm

Our other products



ZBconique

Machined plastic
bevel gear, 1:1



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880



CHM63-MOT

Asynchronous AC
motorgearboxes 0.37
to 1.5kW, 0.37 to
1.5kW



PTA40

Articulated foot with
solid base foot Ø 40,
30000N



GBS

Nut for ballscrew,
Flanged ballscrew nut




RAS

90°ball and socket
joints DIN71802, Steel



DB

Steel bevel gear, 2:1

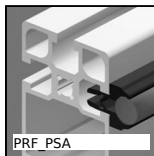

PRF PSA

Shaft support for
aluminium profile,
Shaft support



HW_HT

Half-rail guide, Rail



PRF3232

Standard aluminium
profile, 32 x 32 mm



VELM6

Screw-on base for
hook-and-loop strip,



M1

Worm and wheel set,
Bronze

Complementary products



SBS_L

Chain link, Stainless
steel



SBS_L

Chain link, Stainless
steel



BTESS

Universal stainless
steel arm for
tensioner, For use in
hostile envi...



SBRtool

Chain tool, Drive
chain maintenance
tools