

Single chain supplied by the metre **Sta** **DIN** **Stock**



Pitch 9.52 to 19.05 mm

Stainless steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of 5 metres

Accessories

- BTE/SS arm and PTR/SS idler
- Roll-Ring® RLR idler

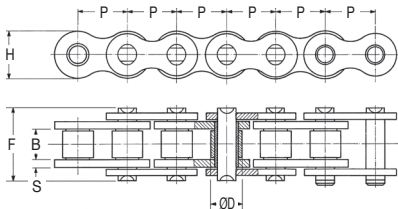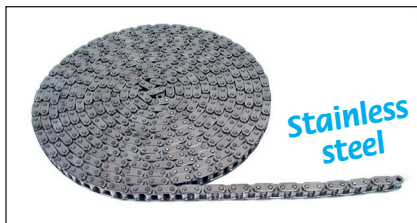

DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Stock*	Price per metre
SBS-375/M 06B-1		9,52	5,72	6,35	14,0	8,3	1,3	9	5 metres	✓	32,72 €
SBS-500/M 08B-1		12,70	7,75	8,51	18,7	11,8	1,6	18	5 metres	✓	37,77 €
SBS-625/M 10B-1		15,88	9,65	10,16	21,1	14,7	1,70	22,4	5 metres	✓	52,66 €
SBS-750/M 12B-1		19,05	11,68	12,07	24,5	16,1	1,85	29	5 metres	✓	60,38 €

*Depending on availability - Dimensions in mm

Our other products



CFF_SS

Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...



CAP821

Slat top chain acetal, Large range 821



V3RA_PTR

3-spoked handwheel with foldable handle, Polyamide



GE14

Toggle latches, With padlock-holder



GSI_A

Gas control screw for gas spring, Gas control screw



GE1006

Elastic ringed latch, Hooks into a slot



PRF4590

Standard aluminium profile, 45 x 90 mm



DOM150

Accessories, Turntable



RFV50

Stainless steel worm and wheel gearbox,



SERB

Cam latch, Cam latch



CAP881

Side flexing slim slat top chain stainless



LRM

Trapezoidal bronze nut, Bronze - 1 thread

Complementary products



SBS_L

Chain link, Stainless steel



SBS_L

Chain link, Stainless steel



BTESS

Universal stainless steel arm for tensioner, For use in hostile envi...



SBRtool

Chain tool, Drive chain maintenance tools