

Flat cable clamp






SCA

Suitable for cable Ø2-Ø6mm

- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:
Clamp: Zinc plated steel Fe360B

Info.

- Not sold individually, please contact us for details

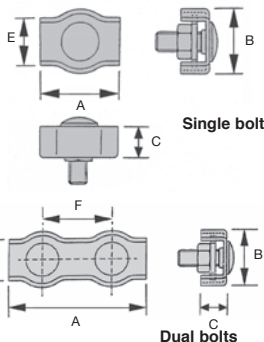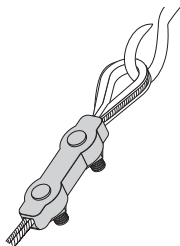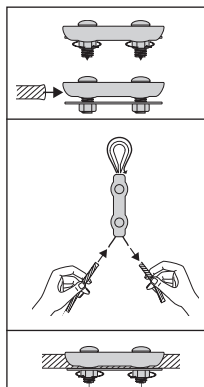

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
Single bolts									
SCA1-02	2	18	12	5	8	-	0,50	✓	0,42 €
SCA1-03	3	20	14	7	10	-	0,75	✓	0,58 €
SCA1-04	4	22	17	8	12	-	1,15	✓	0,66 €
SCA1-05	5	26	21	9	14	-	2,00	✓	0,80 €
SCA1-06	6	30	25	10	17	-	3,00	✓	0,87 €
Dual bolts									
SCA2-02	2	37	13	5	8	20	1,10	✓	0,72 €
SCA2-03	3	40	15	7	10	21	1,50	✓	0,80 €
SCA2-04	4	43	17	7	13	22	2,50	✓	0,91 €
SCA2-05	5	52	22	9	15	27	4,00	✓	1,44 €
SCA2-06	6	60	26	9	18	33	6,00	✓	1,65 €

*Depending on availability - Dimensions in mm

Our other products



TBEBASE10

Economic mini-table with trapezoidal leadscrew, 1kg



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



UGAC_UGET

Actuator guide kit, Coupling for threaded cylinder end



BLHT50

Right angled gearbox, from 11.50 to 30 Nm



Q6

Deep groove ball bearing, Steel



 
PRFRTR

Cross connector for aluminium profile, Cross connector



HK

Manual locking clamp, Manual locking clamp T



M2

Worm and wheel set, Machined plastic (delrin)



CCLSS

Stainless steel wire thimble, Stainless steel



BOX-SHNA

 
Hexagonal nut - DIN934, Box set of steel nuts



PML

Solid foot mount for heavy loads, Ø 100, 120 or 150

Complementary products



CAB

Galvanised steel cable, Galvanised steel



SCA

Flat cable clamp, Steel



CCL

Standard wire thimble, Steel



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

