

# Flat cable clamp






## SCA

Suitable for cable Ø2-Ø6mm

- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:  
Clamp: Zinc plated steel Fe360B

### Info.

- Not sold individually, please contact us for details

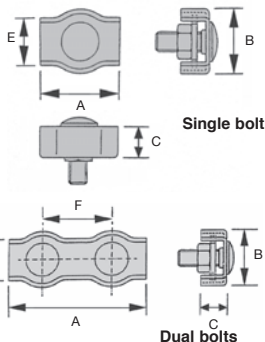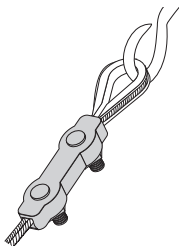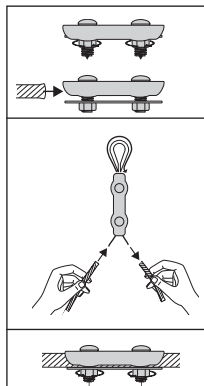

### DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
<b>Single bolts</b>									
SCA1-02	2	18	12	5	8	-	0,50	✓	0,42 €
SCA1-03	3	20	14	7	10	-	0,75	✓	0,58 €
SCA1-04	4	22	17	8	12	-	1,15	✓	0,66 €
SCA1-05	5	26	21	9	14	-	2,00	✓	0,80 €
SCA1-06	6	30	25	10	17	-	3,00	✓	0,87 €
<b>Dual bolts</b>									
SCA2-02	2	37	13	5	8	20	1,10	✓	0,72 €
SCA2-03	3	40	15	7	10	21	1,50	✓	0,80 €
SCA2-04	4	43	17	7	13	22	2,50	✓	0,91 €
SCA2-05	5	52	22	9	15	27	4,00	✓	1,44 €
SCA2-06	6	60	26	9	18	33	6,00	✓	1,65 €

\*Depending on availability - Dimensions in mm

## Our other products



Modular cylindrical brush, Tampico bristles



Spur gear coaxial gearbox, from 10 to 35 Nm - Inline



Eco. range steel bevel gear, 4:1



Parallel axis helical gear, Steel 20NCD2



Cap nut Hygienic Design®, Compact



H Type Guide units, For Ø25 actuators



Right angled gearbox, from 7.70 to 20 Nm



Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



 
Telescopic drawer,



Support for Ø12mm Prox detector, Ø12




Steel spur gear, Steel 20NCD2



Plastic deep groove ball bearing, Plastic - balls material : staine...

## Complementary products

 

Galvanised steel cable, Galvanised steel



Flat cable clamp, Steel



Standard wire thimble, Steel