

Flat cable clamp






SCA

Suitable for cable Ø2-Ø6mm

- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:
Clamp: Zinc plated steel Fe360B

Info.

- Not sold individually, please contact us for details

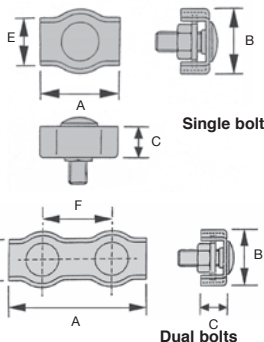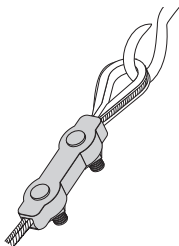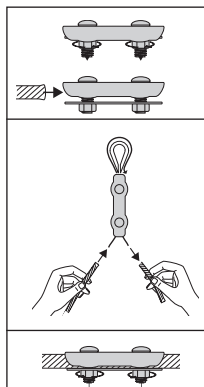

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
Single bolts									
SCA1-02	2	18	12	5	8	-	0,50	✓	0,42 €
SCA1-03	3	20	14	7	10	-	0,75	✓	0,58 €
SCA1-04	4	22	17	8	12	-	1,15	✓	0,66 €
SCA1-05	5	26	21	9	14	-	2,00	✓	0,80 €
SCA1-06	6	30	25	10	17	-	3,00	✓	0,87 €
Dual bolts									
SCA2-02	2	37	13	5	8	20	1,10	✓	0,72 €
SCA2-03	3	40	15	7	10	21	1,50	✓	0,80 €
SCA2-04	4	43	17	7	13	22	2,50	✓	0,91 €
SCA2-05	5	52	22	9	15	27	4,00	✓	1,44 €
SCA2-06	6	60	26	9	18	33	6,00	✓	1,65 €

*Depending on availability - Dimensions in mm

Our other products



PW_PWG05

Worm - precision range, Steel



BTCW

Cap for square tube to be welded, To be welded



BAC105

Storage bin, 8mm



VRC2

Retaining clamp, dual sided, Dual sided



PSG15

Spur gear - precision range, Stainless steel 303



 
GB-RA

Brass spur gear, Brass CuZn39Pb3



UCP_PBT

Stainless/Polymer pillow block bearing, Polymer and stainless steel



PF20

Worm and wheel gear reducer, up to 5 Nm



RPCtc

Swivel castor with central hole, Steel -



HRV

V- rail guidance Simple Select®



AF

 
Shaft clamp with keyway, Set screw



PW_PWG1


Wheel - precision range, Bronze

Complementary products



CAB

 Galvanised steel cable, Galvanised steel



SCA

Flat cable clamp, Steel



CCL

Standard wire thimble, Steel



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

