



- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:  
Clamp: Stainless steel 316 plated steel Fe360B

**Info.**

- Not sold individually, please contact us for details

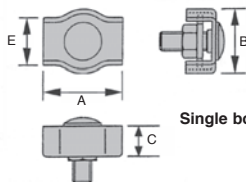

Single bolt

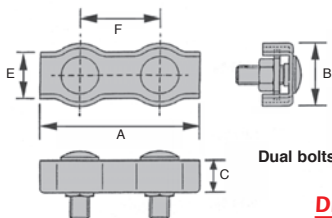

Dual bolts

**DISCOUNTS**

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
<b>Single bolts</b>									
SCA1-02/SS	2	15	11	5,0	7	-	0,438	✓	1,19 €
SCA1-03/SS	3	17	14	6,0	9	-	0,520	✓	1,52 €
SCA1-04/SS	4	20	17	7,0	11	-	1,090	✓	1,87 €
SCA1-05/SS	5	25	19	8,5	13	-	1,442	✓	2,52 €
SCA1-06/SS	6	30	24	10,0	16	-	2,630	✓	4,09 €
<b>Dual bolts</b>									
SCA2-02/SS	2	30	11	5,0	7	15	0,926	✓	1,95 €
SCA2-03/SS	3	34	14	6,0	9	17	1,230	✓	2,59 €
SCA2-04/SS	4	40	17	7,0	11	19	2,290	✓	3,53 €
SCA2-05/SS	5	50	19	8,5	13	25	3,090	✓	4,48 €
SCA2-06/SS	6	60	24	10,0	16	30	5,440	✓	6,28 €

\*Depending on availability - Dimensions in mm

## Our other products



MET  
Cylindrical sintered bronze bush, Self-lubricating sintered bronze



BLH20  
Right angled gearbox, from 0.53 to 1.77



SFWR  
End support, Surface mounting



PLN  
Cylindrical spacer, Thermoplastic



CMA  
Eye bolt, Steel



GCH  
Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



ASH  
Hoist ring for welding, for straight lifts - for welding



HSS  
Shoulder screw ISO7379, Hardened Steel class 12.9



MHX  
Hexagonal threaded sleeve, Hexagonal - steel



PRF\_JL5  
Lip seal for panel, Door seal - Ø 5mm



GAL21  
Conveyor wheel, Plastic




FF20  
Offset spur gear reducer, from 5.80 to 23 Nm

## Complementary products



 SCA\_SS  
Stainless steel flat cable clamp, Stainless steel



CAB  
Stainless steel cable, Stainless steel



CCLSS  
Stainless steel wire thimble, Stainless steel



PPC<sub>ss</sub>  
Pad eye on mounting plate squarred, Stainless steel